




Wiremold
8803S-FC12 Omnibox Series Fire Classified 3-Gang Floor Box
Part No. 8803S-FC12

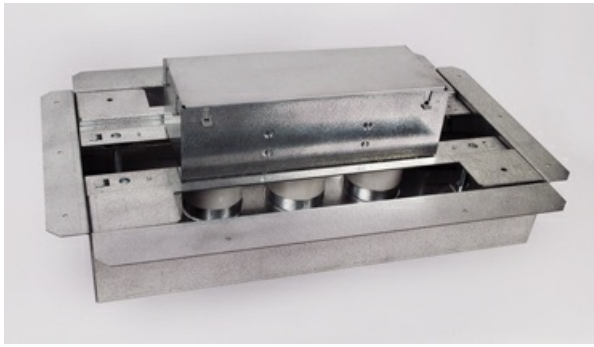

3-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 1 1/4" (32mm) and two 2" (51mm) conduit feed openings. Inside Gang Capacity - 67.5 cubic inches. Outside Gang Capacity - 54 cubic inches each gang. This floor box preserves up to a 3- hour fire rating of floors in which it has been installed.

Features & Benefits

3-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 1 1/4" (32mm) and two 2" (51mm) conduit feed openings. Inside Gang Capacity - 67.5 cubic inches. Outside Gang Capacity - 54 cubic inches each gang. This floor box preserves up to a 3- hour fire rating of floors in which it has been installed.

Specifications

General Info

| | | | |
|---------------------|---|--------------------|--------------|
| Product Line | Wiremold | UPC Number | 786776184204 |
| Country Of Origin | United States | Construction | Assembled |
| Number of Knockouts | 1 | Application Sector | Commercial |
| Standard | cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC. | Type | Floor Box |

Dimensions

| | | | |
|-------------------|-----------|------------------|----------|
| Product Width US | 11.375 in | Product Depth US | 3.5 in |
| Product Length US | 20.0 in | Cubic Capacity | 54 cu in |

Listing Agencies / 3rd Party Agencies

| | | | |
|---------------------|-------|--------------|-----|
| cULus ListingNumber | E2961 | cULus Listed | Yes |
|---------------------|-------|--------------|-----|

Buy American Act Compliance

| | |
|-------|-----|
| NAFTA | Yes |
|-------|-----|

Additional Information

RoHS Conformant Yes

Technical Information

Cable Entry Conduits
