




radiant Collection  
**radiant® 15A Tamper-Resistant Outlet with Night Light, Black**  
Part No. NTL885TRBKCC6

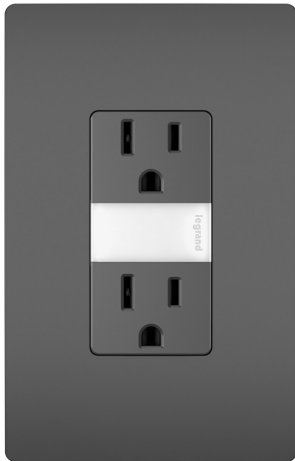

Perfect for adding a little light just where you need it, without sacrificing an outlet or dealing with unattractive plug-in models, this built-in night light from the radiant® Collection comes combined with a tamper-resistant outlet. A great upgrade for hallways and kids' bedrooms, it installs easily in place of a standard outlet and automatically comes on in the dark. With five adjustable light levels, you can easily set its brightness to meet your preferences or needs. Features the sleek, clean lines of radiant for a sophisticated touch. Made exclusively for use with screwless Wall Plates from the radiant® Collection, sold separately.

## Features & Benefits

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisible-shutters" for an invisible effect.

Features five adjustable light settings: Ultra Low, Low, Medium, High and OFF. Optional louver attachment also included for additional light level control.

Features durable, high-impact resistant thermoplastic construction.

Complete the look with a sleek, screwless radiant® Wall Plate, and coordinate with other designer switches and outlets available from the radiant® Collection.

Replaces any standard outlet with ease, in as little as 10 minutes.

Hidden sensor controls night light based on ambient light, automatically turning on when it is dark.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

## Specifications

### General Info

Product Line	Pass & Seymour	Replaced by Part Number	
Color	Black	Finish	Matte
Country Of Origin	China	Number of Receptacles	2
Features	Nightlight	Outlet Type	Tamper-Resistant
Application Sector	Residential	Standard	cULus, UL Listed

---

Warranty Type	1-Year Limited Warranty	Type	Nightlight, Outlet, Tamper-Resistant
---------------	-------------------------	------	--------------------------------------

---

### Dimensions

---

Product Width US	1.29 in	Product Depth US	1.3 in
Product Height US	4.2 in		

---

### Listing Agencies / 3rd Party Agencies

---

cULus Listed	Yes
--------------	-----

---

### Technical Information

---

Is Tamper-Resistant	Yes	Contact Configuration	15A
Operating Cycles	50000	Contact Rating	125
Amperage	15 A	Indoor/Outdoor	Indoor
NEMA Configuration Code	5-15R	Mounting Type	Box
Voltage	125.0 V	Environmental Conditions	Flammability Rating: UL 94 V2

---