




radiant Collection
radiant® Single-Pole 3-Way Vacancy Sensor, Tri-Color
Part No. RRW600VTC

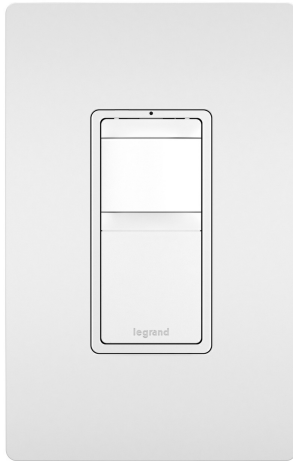

Never worry about leaving the lights on, with the radiant Registered Vacancy Sensor. It automatically shuts off when a room is empty, and includes an adjustable delay setting of up to 20 minutes to match your needs. Designed for ease and style, it features a built-in locator light, and the sleek, clean lines of radiant Registered for a sophisticated touch. Made exclusively for use with screwless Wall Plates from the radiant Registered Collection, sold separately.

Features & Benefits

Passive infrared (PIR) sensor switch technology with 180° coverage up to 600 sq. ft. Rated for up to 600W (5A) of LED lighting.

Works with virtually any bulb/fixture, including: LED, incandescent, fluorescent, compact fluorescent (CFL), magnetic low-voltage (MLV) and electronic low-voltage (ELV), 1/6 hp.

Turn the light on when you enter, and let it turn itself off automatically after you leave for true convenience. Perfect for bathrooms, hallways, closets, garages, and more.

Locator light illuminates when switch is off, emitting a soft glow to help you find it in the dark.

Features an adjustable time delay to off after no motion is detected. Delay settings range from 30 seconds to 20 minutes after the room is vacated (default 20 minute delay).

Manual ON/Auto OFF functionality. Meets California Title 24 requirements for automatic off lighting control.

Replace any basic light or fan switch in 15 minutes or less. Supports single pole and multi-location installs. No neutral required.

Complete the look with a sleek, screwless radiant® Wall Plate, and coordinate with other designer switches and outlets available from the radiant® Collection.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Specifications

General Info

Product Line	Pass & Seymour	Replaced by Part Number	
Color	Ivory, Light Almond, White	Country Of Origin	China
Features	Motion Sensor	Switch Type	Motion Sensor
Application Sector	Residential	Standard	cULus

Dimensions

Product Width US	1.69 in	Product Depth US	1.88 in
Product Height US	2.63 in		

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Technical Information

Target Size	180 deg	Response Frequency	60 Hz
Sensor Type	Occupancy	Amperage	5 A
Number of Poles	Single Pole	Wattage	600 W
Mounting Type	Box	Sensing Range	600 sq ft
Sensitivity	60Hz	Load	120VAC
Environmental Conditions	Indoor Use Only		
