




Wiremold  
8802S-FC Omnibox Series Fire Classified 2-Gang Floor Box  
Part No. 8802S-FC

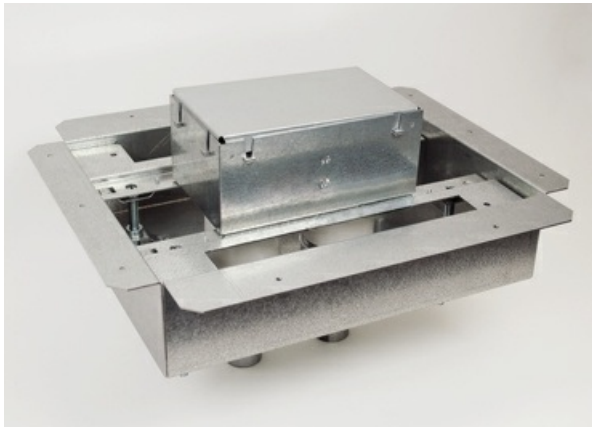

2-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 5" (127mm) maximum. Two 1 1/4" (32mm) conduit feed openings. Box Capacity - 58.5 cubic inches per gang. This floor box preserves the 2-hour fire rating of floors in which it has been installed.

## Features & Benefits

2-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 5" (127mm) maximum. Two 1 1/4" (32mm) conduit feed openings. Box Capacity - 58.5 cubic inches per gang. This floor box preserves the 2-hour fire rating of floors in which it has been installed.

## Specifications

### General Info

|                    |               |              |   |
|--------------------|---------------|--------------|---|
| Product Line       | Wiremold      | UPC Number   | 786776183153  |
| Country Of Origin  | United States | Construction | Assembled   |
| Application Sector | Commercial    | Standard     | cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC. |
| Type               | Floor Box     |              |   |

### Dimensions

|                |           |
|----------------|-----------|
| Cubic Capacity | 117 cu in |
|----------------|-----------|

### Listing Agencies / 3rd Party Agencies

|                     |       |              |     |
|---------------------|-------|--------------|-----|
| cULus ListingNumber | E2961 | cULus Listed | Yes |
|---------------------|-------|--------------|-----|

### Buy American Act Compliance

|       |     |
|-------|-----|
| NAFTA | Yes |
|-------|-----|

---

## Additional Information

---

RoHS Conformant                      Yes

---

## Technical Information

---

Cable Entry                      conduit Feed Channels                      Number of Outlets    4

---