




adorne Collection
adorne® Touch Tru-Universal Dimmer, Magnesium, with Microban®
Part No. ADTH703TUM4

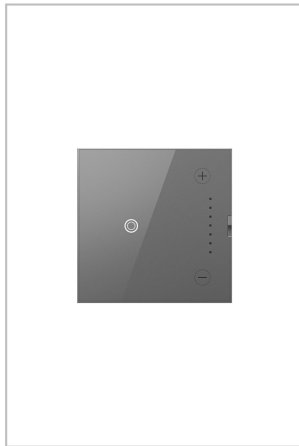

This dimmer switch from the adorne Collection features a translucent, glass-like face and operates with the simple touch of a finger on the center circle to turn lights on/off, or by using the + or - on the side to dim. In multi-gang installations, we recommend using the Touch-control modern light switches and dimmers together for consistency of control and aesthetic. A Tru-Universal Dimmer, this device self-calibrates to work with virtually any 120V dimmable bulb or fixture (excludes 0-10V).

This dimmer* features enduring Microban® antimicrobial technology that works to reduce the growth of bacteria, around the clock, for the lifespan of the product.

* Existing inventory of switches, dimmers and plastic wall plates from the adorne® Collection at some partner locations may not yet include Microban® protection. To confirm that a specific Legrand product is protected with Microban®, check that the exterior of the product packaging includes a green dot or a "Protected with Microban" label.

Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

Features & Benefits

Helps fight the growth of stain and odor-causing bacteria through the invisible and continuous product protection of Microban® antimicrobial technology

Installs in 15 minutes or less, fitting into an existing electrical box; neutral wire required.

Self-calibrates when you select your fixture's lighting type, automatically setting the appropriate minimum voltage to eliminate flicker and poor performance.

Offers installation flexibility, working in both single-pole and 3-way applications.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Works with virtually any 120V dimmable bulb or fixture (excludes 0-10V).

Constant memory feature returns lights to their previous level when turning back on or after a power outage.

Usable in both single-pole and 3-way applications.

Specifications

General Info

Product Line

Pass & Seymour

Replaced by Part Number

| | | | |
|------------------------------|---|-------------------|---------------------------|
| Color | Magnesium | Country Of Origin | China |
| Features | Antimicrobial Protection, Indicator Lights | Switch Type | Touch |
| Number of Switches | 1 | Warranty Type | Limited Lifetime Warranty |
| Dimensions | | | |
| Product Width US | 1.77 in | Product Depth US | 1.29 in |
| Product Height US | 2.48 in | | |
| Technical Information | | | |
| Electrical Rating | 120V 1100W (Halogen), 120V 1600VA (MLV), 120V 16A (Fluorescent), 120V 2000W (Incandescent), 120V 450W (CFL), 120V 450W (LED), 120V 5A (Fan Control), 120V 700W (ELV), 120V 8A (EFL) | Number of Gangs | 1 |
| Bulb Compatibility | CFL, Fluorescent, Halogen, HID, Incandescent, LED, Universal, Xenon | Number of Poles | 3-Way, Single Pole |
| Wattage | 700 W | Mounting Type | Box |
| Voltage | 120.0 V | Connection Type | Internal Pressure Plates |