




adorne Collection
adorne® Ultra-Fast USB Type-A/A Outlet Module, White
Part No. ARUSB2AA6W4

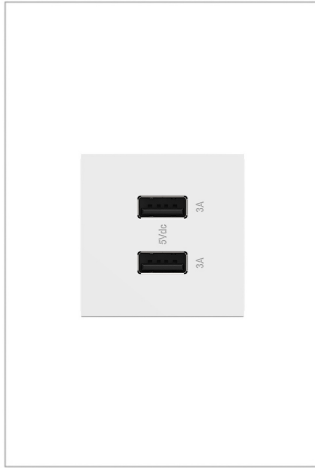

Charge phones, tablets and more up to 40% faster, with Ultra-Fast USB Outlets from the adorne® Collection. Delivering a leading 6 amps of power to its two USB connections for faster in-wall charging, without an adapter. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Features an industry-leading 6.0A of power, as well as Smart Chip technology, to maximize charging speed for each USB connection.

Legrand USB Outlets are manufactured through high-quality design, sourcing and production, and backed by a Lifetime Warranty.

Provides fast and convenient built-in charging, without sacrificing plugs or requiring a bulky adapter.

Replaces a traditional outlet easily, in as little as 10 minutes.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Finish	Matte	Country Of Origin	China
Number of Receptacles	0	Features	USB-A Charging
Outlet Type	Indoor, Residential, USB-Charging	Application Sector	Residential/Commercial
Standard	yes	Warranty Type	Limited Lifetime Warranty
Type	Outlet		

Dimensions

Product Width US	1.77 in	Product Depth US	1.7 in
------------------	---------	------------------	--------

Product Height US	2.65 in
-------------------	---------

Technical Information

USB Amperage	6 A	Connection	USB Type A/A
--------------	-----	------------	--------------

Number of USBs	2	Number of Gangs	1
----------------	---	-----------------	---

USB Power Output	15 W	Number of Poles	Double Pole
------------------	------	-----------------	-------------

Indoor/Outdoor	Indoor	Mounting Type	Box
----------------	--------	---------------	-----

Voltage	5.0 VDC	Connection Type	Internal Pressure Plates
---------	---------	-----------------	--------------------------

Environmental Conditions	95% (relative humidity, non-condensing)
--------------------------	---
