




adorne Collection
adorne® Ultra-Fast USB Type-A/C Outlet Module, Magnesium
Part No. ARUSB2AC6M4

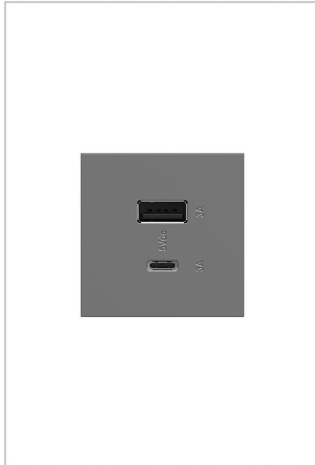

Charge phones, tablets and more up to 40% faster, with Ultra-Fast USB Outlets from the adorne® Collection. Made to deliver a leading 6 amps of power, it features two built-in USB connections, including one to fit USB Type-C devices, and provides a fast, future-proof solution for convenient in-wall charging without an adapter. Easily replacing traditional outlets in as little as ten minutes, this Ultra-Fast USB Outlet transforms your space with modern functionality and the unique, contemporary aesthetic of adorne. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Features an industry-leading 6.0A of power, as well as Smart Chip technology, to maximize charging speed for each USB connection.

Replaces a traditional outlet easily, in as little as 10 minutes.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Provides fast and convenient built-in charging, without sacrificing plugs or requiring a bulky adapter.

Includes connections for both traditional USB Type-A and the newer USB Type-C, to accommodate all mobile devices.

Legrand USB Outlets are manufactured through high-quality design, sourcing and production, and backed by a Lifetime Warranty.

Specifications

General Info

| | | | |
|--------------------|--------------------------------|-------------------------|-----------------------------------|
| Product Line | Pass & Seymour | Replaced by Part Number | |
| Color | Magnesium | Finish | Frosted |
| Country Of Origin | China | Number of Receptacles | 0 |
| Features | USB-A Charging, USB-C Charging | Outlet Type | Indoor, Residential, USB-Charging |
| Application Sector | Residential/Commercial | Standard | yes |
| Warranty Type | Limited Lifetime Warranty | Type | Outlet |

Dimensions

| | | | |
|------------------|---------|------------------|--------|
| Product Width US | 1.77 in | Product Depth US | 1.7 in |
|------------------|---------|------------------|--------|

| | |
|-------------------|---------|
| Product Height US | 2.65 in |
|-------------------|---------|

Technical Information

| | | | |
|--------------|-----|------------|--------------|
| USB Amperage | 6 A | Connection | USB Type A/C |
|--------------|-----|------------|--------------|

| | | | |
|----------------|---|-----------------|---|
| Number of USBs | 2 | Number of Gangs | 1 |
|----------------|---|-----------------|---|

| | | | |
|------------------|------|-----------------|-------------|
| USB Power Output | 15 W | Number of Poles | Double Pole |
|------------------|------|-----------------|-------------|

| | | | |
|----------------|--------|---------------|-----|
| Indoor/Outdoor | Indoor | Mounting Type | Box |
|----------------|--------|---------------|-----|

| | | | |
|---------|---------|-----------------|--------------------------|
| Voltage | 5.0 VDC | Connection Type | Internal Pressure Plates |
|---------|---------|-----------------|--------------------------|

| | |
|--------------------------|---|
| Environmental Conditions | 95% (relative humidity, non-condensing) |
|--------------------------|---|
