




Wiremold  
8802S-FC Omnibox Series Fire Classified 2-Gang Floor Box  
Part No. 8802S-FC

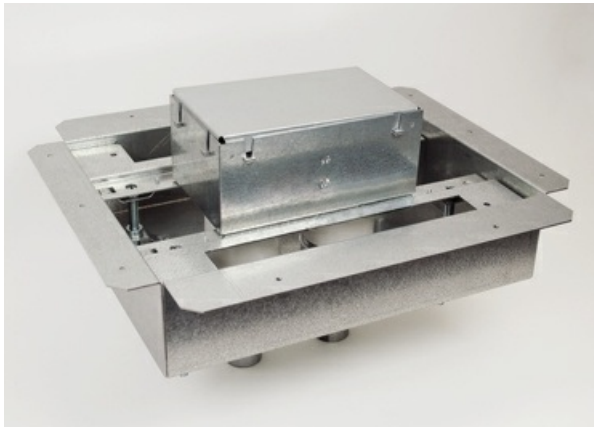

2-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 5" (127mm) maximum. Two 1 1/4" (32mm) conduit feed openings. Box Capacity - 58.5 cubic inches per gang. This floor box preserves the 2-hour fire rating of floors in which it has been installed.

## Features & Benefits

2-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 5" (127mm) maximum. Two 1 1/4" (32mm) conduit feed openings. Box Capacity - 58.5 cubic inches per gang. This floor box preserves the 2-hour fire rating of floors in which it has been installed.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786776183153
Country Of Origin	United States	Construction	Assembled
Application Sector	Commercial	Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.
Type	Floor Box		

### Dimensions

Cubic Capacity	117 cu in
----------------	-----------

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E2961	cULus Listed	Yes
---------------------	-------	--------------	-----

### Buy American Act Compliance

NAFTA	Yes
-------	-----

---

## Additional Information

---

RoHS Conformant                      Yes

---

## Technical Information

---

Cable Entry                      conduit Feed Channels                      Number of Outlets    4

---