




adorne Collection  
adorne® 15A Dual Tamper-Resistant Outlet, White  
Part No. ARTR152W4

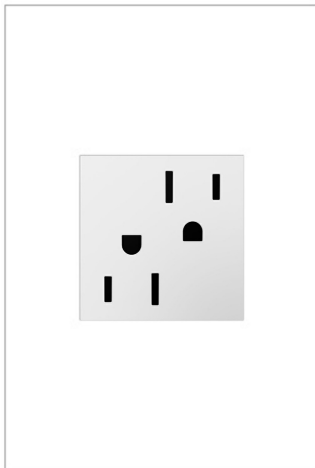

A modern upgrade for style and safety, this 15A tamper-resistant designer outlet from the adorne Collection installs easily for the basic power every home needs, while elevating your space. The adorne wall outlets are made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

## Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Replaces any standard outlet with ease, in as little as 10 minutes.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisible shutters" for an invisible effect.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

## Specifications

### General Info

Product Line	Pass & Seymour	Replaced by Part Number	
Color	White	Finish	Matte
Country Of Origin	China	Number of Receptacles	2
Outlet Type	Indoor, Residential, Tamper-Resistant	Application Sector	Residential
Standard	CULUS	Warranty Type	Limited Lifetime Warranty
Type	Outlet		

### Dimensions

Product Width US	1.77 in	Product Depth US	1.73 in
Product Height US	2.12 in		

---

## Technical Information

---

Phase	Single	Connection	Side and Back Wire
Number of Wires	3	Number of Gangs	1
Amperage	15 A	Number of Poles	Double Pole
Wire Size	14 - 10 AWG	Indoor/Outdoor	Indoor
NEMA Configuration Code	5-15R	Mounting Type	Box
Voltage	125.0 V	Connection Type	Internal Pressure Plates
Environmental Conditions	95% (relative humidity, non-condensing)		

---