




APPLICATIONS

CPSA Vari-Angle Series Support is variable angle support designed for sloped or uneven surfaces.

Use for:

- Wire mesh and ladder cable pathways
- Ventilation duct
- Walkway systems
- HVAC equipment

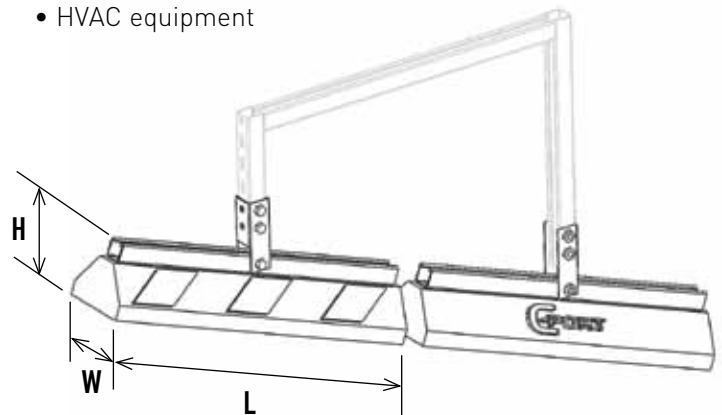

FEATURES

- UV resistant
- Install on any roofing material
- Easily adjusted onsite
- Leg adaptor will accommodate 1-5/8" x 1-5/8" channel framing
- U-shaped 1-7/8" x 1-7/8" leg adaptor predrilled with 9/16" mounting holes is pre-mounted to base
- CPSA maximum load 500 lbs.
- 100% recycled rubber construction assists with building qualification for LEED credits.

PRODUCT NO.	SUPPORT	BASE HEIGHT	BASE WIDTH	BASE LENGTH	WEIGHT	PG
CPSA10PG	STRUT	5-5/8"	6"	9.6"	8.0	943667
CPSA20PG		5-5/8"	6"	22"	15.1	943668

Vertical 1 5/8" x 1 5/8" strut and horizontal crossbar not provided.