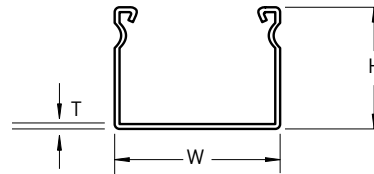

FEATURES

- Strong corrosion resistant steel construction
- Rolled edge for cable protection
- Unique design allows covers to snap on
- 18 gage steel (T)

COMPATIBLE COVER
FTC
(sold separately)


	TRAY HEIGHT (H)		TRAY WIDTH (W)		LENGTH		PG	BL
	INCHES	MM	INCHES	MM	FT	M		
							STANDARD	
FT 50/50	2.0	50	2.0	50	9.8	3	340 020	960 000
FT 50/100	2.0	50	3.9	100	9.8	3	340 021	960 001
FT 50/200*	2.0	50	7.9	200	9.8	3	340 023	960 002
FT 50/300*	2.0	50	11.8	300	9.8	3	340 024	960 003
FT 100/100	3.9	100	3.9	100	9.8	3	340 030	960 004
FT 100/200	3.9	100	7.8	200	9.8	3	340 032	960 005
FT 100/300	3.9	100	11.8	300	9.8	3	340 033	960 006
FT 100/500*	3.9	100	19.7	500	9.8	3	340 093	960 007
FT 100/600*	3.9	100	23.6	600	9.8	3	340 107	960 008

* Ribbed bottom for additional rigidity

FINISHES		
SYMBOL	MATERIAL	FINISH & STANDARD
STANDARD	PG	Carbon Steel Pre-Galvanized: Continuous Galvanization Before Fabrication ASTM A 653
	BL	Carbon Steel ASTM A510 Grade 1008 Black Painted: Black Powder Coated ASTM D 3451

Legrand/Cablofil
 8319 State Route 4
 Mascoutah, IL 62258 USA
 1-800-658-4641
 618-566-3230
 Fax 618-566-3250
www.legrand.us/cablofil