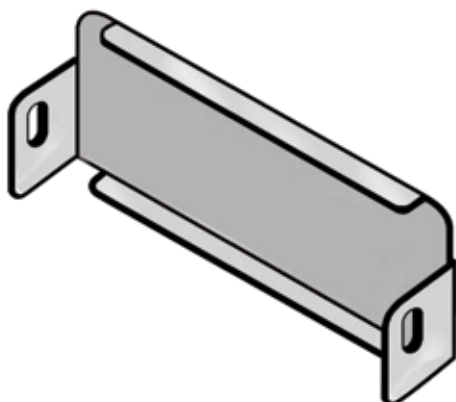


Hardware included

- M6x12mm square neck carriage bolt (zinc plated)
- M6 serrated flange hex nut (zinc plated)

FEATURES

- Provides closure at ends
- Rigid steel construction
- Can be punched for conduit attachment

	PACK		HEIGHT		WIDTH		PG	BL
	PCS	INCHES	MM	INCHES	MM	STANDARD		
FTBE 50/50	1	2	50	2	50	341 537	960 144	
FTBE 50/100	1	2	50	4	100	341 538	960 145	
FTBE 50/200	1	2	50	8	200	341 540	960 146	
FTBE 50/300	1	2	50	12	300	341 541	960 147	
FTBE 100/100	1	4	100	4	100	341 659	960 159	
FTBE 100/200	1	4	100	8	200	341 661	960 160	
FTBE 100/300	1	4	100	12	300	341 662	960 161	
FTBE 100/500	1	4	100	20	500	341 664	960 162	
FTBE 100/600	1	4	100	24	600	340 737	960 163	

FINISHES			
SYMBOL		MATERIAL	FINISH & STANDARD
STANDARD	PG	Carbon Steel	Pre-Galvanized: Continuous Galvanization Before Fabrication ASTM A 653
	BL	Carbon Steel ASTM A510 Grade 1008	Black Painted: Black Powder Coated ASTM D 3451

Legrand/Cablofil
 8319 State Route 4
 Mascoutah, IL 62258 USA
 1-800-658-4641
 618-566-3230
 Fax 618-566-3250
www.legrand.us/cablofil