


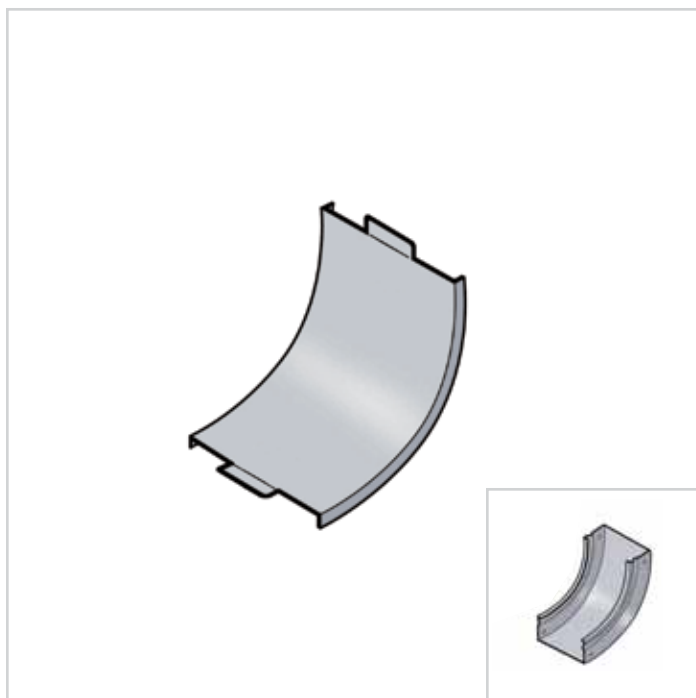

FEATURES

- Strong corrosion-resistant steel
- Tool-less, snap-on design
- Extended tongue support cover centers, eliminates gaps
- 18 gage steel

FITS ELBOW

FTVI90

(sold separately)

	FITS TRAY HEIGHT		COVER WIDTH		PG	BL
	INCHES	MM	INCHES	MM	STANDARD	
FTCVI90 50/50	2	50	2	50	340 888	960 112
FTCVI90 50/100	2	50	4	100	340 890	960 113
FTCVI90 50/200	2	50	8	200	340 892	960 114
FTCVI90 50/300	2	50	12	300	340 893	960 115
FTCVI90 100/100	4	100	4	100	341 175	960 116
FTCVI90 100/200	4	100	8	200	340 894	960 117
FTCVI90 100/300	4	100	12	300	340 895	960 118
FTCVI90 100/500	4	100	20	500	340 897	960 119
FTCVI90 100/600	4	100	24	600	340 898	960 120

FINISHES			
SYMBOL	MATERIAL	FINISH & STANDARD	
STANDARD	PG	Carbon Steel	Pre-Galvanized: Continuous Galvanization Before Fabrication ASTM A 653
	BL	Carbon Steel ASTM A510 Grade 1008	Black Painted: Black Powder Coated ASTM D 3451

Legrand/Cablofil
 8319 State Route 4
 Mascoutah, IL 62258 USA
 1-800-658-4641
 618-566-3230
 Fax 618-566-3250
www.legrand.us/cablofil