



## 90HB/ 60HB/ 45 HB/ 30HB Covers for Horizontal Elbow Fittings

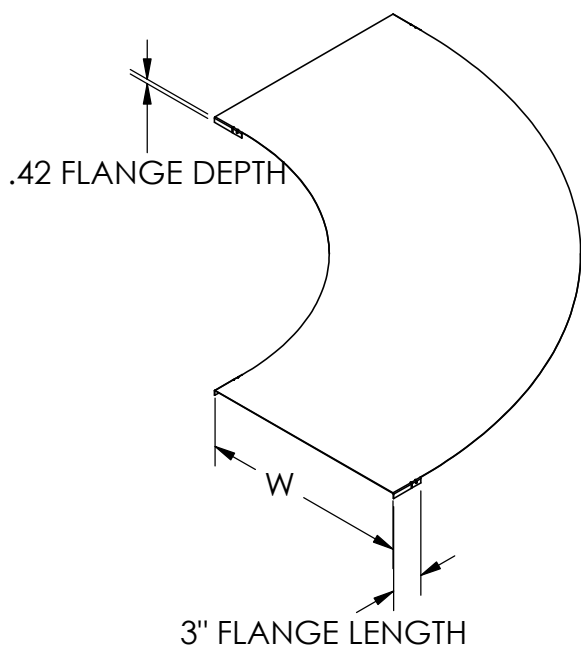


**STANDARD HORIZONTAL  
BEND COVER STYLE**

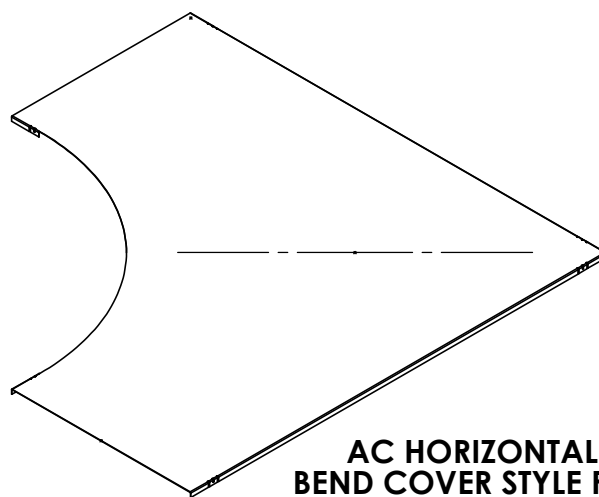

**AC HORIZONTAL  
BEND COVER STYLE FOR  
VC & SC STYLE FITTINGS**

### FOR HORIZONTAL ELBOWS ( 90HB/60HB/45HB/30HB )

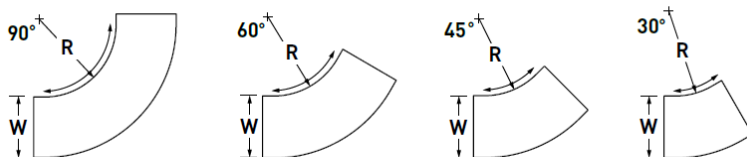

#### HORIZONTAL ELBOW COVER CATALOG NUMBERING EXAMPLE:

A - S F F - 90HB12 - 06					WIDTH
A - Aluminum for Ladder and Solid Flat Bottoms AC* - Aluminum for Corrugated Bottoms	COVER TYPE	FITTING CODE	RADIUS		
				06 - 6"	
				09 - 9"	
				12 - 12"	
SFF - Solid Flat Flanged LFF - Louvered Flat Flanged SPF - Solid Peaked Flanged		90HB	12 - 12"	18 - 18"	
		60HB	24 - 24"	24 - 24"	
		45HB	36 - 36"	30 - 30"	
		30HB		36 - 36"	

\*AC covers are only available in SFF.

- **Material:** Aluminum Alloy 5052 - H32
- **Finish:** Plain
- **Height (H):** Tray height: 4", 5", 6", 7"
- **Width (W):** Tray width: 6", 9", 12", 18", 24", 30", 36"
- Cover connectors are purchased separately

- \* Radius is the radius of fitting being covered
- \* **AC covers have mitered outside radius to match VC & SC fittings.**