
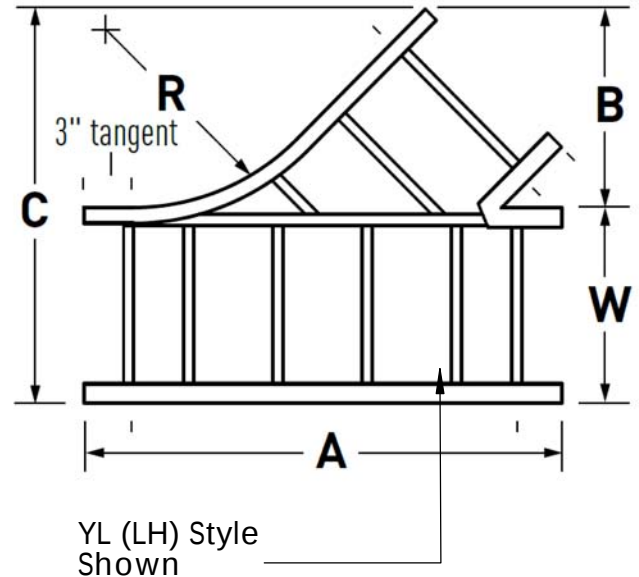


YL/YR Horizontal WYE Branches

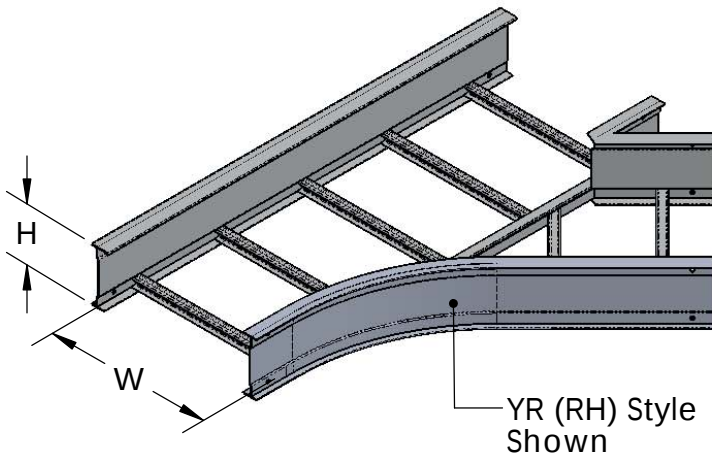

ITRAY HORIZONTAL WYE BRANCH CATALOG NUMBERING EXAMPLE:

BOTTOM TYPE	LD - 4	A	- YL	24 - 09	WIDTH
VENTED					06 - 6"
LD - Ladder Rung					09 - 9"
VC - Vented Corrugated					12 - 12"
NON-VENTED					18 - 18"
SC - Solid Corrugated					24 - 24"
SB - Solid Bottom					30 - 30"
					36 - 36"

RAIL HEIGHT: 4 - 4", 5 - 5", 6 - 6", 7 - 7"

FITTING CODE: YL, YR

RADIUS: 24 - 24"

MATERIAL: A

Width W	Radius R	A	B	C
6	24	31-1/4	12	18
9		35-1/2	14-1/8	23-1/8
12		39-5/8	16-1/4	28-1/4
18		48-1/4	20-1/2	38-1/2
24		56-5/8	24-3/4	48-3/4
30		65-1/4	29	59
36		73-5/8	33-1/4	69-1/4

- **Material:** Aluminum Alloy 6063
- **Finish:** Plain
- **Bottom:** LD: 1" wide rung
SB: Flat sheet over Rung
SC: Solid Corrugated
VC: Vented Corrugated
- **Construction:** Welded
- **Tray Design:** Tray construction and markings are per the latest edition of NEMA Standards Publication VE1, CSA C22.2 No. 126
- **Connectors:** All fittings are supplied with necessary connectors and fasteners
- **Fitting heights (H):** 4", 5", 6", 7"