
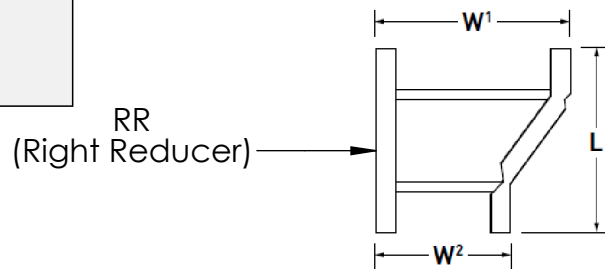
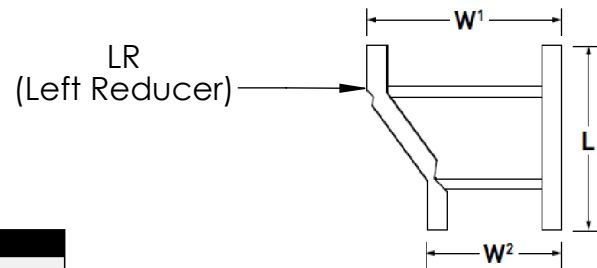
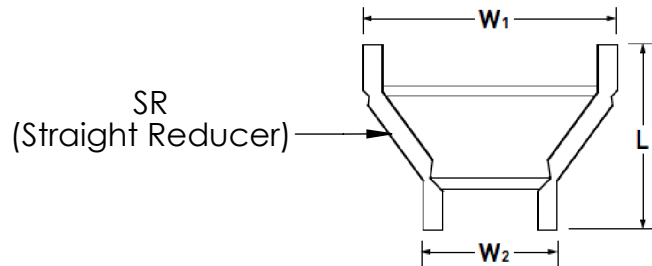


SR/LR/RR Reducers

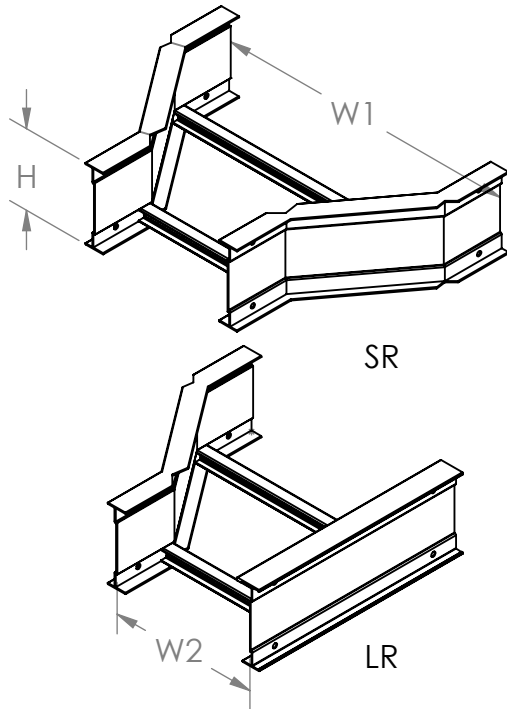

ITRAY HORIZONTAL REDUCER CATALOG NUMBERING EXAMPLE:					
BOTTOM TYPE		VC - 4 A - SR 09 - 06			WIDTH 2
VENTED		RAIL HEIGHT	FITTING CODE	06 - 6"	
LD - Ladder Rung				09 - 9"	
VC - Vented Corrugated		4 - 4"	MATERIAL	12 - 12"	
NON-VENTED		5 - 5"		18 - 18"	
SC - Solid Corrugated		6 - 6"		24 - 24"	
SB - Solid Bottom		7 - 7"		30 - 30"	
				36 - 36"	

- **Material:** Aluminum Alloy 6063
- **Finish:** Plain
- **Bottom:** LD: 1" wide rung
SB: Flat sheet over Rung
SC: Solid Corrugated
VC: Vented Corrugated
- **Construction:** Welded
- **Connectors:** All fittings are supplied with necessary connectors and fasteners
- **Fitting heights (H):** 4, 5, 6, 7 "

LENGTH L	MAIN WIDTH W1	AVAILABLE BRANCH WIDTHS W2					
18	9	6	-	-	-	-	-
	12	6	9	-	-	-	-
	18	6	9	12	-	-	-
	24	6	9	12	18	-	-
	30	6	9	12	18	24	-
	36	6	9	12	18	24	30