



Cable management that's secure and installs 50% faster

J-Hooks provide an easy-to-install, non-continuous cable support for all types of telecommunication, data and power cabling. They also are perfect for low voltage building cable management and fire protection cabling.

Our CJH Series is engineered to provide stress-free cable support for multiple cables and features a structural design for optimal strength and tapered edges to reduce cable sheath damage. Multiple pre-drilled holes reduce on-site modification at installation. J-Hooks can be attached to a variety of structures and are available with multiple attachment options that allow quick and easy cable installation virtually anywhere.

The CJHP Series J-Hooks are plenum rated, plastic coated and feature a built in latch that allows you to lock the bendable flap into place – and unlock easier. CJHP hooks also combine the best features of both metal and plastic, providing strength and a slick, no-burr surface to make pulling cable easy. All CJHP hooks are plenum safe.

Features & Benefits

CJH Series – Steel J-Hooks

- **Broad product line.** CJH Series J-Hooks are available in 4 sizes ¾" to 4" sizes with a cable retainer clip (Patent Pending) and has multiple attachment options.
- **Sturdy steel construction.** CJH Series J-Hooks have a wider base and provides optimal support for electrical and high-performance data cables, including CAT 5e, CAT 5, CAT 6A, CAT 7 and fiber optic.
- **Smooth tapered edges.** Smooth edges of CJH Series J-Hooks reduces pressure points for ultimate cable protections.
- **Simple single person installation.** Labor savings.
- **Highest cable fill capacity.** CJH Series J-Hooks have the highest fill capacity on the market and are engineered to accommodate future emerging data cables.
- **Manufactured using over 70% recycled steel.** CJH Series J-Hooks are manufactured using over 70% recycled steel. Great for recycling and the environment.
- **UL load and anti-corrosion tested.** cULus listed.
- **RoHS compliant.** Environmentally friendly.
- **Meets TIA-568-C & TIA 569-C and complies with EN 50174-2.** Ensures that software and applications running on the network are able to perform as designed and work seamlessly together.

CJHP Series – Plastic J-Hooks

- **Cable containment latch.** CJHP Services J-Hooks integral catch quickly opens and closes for easy moves, adds or changes. Available in 4 sizes 1" to 4" sizes and has multiple attachment options.
- **Smooth easy-slide polypropylene construction.** CJHP Series J-Hooks allow cables to slide with 50% less pulling tension.
- **Safe for use in plenum spaces.** CJHP Series J-Hooks are UL listed safe for use in plenum spaces.
- **Simple single person installation.** Labor savings.
- **UL load and anti-corrosion tested.** cULus listed.
- **RoHS compliant.** Environmentally friendly.
- **Meets TIA-568-C & TIA 569-C and complies with EN 50174-2.** Ensures that software and applications running on the network are able to perform as designed and work seamlessly together.

Vertical Markets

- Commercial
- Hospitality
- Education
- Entertainment


Compliance

- cULus Listed UL31TS
- RoHS Compliant

Country of Origin

- Cablofil® CJH Series and CJHP Series J-Hooks are made in the USA and assembled in Mexico.

CJH Series Steel J-Hooks Specifications

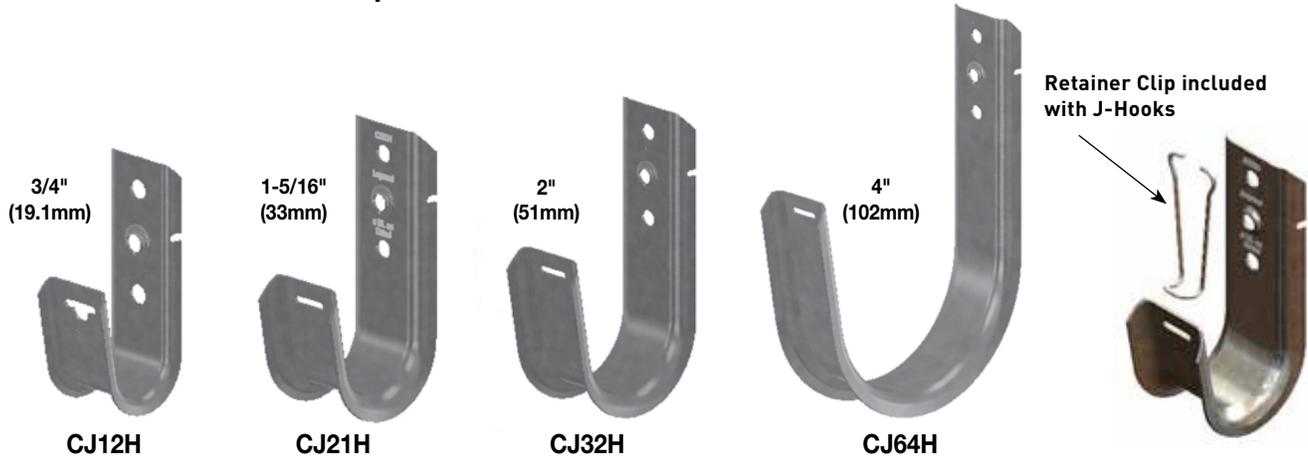

CJH Series J-Hooks Load/Fill Capacity Table					
	HOOK SIZE	LOAD CAPACITY	CABLE CAPACITY		
	IN	LBS	4-PAIR UTP CAT 5E	CAT 6	CAT 6A
CJ12H	3/4"	65	34	23	13
CJ21H	1-5/16"	65	61	42	24
CJ32H	2"	65	119	81	48
CJ64H	4"	65	417	284	167

CJH Series J-Hooks Attachment Options				
W 	AC 	AC6 	HOK24 	HOK58
Bat Wing 12 Gage – 1/4" & 3/8" ATR	90° Angled Clip – 1/4" hole	90° Angled Clip – 3/8" hole	Knock-On Steel Beam Clamp – 1/8" to 1/4"	Knock-On Steel Beam Clamp – 5/16" to 1/2"
PBC 	ACPBC 	SSBC 	ACSSB 	ACHOK24
Pressed Beam Clamp – up to 1/2"	Angled Clip & Pressed Beam Clamp – up to 1/2"	Assembled to SSBC – 1/8" to 1/2"	Angled Clip & SSBC – swivels 360°	Knock-on Clamp & Angled Clip – swivels 360°

PART NUMBERING EXAMPLE
CJ12HHOK24

J-HOOK ——— **ATTACHMENT**
 Choose between ——— Choose option
 CJ12H, CJ21H, CJ32H & CJ64H

CJH Series Steel J-Hooks Ordering Information

CJ12H – 3/4" J-HOOK					
	PKG QTY	HOOK SIZE (In.)	DESCRIPTION	WEIGHT (Lbs.)	PG
CJ12H	50	3/4"	J-Hook Wide Base w/Retainer	4.5	F000247
CJ12HAC	50	3/4"	J-Hook Wide/Ret - 90° Angle Clip 1/4 Rod	5.8	F000248
CJ12HW*	50	3/4"	J-Hook Wide/Ret - Batwing Clip	5.75	F000249
CJ12HAC6	50	3/4"	J-Hook Wide/Ret 90° Angle Clip 3/8 Rod	5.7	F000250
CJ12HSSBC	50	3/4"	J-Hook Wide/Ret - Screw on Spring Steel Beam Clip 1/2	7.3	F000259
CJ12HACHOK24	50	3/4"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 1/8-1/4	8.35	F000252
CJ12HACHOK58	50	3/4"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 5/16-1/2	8.35	F000253
CJ12HACPBC	50	3/4"	J-Hook Wide/Ret - 90° Swivel Screw on Beam Clip 1/2	11.5	F000254
CJ12HACSSBC	50	3/4"	J-Hook Wide/Ret - 90° Swivel Screw on Beam Clip 1/2	8.6	F000255
CJ12HHOK24	50	3/4"	J-Hook Wide/Ret - Knock on Beam Clamp 1/8-1/4	5.8	F000256
CJ12HHOK58	50	3/4"	J-Hook Wide/Ret - Knock on Beam Clamp 5/16-1/2	5.8	F000257
CJ12HPBC	50	3/4"	J-Hook Wide/Ret - Screw on Beam Clamp 1/2	10.2	F000258

CJ21H – 1 5/16" J-HOOK					
	PKG QTY	HOOK SIZE (In.)	DESCRIPTION	WEIGHT (Lbs.)	PG
CJ21H	50	1-5/16"	J-Hook Wide Base w/Retainer	8.5	F000260
CJ21HAC	50	1-5/16"	J-Hook Wide/Ret - 90° Angle Clip 1/4 Rod	9.8	F000261
CJ21HW*	50	1-5/16"	J-Hook Wide/Ret - Batwing Clip	9.75	F000262
CJ21HAC6	50	1-5/16"	J-Hook Wide/Ret - 90° Angle Clip 3/8 Rod	9.7	F000263
CJ21HSSBC	50	1-5/16"	J-Hook Wide/Ret - Screw on Spring Steel Beam Clip 1/2	11.3	F000272
CJ21HACHOK24	50	1-5/16"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 1/8-1/4	12.35	F000265
CJ21HACHOK58	50	1-5/16"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 5/16-1/2	12.35	F000266
CJ21HACPBC	50	1-5/16"	J-Hook Wide/Ret - 90° Swivel Screw on Beam Clip 1/2	15.5	F000267
CJ21HACSSBC	50	1-5/16"	J-Hook Wide/Ret - 90° Swivel Screw on Spring Steel Beam Clip 1/2	12.6	F000268
CJ21HHOK24	50	1-5/16"	J-Hook Wide/Ret - Knock on Beam Clip 1/8-1/4	9.8	F000269
CJ21HHOK58	50	1-5/16"	J-Hook Wide/Ret - Knock on Beam Clip 5/16-1/2	9.8	F000270
CJ21HPBC	50	1-5/16"	J-Hook Wide/rRet - Screw on Beam Clip 1/2	14.2	F000271

CJ32H – 2" J-HOOK					
	PKG QTY	HOOK SIZE (In.)	DESCRIPTION	WEIGHT (Lbs.)	PG
CJ32H	50	2"	J-Hook Wide Base w/Retainer	10.3	F000273
CJ32HAC	50	2"	J-Hook Wide/Ret - 90° Angle Clip 1/4 Rod	11.6	F000274
CJ32HW*	50	2"	J-Hook Wide/Ret - Batwing Clip	11.55	F000275
CJ32HAC6	50	2"	J-Hook Wide/Ret - 90° Angle Clip 3/8 rod	11.5	F000276
CJ32HSSBC	50	2"	J-Hook Wide/Ret - Screw on Spring Steel Beam Clip 1/2	13.1	F000285
CJ32HACHOK24	50	2"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 1/8-1/4	14.15	F000278
CJ32HACHOK58	50	2"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 5/16-1/2	14.15	F000279
CJ32HACPBC	50	2"	J-Hook Wide/Ret - 90° Swivel Screw on Press Beam Clip 1/2	17.3	F000280
CJ32HACSSBC	50	2"	J-Hook Wide/Ret - 90° Swivel Screw on Spring Steel Beam Clip 1/2	14.4	F000281
CJ32HHOK24	50	2"	J-Hook Wide/Ret - Knock on Beam Clip 1/8-1/4	11.6	F000282
CJ32HHOK58	50	2"	J-Hook Wide/Ret - Knock on Beam Clip 5/16-1/2	11.6	F000283
CJ32HPBC	50	2"	J-Hook Wide/Ret - Screw on Beam Clip 1/2	13.8	F000284

* Works with both 1/4 x 20 and 3/8 x 16 rod

CJH Series Steel J-Hooks Ordering Information

CJ64H – 4" J-HOOK					
	PKG QTY	HOOK SIZE (In.)	DESCRIPTION	WEIGHT (Lbs.)	PG
CJ64H	25	4"	J-Hook Wide Base w/Retainer	9.25	F000286
CJ64HAC	25	4"	J-Hook Wide/Ret - 90° Angle Clip 1/4 Rod	9.9	F000287
CJ64HW*	25	4"	J-Hook Wide/Ret - Batwing Clip	10	F000288
CJ64HAC6	25	4"	J-Hook Wide/Ret - 90° Angle Clip 3/8 Rod	9.85	F000289
CJ64HSSBC	25	4"	J-Hook Wide/Ret - Screw on Beam Clip 1/2	10.65	F000298
CJ64HACHOK24	25	4"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 1/8-1/4	11.18	F000291
CJ64HACHOK58	25	4"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 5/16-1/2	11.18	F000292
CJ64HACPBC	25	4"	J-Hook Wide/Ret - Screw on Press Beam Clip 1/2	12.75	F000293
CJ64HACSSBC	25	4"	J-Hook Wide/Ret - Screw on Spring Steel Beam Clip 1/2	11.3	F000294
CJ64HHOK24	25	4"	J-Hook Wide/Ret - Knock on Beam Clip 1/8-1/4	9.9	F000295
CJ64HHOK58	25	4"	J-Hook Wide/Ret - Knock on Beam Clip 5/16-1/2	9.9	F000296
CJ64HPBC	25	4"	J Hook Wide/Ret - Screw on Beam Clip 1/2	12.1	F000297

* Works with both 1/4 x 20 and 3/8 x 16 rod

CJHP Series Plastic J-Hooks Ordering Information




1"
(25mm)




CJ16HP

2"
(51mm)

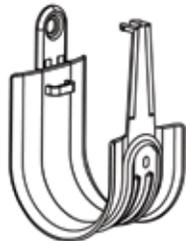


CJ32HP

3"
(76mm)

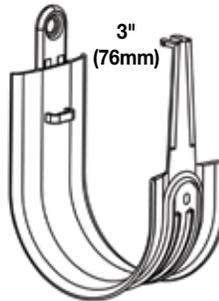

CJ48HP

4"
(102mm)

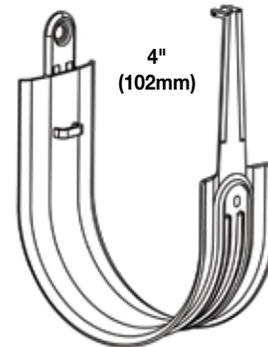


CJ64HP

CJHP Load Capacity Table					
	HOOK SIZE	LOAD CAPACITY	CABLE CAPACITY		
	IN.	LBS.	4-PAIR UTP CAT 5E	CAT 6	2 STRAND FIBER OPTIC
CJ16HP	1"	17	20	15	20
CJ32HP	2"	17	90	60	90
CJ48HP	3"	20	200	150	200
CJ64HP	4"	17	330	220	330

NOTE: Standard color is white. Additional colors available are black, blue and red.

CJHP Series Plastic J-Hooks Attachment Options

CJHP Series J-Hooks Attachment Options				
W 	AC 	AC6 	HOK24 	HOK58 
Bat Wing 12 Gage – 1/4" ATR	90° Angled Clip – 1/4" hole	90° Angled Clip – 3/8" hole	Knock-On Steel Beam Clamp – 1/8" to 1/4"	Knock-On Steel Beam Clamp – 5/16" to 1/2"
PBC 	ACPBC 	SSBC 	ACSSB 	ACHOK24 
Pressed Beam Clamp – up to 1/2"	Angled Clip & Pressed Beam Clamp – up to 1/2"	Assembled to SSBC – 1/8" to 1/2"	Angled Clip & SSBC – swivels 360°	Knock-on Clamp & Angled Clip – swivels 360°

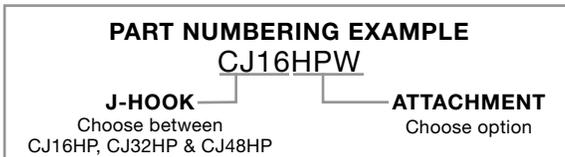

CJHP Series Plastic J-Hooks Ordering Information

CJ16HP					
	PKG QTY	HOOK SIZE (In.)	DESCRIPTION	WEIGHT (Lbs.)	PG
CJ16HP	25	1"	Basic Plastic Coated JHook w/Latch	3	F000051
CJ16HPBL	25	1"	Basic Black Plastic Coated Jhook w/Latch	3	F000299
CJ16HPBU	25	1"	Basic Blue Plastic Coated Jhook w/Latch	3	F000300
CJ16HPRD	25	1"	Basic Red Plastic Coated Jhook w/Latch	3	F000301
CJ16HPAC	25	1"	Plastic Coated JHook w/Latch and 90°Angle Clip 1/4 rod	4	F000060
CJ16HPW*	25	1"	Plastic Coated Jhook w/Latch and Batwing Clip	4	F000059
CJ16HPAC6	25	1"	Plastic Coated JHook w/Latch and 90° Angle Clip 3/8 rod	4	F000302
CJ16HPHOK24	25	1"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	5	F000304
CJ16HPHOK58	25	1"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	6	F000305
CJ16HPACPBC	25	1"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	7	F000306
CJ16HPACSSBC	25	1"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	5	F000307
CJ16HPHOK24	25	1"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	4	F000308
CJ16HPHOK58	25	1"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	4	F000309
CJ16HPPBC	25	1"	Plastic Coated Jhook w/Latch and Screw on Beam Clip 1/2	6	F000310
CJ16HPSSBC	25	1"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	5	F000311

CJ32HP					
	PKG QTY	HOOK SIZE (In.)	DESCRIPTION	WEIGHT (Lbs.)	PG
CJ32HP	25	2"	Basic Plastic Coated JHook w/Latch	4	F000052
CJ32HPBL	25	2"	Basic Black Plastic Coated JHook w/Latch	4	F000312
CJ32HPBU	25	2"	Basic Blue Plastic Coated JHook w/Latch	4	F000313
CJ32HPRD	25	2"	Basic Red Plastic Coated JHook w/Latch	4	F000314
CJ32HPAC	25	2"	Plastic Coated JHook w/Latch and 90° Angle Clip 1/4 rod	5	F000062
CJ32HPW*	25	2"	Plastic Coated w/Latch JHook and Batwing Clip	5	F000061
CJ32HPAC6	25	2"	Plastic Coated Jhook w/Latch and 90° Angle Clip 3/8 rod	5	F000315
CJ32HPHOK24	25	2"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	6	F000317
CJ32HPHOK58	25	2"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	7	F000318
CJ32HPACPBC	25	2"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	8	F000319
CJ32HPACSSBC	25	2"	Plastic Coated Jhook w/Latch and Screw on Beam Clip 1/2	6	F000320
CJ32HPHOK24	25	2"	Plastic Coated JHook w/Latch and Knock on beam Clip 1/8 - 1/4	5	F000321
CJ32HPHOK58	25	2"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	5	F000322
CJ32HPPBC	25	2"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	7	F000323
CJ32HPSSBC	25	2"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	6	F000246

* Works with both 1/4 x 20 and 3/8 x 16 rod

CJHP Series Plastic J-Hooks Ordering Information

CJ48HP					
	PKG QTY	HOOK SIZE (In.)	DESCRIPTION	WEIGHT (Lbs.)	PG
CJ48HP	25	3"	Basic Plastic Coated Jhook w/Latch	9	F000053
CJ48HPBL	25	3"	Basic Black Plastic Coated Jhook w/Latch	9	F000324
CJ48HPBU	25	3"	Basic Blue Plastic Coated Jhook w/Latch	9	F000325
CJ48HPRD	25	3"	Basic Red Plastic Coated Jhook w/Latch	9	F000326
CJ48HPAC	25	3"	Plastic Coated JHook w/Latch and 90° Angle Clip 1/4 rod	10	F000064
CJ48HPW*	25	3"	Plastic Coated Jhook w/Latch and Batwing Clip	10	F000063
CJ48HPAC6	25	3"	Plastic Coated JHook w/Latch and 90° Angle Clip 3/8 rod	10	F000327
CJ48HPHOK24	25	3"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	12	F000329
CJ48HPHOK58	25	3"	Plastic Coated Jhook w/Latch and Knock on Beam Clip 5/16 - 1/2	12	F000330
CJ48HPACPBC	25	3"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	13	F000331
CJ48HPACSSBC	25	3"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	12	F000332
CJ48HPHOK24	25	3"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	11	F000333
CJ48HPHOK58	25	3"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	10	F000334
CJ48HPPBC	25	3"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	12	F000335
CJ48HPSSBC	25	3"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	11	F000336

CJ64HP					
	PKG QTY	HOOK SIZE (In.)	DESCRIPTION	WEIGHT (Lbs.)	PG
CJ64HP	25	4"	Basic Plastic Coated Jhook w/Latch	11	F000337
CJ64HPBL	25	4"	Basic Black Plastic Coated Jhook w/Latch	11	F000338
CJ64HPBU	25	4"	Basic Blue Plastic Coated Jhook w/Latch	11	F000339
CJ64HPRD	25	4"	Basic Red Plastic Coated Jhook w/Latch	11	F000340
CJ64HPAC	25	4"	Plastic Coated JHook w/Latch and 90° Angle Clip 1/4 rod	12	F000341
CJ64HPW*	25	4"	Plastic Coated Jhook w/Latch and Batwing clip	12	F000342
CJ64HPAC6	25	4"	Plastic Coated JHook w/Latch and 90° Angle Clip 3/8 rod	12	F000343
CJ64HPHOK24	25	4"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	13	F000345
CJ64HPHOK58	25	4"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	14	F000346
CJ64HPACPBC	25	4"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	15	F000347
CJ64HPACSSBC	25	4"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	13	F000348
CJ64HPHOK24	25	4"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	12	F000349
CJ64HPHOK58	25	4"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	12	F000350
CJ64HPPBC	25	4"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	14	F000351
CJ64HPSSBC	25	4"	Plastic Coated Jhook w/Latch and Screw on Beam Clip 1/2	12	F000352

* Works with both 1/4 x 20 and 3/8 x 16 rod

BRIDLE RINGS

Bridle rings are a simple option for smaller bundles of communication or data cabling.

	PKG QTY	RING SIZE (IN)	DESCRIPTION	WEIGHT (LBS)	EZ
CJ4T125	100	1 ¼	Bridle Ring ¼ x 20	6	F000042
CJ4T2	100	2	Bridle Ring ¼ x 20	9	F000043



J-Hooks Attachments Ordering Information


Use these attachment options to create your own custom J-Hook combinations. Sold in quantities of 100.

CJ Attachment Mounting Hardware			
 CJ24	 CJ58	 CJFMP	 CJBC
Knock-on steel beam clamp – 1/8" to 1/4"	Knock-on steel beam clamp – 5/16" to 1/2"	Knock-on spring steel beam clamp – 1/8" to 1/2"	Pressed beam clamp – up to 1/2"
 CJSSBC	 CJZ14	 CJC14	 CJBW
Spring steel beam clamp 1/8" – 1/2"	1/8" – 1/4" Z Purlin	1/8" – 1/4" C Purlin	Bat wing 12 gage – 1/4" & 3/8" ATR

Field Creation of J-Hook Trees

Use J-Hook extension bracket to create your own custom J-Hook trees.

Catalog No./Item	Description/Specifications
CJHEB	Wide Style J-Hook Extension Bracket

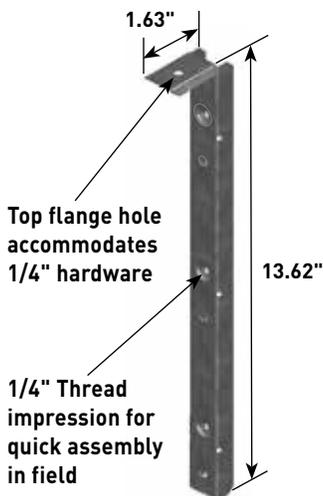

Features

- Allows for field creation of custom J-Hook Trees of any of the four (4) sizes available up to three (3) tiers
- Single side or back-to-back
- Sold as each
- Complies with NEC & meets TIA568-C & 569-C



CJHEB Bracket shown with 3 tiers of CJ32H's.

Factory Assembled J-Hooks with Retainer Clips Trees Ordering Information

J-Hook Trees are the ideal solution for segregating up to five runs of cable following the same cable pathway. They are ready to use with no assembly required in multiple sizes and attachment methods.


These items are not stocked in our inventory. Please contact the manufacturer for shipping information, pricing and other configurations.



CJHEB Shown with 3 tiers of CJ32H's mounted back-to-back.

CJH TREES					
	HOOK COUNT	WEIGHT (LBS)		HOOK COUNT	WEIGHT (LBS)
1-5/16" VERTICAL TREE SUPPORTS			2" VERTICAL TREE SUPPORTS		
CJ21H-EB-2	2	1.4	CJ32H-EB-2	2	1.6
CJ21H-EB-3	3	2.4	CJ32H-EB-3	3	2.6
CJ21H-EB-4	4	3.4	CJ32H-EB-4	4	3.6
CJ21H-EB-5	5	3.9	CJ32H-EB-5	5	4.1
w/ ANGLE CLIP			w/ ANGLE CLIP		
CJ21H-AC-EB-2	2	1.4	CJ32H-AC-EB-2	2	1.6
CJ21H-AC-EB-3	3	2.4	CJ32H-AC-EB-3	3	2.6
CJ21H-AC-EB-4	4	3.4	CJ32H-AC-EB-4	4	3.6
CJ21H-AC-EB-5	5	3.9	CJ32H-AC-EB-5	5	4.1
w/ BEAM CLAMP			w/ BEAM CLAMP		
CJ21H-PBC-EB-2	2	1.9	CJ32H-PBC-EB-2	2	2.1
CJ21H-PBC-EB-3	3	2.4	CJ32H-PBC-EB-3	3	2.6
CJ21H-PBC-EB-4	4	3.4	CJ32H-PBC-EB-4	4	3.6
CJ21H-PBC-EB-5	5	4.4	CJ32H-PBC-EB-5	5	4.6
4" VERTICAL TREE SUPPORTS			4" VERTICAL TREE SUPPORTS		
CJ64H-EB-2	2	1.5	CJ64H-EB-2	2	1.5
CJ64H-EB-3	3	2.2	CJ64H-EB-3	3	2.2
CJ64H-EB-4	4	-	CJ64H-EB-4	4	-
CJ64H-EB-5	5	3.6	CJ64H-EB-5	5	3.6
w/ ANGLE CLIP			w/ ANGLE CLIP		
CJ64H-AC-EB-2	2	2	CJ64H-AC-EB-2	2	2
CJ64H-AC-EB-3	3	3	CJ64H-AC-EB-3	3	3
CJ64H-AC-EB-4	4	4	CJ64H-AC-EB-4	4	4
CJ64H-AC-EB-5	5	4.5	CJ64H-AC-EB-5	5	4.5
w/ BEAM CLAMP			w/ BEAM CLAMP		
CJ64H-PBC-EB-2	2	2.5	CJ64H-PBC-EB-2	2	2.5
CJ64H-PBC-EB-3	3	3	CJ64H-PBC-EB-3	3	3
CJ64H-PBC-EB-4	4	4	CJ64H-PBC-EB-4	4	4
CJ64H-PBC-EB-5	5	5	CJ64H-PBC-EB-5	5	5

CJHP TREES					
	HOOK COUNT	WEIGHT (LBS)		HOOK COUNT	WEIGHT (LBS)
1" VERTICAL TREE SUPPORTS WITH PLASTIC COATED HOOKS			2" VERTICAL TREE SUPPORTS WITH PLASTIC COATED HOOKS		
CJ16HP-EB-2	2	1.4	CJ32HP-EB-2	2	1.6
CJ16HP-EB-3	3	2.4	CJ32HP-EB-3	3	2.6
CJ16HP-EB-4	4	3.4	CJ32HP-EB-4	4	3.6
CJ16HP-EB-5	5	3.9	CJ32HP-EB-5	5	4.1
W/ ANGLE CLIP			W/ ANGLE CLIP		
CJ16HP-AC-EB-2	2	1.4	CJ32HP-AC-EB-2	2	1.6
CJ16HP-AC-EB-3	3	2.4	CJ32HP-AC-EB-3	3	2.6
CJ16HP-AC-EB-4	4	3.4	CJ32HP-AC-EB-4	4	3.6
CJ16HP-AC-EB-5	5	3.9	CJ32HP-AC-EB-5	5	4.1
W/ BEAM CLAMP			W/ BEAM CLAMP		
CJ16HP-PBC-EB-2	2	1.9	CJ32HP-PBC-EB-2	2	2.1
CJ16HP-PBC-EB-3	3	2.4	CJ32HP-PBC-EB-3	3	2.6
CJ16HP-PBC-EB-4	4	3.4	CJ32HP-PBC-EB-4	4	3.6
CJ16HP-PBC-EB-5	5	4.4	CJ32HP-PBC-EB-5	5	4.6
3" VERTICAL TREE SUPPORTS WITH PLASTIC COATED HOOKS			3" VERTICAL TREE SUPPORTS WITH PLASTIC COATED HOOKS		
CJ48HP-EB-2	2	2	CJ48HP-EB-2	2	2
CJ48HP-EB-3	3	2	CJ48HP-EB-3	3	2
CJ48HP-EB-4	4	4	CJ48HP-EB-4	4	4
CJ48HP-EB-5	5	4	CJ48HP-EB-5	5	4
W/ ANGLE CLIP			W/ ANGLE CLIP		
CJ48HP-AC-EB-2	2	2	CJ48HP-AC-EB-2	2	2
CJ48HP-AC-EB-3	3	3	CJ48HP-AC-EB-3	3	3
CJ48HP-AC-EB-4	4	4	CJ48HP-AC-EB-4	4	4
CJ48HP-AC-EB-5	5	4	CJ48HP-AC-EB-5	5	4
W/ BEAM CLAMP			W/ BEAM CLAMP		
CJ48HP-PBC-EB-2	2	2	CJ48HP-PBC-EB-2	2	2
CJ48HP-PBC-EB-3	3	3	CJ48HP-PBC-EB-3	3	3
CJ48HP-PBC-EB-4	4	4	CJ48HP-PBC-EB-4	4	4
CJ48HP-PBC-EB-5	5	4	CJ48HP-PBC-EB-5	5	4

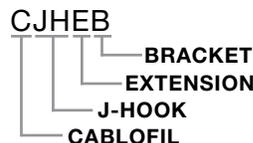

NOTE: All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



NOTE: The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act complaint. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.



Legrand, North America
60 Woodlawn Street
West Hartford, CT 06110
1.877.BY.LEGRAND (295.3472)
www.legrand.us

Canada
905.738.9195
www.legrand.ca

FOLLOW US

