




CHANNEL SYSTEM


Channel Tray

CCV


Vented Cable Channel, Straight

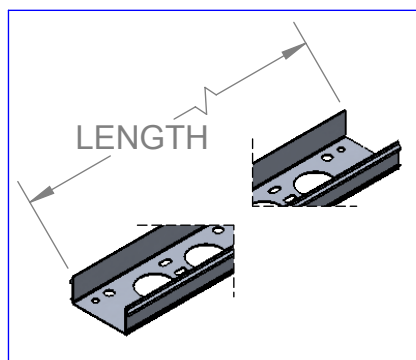

4"

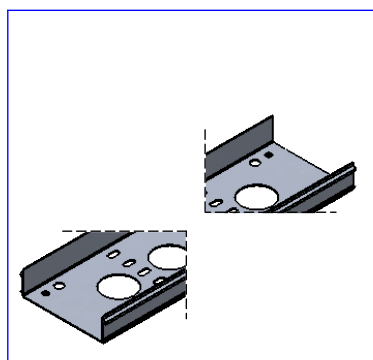


6"

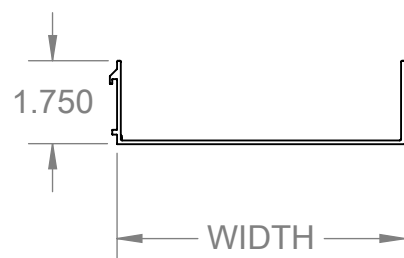

- **Material:** Aluminum Alloy 6063-T6
- **Depth:** 1.75" (Nominal)
- **Finish:** Plain
- **Bottom:** CCV: Vented
- **Construction:** Aluminum Extrusion
- **Cable Channel Design:** Cable Channel construction and markings are per the latest edition of NEMA Standards Publication VE1, CSA C22.2 No. 126.
- **Cable Channel Grounding Capability:** Classified as an equipment grounding conductor per NEC 392.60 with a maximum ampere rating: UL Cross Sectional area:
 - 4" = 0.657 in² (UL: .60 = 1000A)
 - 6" = 0.817 in² (UL: .60 = 1000A)
- **Mechanical Properties:**
 - 4": Ix-x = 0.145 in⁴, Sx-x = 0.114 in³
 - 6": Ix-x = 0.163 in⁴, Sx-x = 0.119 in³

MATERIAL	WIDTH(IN)	CHANNEL WEIGHT (LBS/FT)
A	4	0.571
A	6	0.708

CATALOG NUMBERING EXAMPLE:

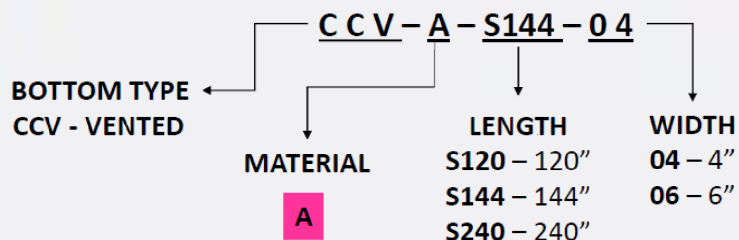

"Copyright LNA, Inc. Drawings are proprietary and may not be copied or otherwise duplicated or used without express written permission."

CABCS0576



Legrand
8319 State Rt. 4
Mascoutah, IL 62258 USA
800-658-4641
618-566-3250
Fax 618-566-4978
www.legrand.us/cablofil