



- LINE INTERACTIVE, SINGLE PHASE, 120V, 1.1kVA, 0.99 kW
- INPUT TYPE: NEMA 5-15P, CORD
- OUTPUT TYPE: (8) NEMA 5-15R
- DISCHARGE TIME:
 - 100% LOAD 3.0 min.
 - 75% LOAD 5.3 min.
 - 50% LOAD 10.2 min.
 - 25% LOAD 25.0 min.

- WEIGHT 29.5 lbs.
- COLOR BLACK

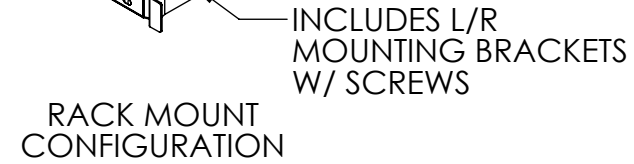

- ALSO INCLUDED:
- (1) USB CABLE 5'
 - (1) MANUAL

<p>*** NOTICE ***</p> <p>THIS DOCUMENT CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION INTENDED FOR USE ONLY BY THE INDIVIDUAL(S) PROVIDED. NEITHER THIS DOCUMENT, NOR ANY INFORMATION CONTAINED HEREIN, MAY BE COPIED, DISTRIBUTED, DISCLOSED TO ANY THIRD PARTY OR USED IN ANY MANNER OTHER THAN FOR WHICH IT HAS BEEN PROVIDED, WITHOUT THE PRIOR WRITTEN CONSENT OF LEGRAND</p>		 <p>WWW.LEGRAND.US</p>	
		<p>TITLE</p> <p>LEGRAND UPS LINE INTERACTIVE 1100VA, 120V, 50-60HZ</p>	
	NAME	DATE	
DWN	MM	3/6/2019	
CHK	RJG	3/7/2019	
APPR			
SIZE		CAD FILE	DWG NO
B		LU1100RTL	REV
SCALE		1:4	SHEET
			1 OF 1