



- ELECTRICAL PARAMETERS:**
- DOUBLE-CONVERSION ONLINE, SINGLE-PHASE, 120V, 2.0kVA, 2.0kW
 - INPUT TYPE: NEMA 5-20P, 6.0' CORD
 - OUTPUT TYPE: (8) NEMA 5-20R
 - DISCHARGE TIME:
 - 100% LOAD 3.0 min.
 - 75% LOAD 5.0 min.
 - 50% LOAD 9.9 min.
 - 25% LOAD 25.8 min.

- MECHANICAL PARAMETERS:**
- WEIGHT 43.0 lbs.
 - COLOR BLACK

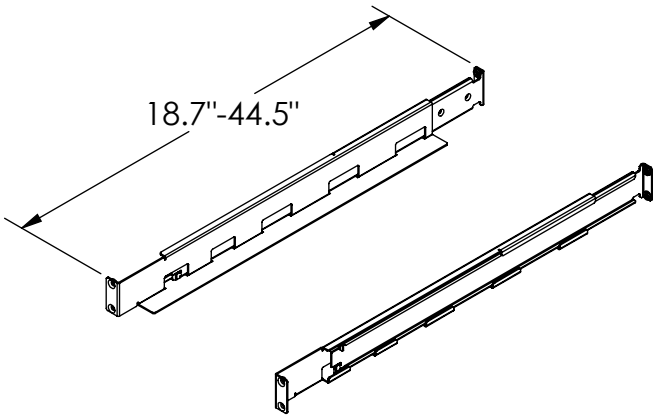


LU-4PKIT-2U 4POST RAIL KIT, 2U

- (12) M6 RACK SCREWS
- (6) M6 CAGE NUTS

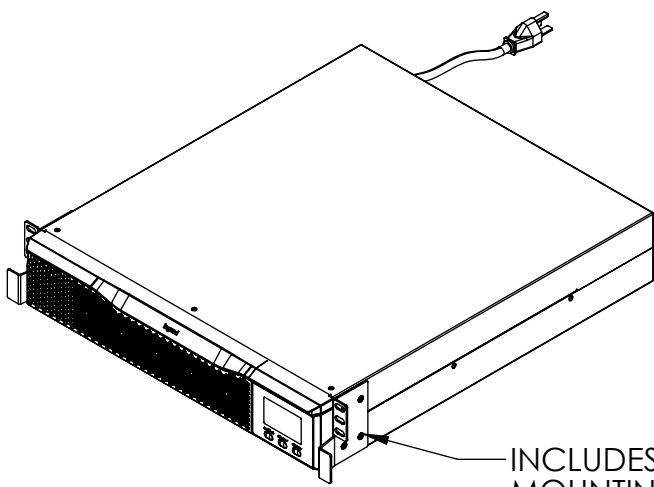




RACK MOUNT CONFIGURATION

INCLUDES L/R MOUNTING BRACKETS W/ SCREWS

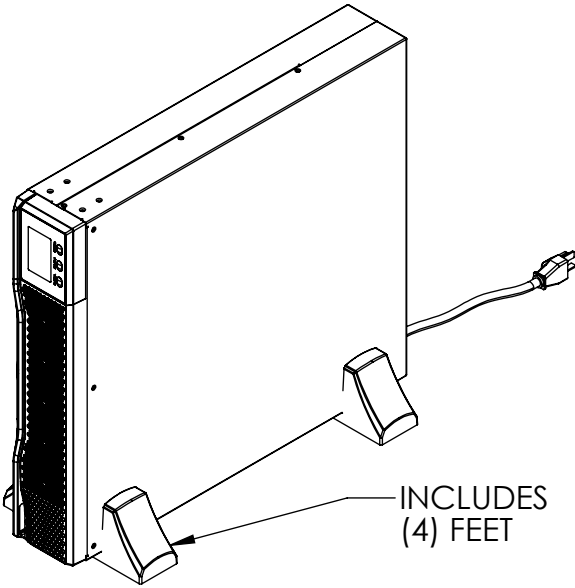


TOWER CONFIGURATION

INCLUDES (4) FEET

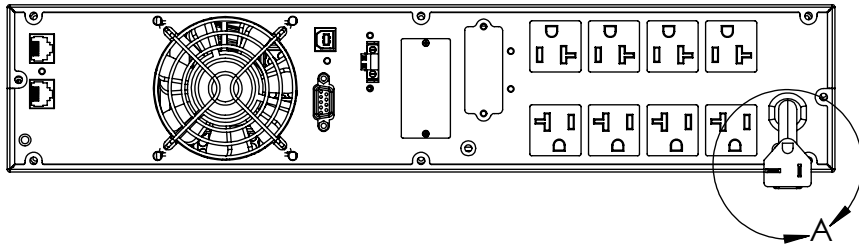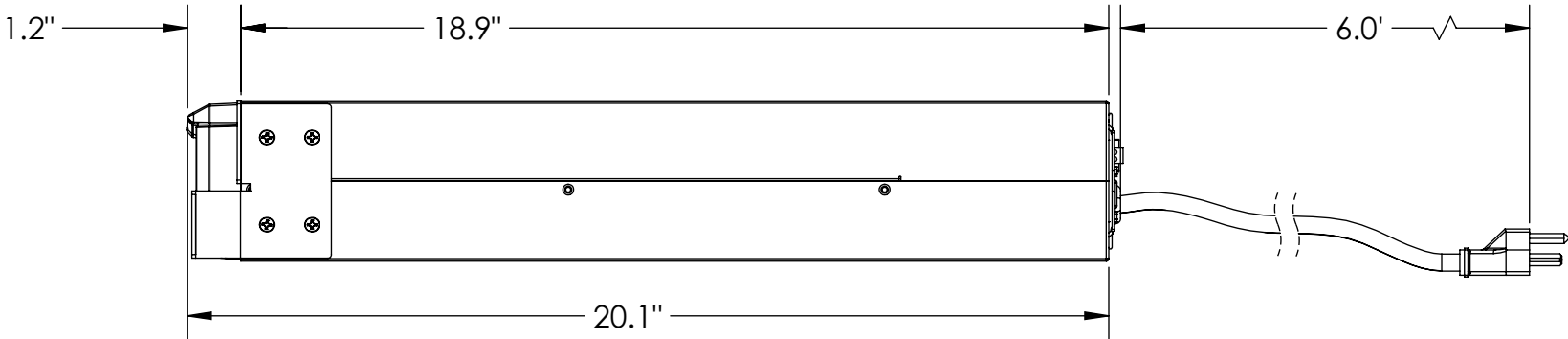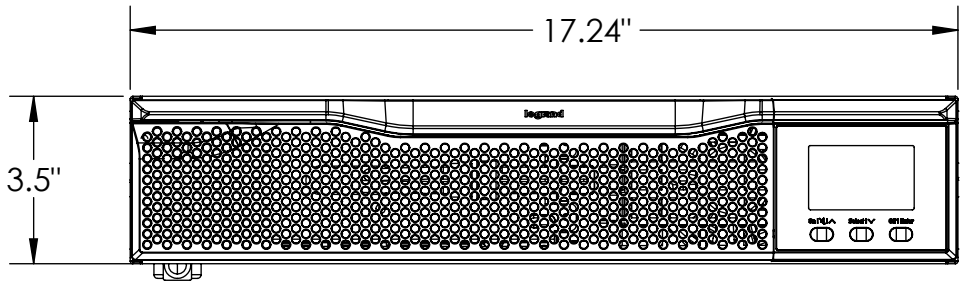

- ALSO INCLUDED:**
- (1) USB CABLE 5.0'
 - (1) MANUAL

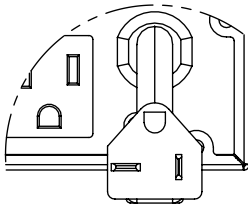

DETAIL A
NEMA 5-20P
SCALE 1 : 2

*** NOTICE ***
THIS DOCUMENT CONTAINS
CONFIDENTIAL AND/OR PROPRIETARY
INFORMATION INTENDED FOR USE ONLY
BY THE INDIVIDUAL(S) PROVIDED.
NEITHER THIS DOCUMENT, NOR ANY
INFORMATION CONTAINED HEREIN, MAY
BE COPIED, DISTRIBUTED, DISCLOSED TO
ANY THIRD PARTY OR USED IN ANY
MANNER OTHER THAN FOR WHICH IT HAS
BEEN PROVIDED, WITHOUT THE PRIOR
WRITTEN CONSENT OF LEGRAND

	NAME	DATE
DWN	MM	3/6/2019
CHK	RJG	3/7/2019
APPR	CV	3/18/2019



WWW.LEGRAND.US

TITLE

LEGRAND UPS ONLINE 2000VA, 120V, 50-60HZ

SIZE B	CAD FILE LU2000RTC	DWG NO LU-2000-RT	REV 00
SCALE 1:4	SHEET 1 OF 1		