

2

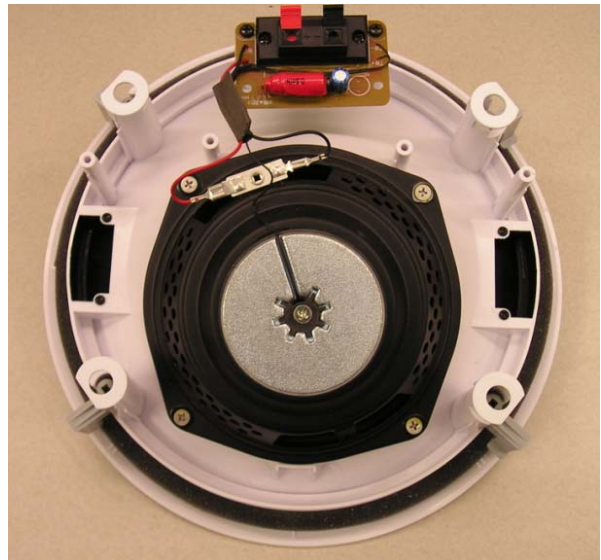
1

NOTES:

- 1. MOISTURE RATING: SUITABLE FOR MOISTURE RICH ENVIRONMENTS
- 2. EFFICIENCY: 90 db
- 3. IMPEDANCE: 8 ohm
- 4. FREQUENCY RESPONSE: 60-20KHz
- 5. WOOFER TYPE: BLUE POLY
- 6. TWEETER TYPE: 1" UFLC DOME
- 7. POWER RMS/PEAK: 75W/150W
- 8. PAINTABLE SPEAKER GRILL INCLUDED



B

B



A

A

PROPRIETARY AND CONFIDENTIAL THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF On-Q/LEGRAND. ANY REPRODUCTION IN PART OR AS A WHOLE WITHOUT THE WRITTEN PERMISSION OF On-Q/LEGRAND IS PROHIBITED. DRAWING IS SUBJECT TO CHANGE WITHOUT NOTICE.	  P.O. Box 60907 Middletown, PA 17106-0907 1-800-321-2343		TITLE: evoQ 5000 6.5" ANGLED IN-CEILING SPEAKER		
	SIZE A	DWG NO HT5655	FILE NAME CD-HT5655	CUST REV 1	
	REVISED DATE 11/14/07	SCALE NONE	SHEET 1 OF 1		

2

1