

**OnQ AnyPort®
Audio Binding
Post Insert**



OnQ Technologies, Inc.
P.O. Box 60907
Harrisburg, PA 17106-0907
www.onqtech.com

IS-0107 Rev. O
Ref. P/N 100225-07




COMMUNICATION
CIRCUIT
ACCESSORY 73HM


OnQ AnyPort® Audio Binding Post Inserts provide connectivity to audio services.

INSTALLATION



1. Strip off approximately 3/8" of insulation from wire conductor.

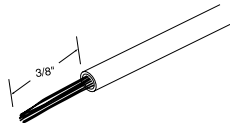

2. Using a small screwdriver, back out the small set screw on the rear of the binding post. Insert the stripped wire into the rear opening of the binding post. Tighten the set screw so wire is secure.

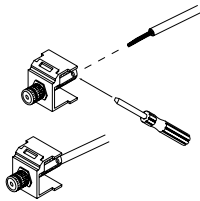


3. Insert binding post into an AnyPort designer outlet, decorator outlet or Hide-A-Port outlet.
NOTE: Inserts used in the AnyPort decorator outlets must be rotated 90° for proper insertion.

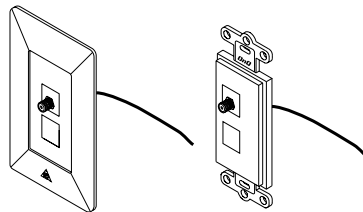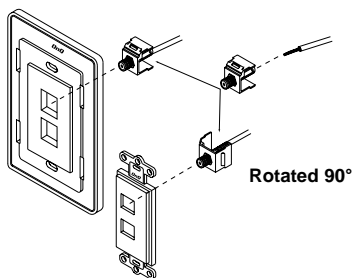

INSTALLATION TO THE "FRONT" OF THE BINDING POST

1. To make a connection to the front of the binding post, strip off approximately 1/2 to 3/4" of insulation from wire conductor.

Unscrew the front binding nut. Insert the wire conductor into the hole on the binding post barrel. Screw front binding nut back in place until wire is secure.

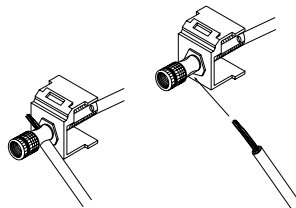

2. If you are using a banana plug connector on the front of the binding post, simply "plug" the banana plug connector straight into the front of the binding post.

