

**ORTRONICS®**125 EUGENE O'NEILL DRIVE
NEW LONDON, CT 06320
TEL: 860-445-3800
FAX: 860-405-2990




TITLE: OR-63760030 45° TRACJACK 8P8C 568A/B

INSTRUCTION
SHEET #: 71601069

REVISION: 02

DATE: 01/20/03

SIDE 1 of 2

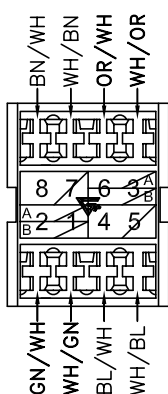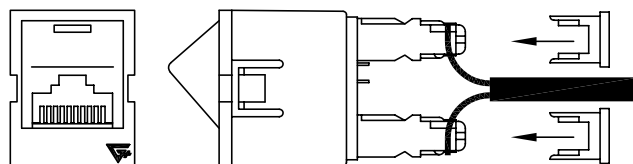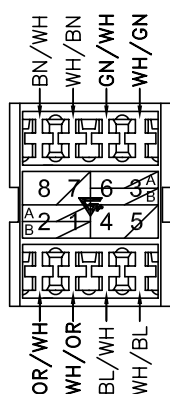
CAUTION: TERMINATE TRACJACKS PER SPECIFIED
WIRING SYSTEM 'T568A' or 'T568B'.**568A
8P8C****568B
8P8C**

NOTE: When terminating cables to TracJacks, lace wires from the center to the outside of the module. Install stuffer caps after terminating cable.


'This device is intended for indoor use on communication loop circuit which have been isolated from the Public Switched Telephone Network'

WIRING CHART


110D-2 INSERT COLOR CODE	RJ45 8P8C T568A WIRING	RJ45 8P8C T568B WIRING
WHITE/BLUE	5	5
BLUE/WHITE	4	4
WHITE/ORANGE	3	1
ORANGE/WHITE	6	2
WHITE/GREEN	1	3
GREEN/WHITE	2	6
WHITE/BROWN	7	7
BROWN/WHITE	8	8

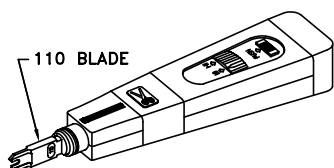

REQUIRED TERMINATION TOOL
OR-60300005 (TOOL & BLADE)
OR-60300006 (BLADE ONLY)

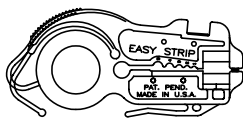



RECOMMENDED
STRIPPING TOOL
OR-60300032 (TOOL)

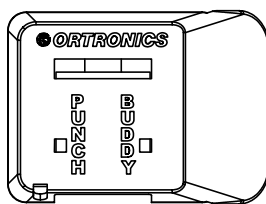

PUNCH BUDDY, TracJack holder
supplied with full cartons of
TracJacks or under part #
TJPB5PK (5 pack)

TracJack Module Termination

- STEP 1: Feed station cables through faceplate. Mount faceplate to wall without modules installed.
- STEP 2: Strip 2" of cable jacket off station cables.
- STEP 3: Load TracJack as shown below, by sliding into accepting groove on Punch Buddy, until fully seated.
Do not load TracJack from the top, this may damage TracJack or Punch Buddy.
- STEP 4: Lace color coded wire pairs into 110 termination.
- STEP 5: Place Punch Buddy on solid flat surface, then using a single wire 110 tool terminate all 4 pairs. (see diagram below)
- STEP 6: Repeat steps 3 thru 5 until all TracJack Modules are terminated.
- STEP 7: Snap TracJack module into faceplate,
or set TracJack module into base of surface mount box.

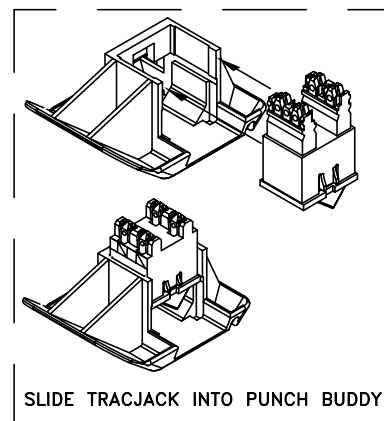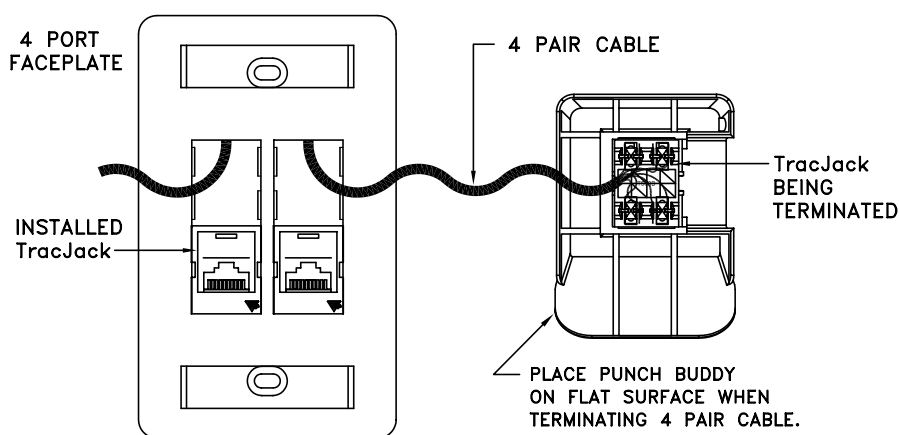

SLIDE TRACJACK INTO PUNCH BUDDY

SIDE 2 of 2