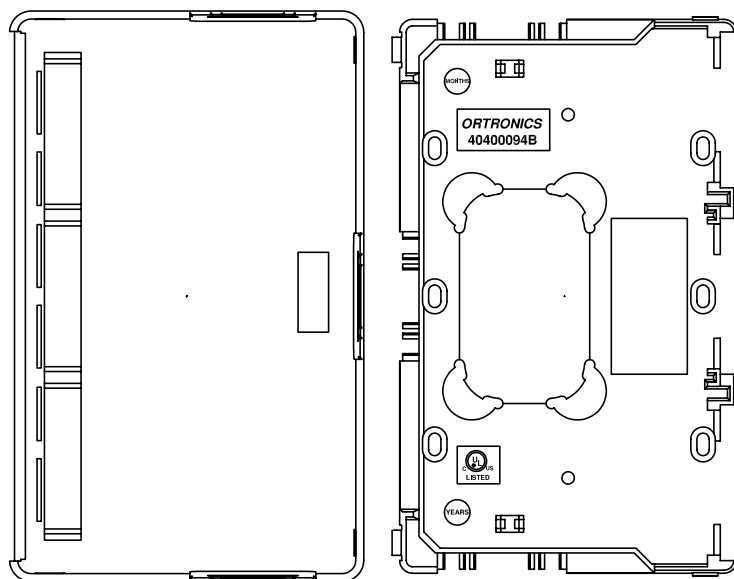



**ORTRONICS®**125 EUGENE O'NEILL DRIVE
NEW LONDON, CT 06320
TEL: 860-445-3800
FAX: 860-405-2990

TITLE

Series II 2 & 3 PORT SMB KITS
OR-404S22U & OR-404S23U

COVER

BASE


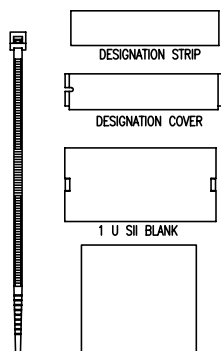


INSTR: SERIES II SMB 2/3 PORT

#6-20 X 3/4" SCREW
#6-32 X 1" SCREW


OR-404S23U

QTY	DESCRIPTION
1	BASE SERIES II, 3 PORT, SMB
1	SMB COVER, COMBO SERIES II, 3 PORT/6 PORT TJ
3	DESG COVER IMO
3	DESG STRIP, PAPER, WHITE
4	SCREW #6-20 X 3/4", PAN HEAD
4	SCREW #6-20 X 1", BINDING HEAD
2	1 U SII BLANK
1	BAG, 9" X 10.5", ORTRONICS LOGO
1	INSTR: SERIES II SMB 2/3 PORT
2	4" CABLE TIE

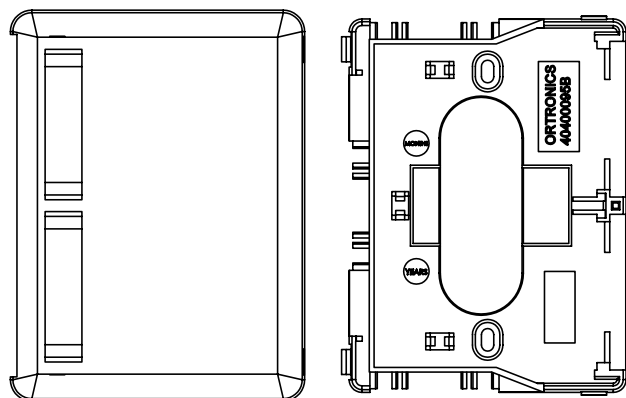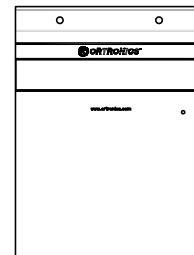

COVER

BASE

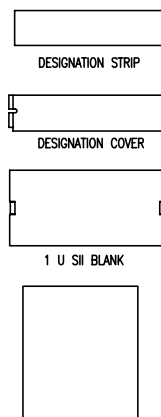


INSTR: SERIES II SMB 2/3 PORT

#6-20 X 3/4" SCREW
#6-32 X 1" SCREW



OR-404S22U

QTY	DESCRIPTION
1	BASE, 2 PORT SII
1	COVER, COMBO, 2 PORT
2	DESG COVER FOR IMO
2	DESG STRIP, PAPER, WHITE
2	SCREW #6-20 X 3/4", PAN HEAD
2	SCREW #6-32 X 1", BINDING HEAD
1	BLANK, SII, 180 DEG
1	BAG 9" X 10.5" ORTRONICS LOGO
1	INSTR SHEET SII 2 & 3 PORT SMB
3	4" CABLE TIE

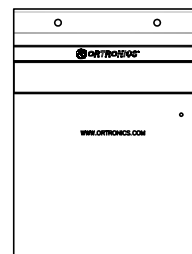

MOUNTING INSTRUCTIONS: The 4040S23U box can be mounted directly to a recessed single or dual gang electrical box using the two or four 6-32 x 1" screws, or fastened to the wall using the #6 X 3/4" screws. The 404S22U box can be mounted directly to a single gang electrical box or fastened to the wall using same screws as 4040S23U box. For both boxes if the Wiremold 2700, 2800, 2900 raceway is being utilized (you need to cut the alignment guides on the base of the box.) (fig 1) Cutout corresponding knockout's in the 404S2's covers

Fig. 1

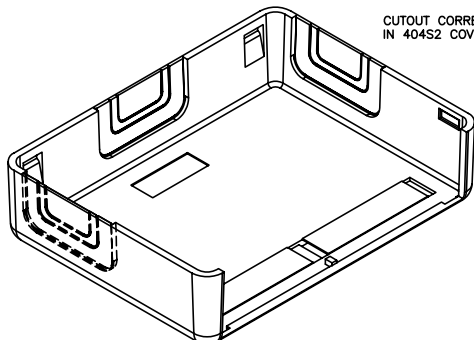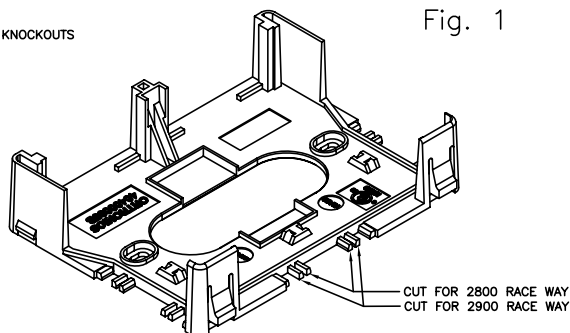CUTOUT CORRESPONDING KNOCKOUTS
IN 404S2 COVERSCUT FOR 2800 RACE WAY
CUT FOR 2900 RACE WAY


INSTRUCTION SHEET #	REV.	ECN #	SHEET	DWN.BY:	DATE	CHK.BY:	DATE	APP.BY:	DATE
71601497	00		1 of 2	L.FIGUEROA	05/29/07	C.A.C.	09/07/07	M.E.M.	09/07/07

**ORTRONICS**

125 EUGENE O'NEILL DRIVE
NEW LONDON, CT 06320
TEL: 860-445-3800
FAX: 860-405-2990

TITLE

TRACJACK 2 & 3 PORT SMB KITS OR-404S22U & OR-404S23U

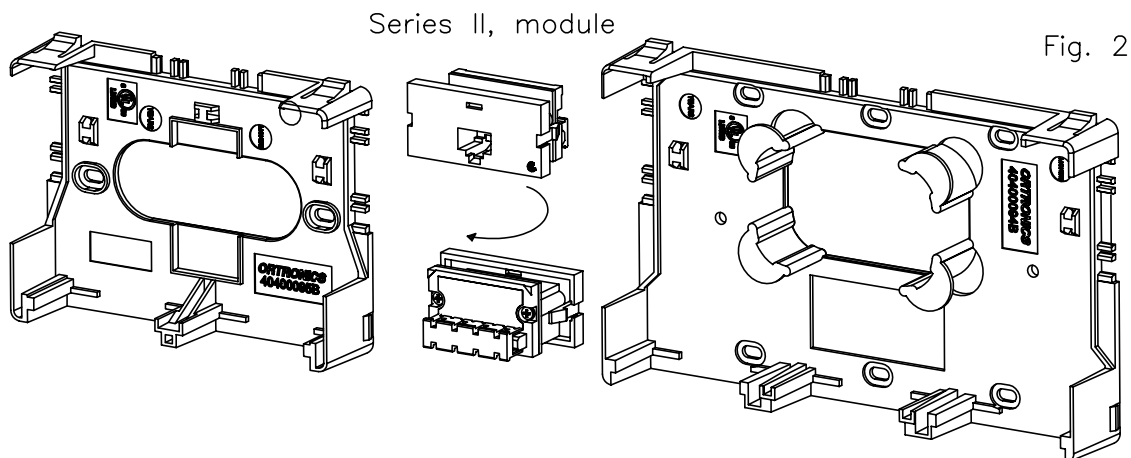


Bring cables into base thru raceway openings, or thru opening in center of base.

Series II TERMINATION:


Refer to Series II module instruction sheet (71601234) for complete cable termination instructions.

FIBER TERMINATION:

Ortronics recommends using the outside position on the 404S23U box for fiber when installing Fiber and Copper together. Terminate the fiber cable as recommended by the connector manufacturers specifications. The 404S23U box has a fiber ring for fiber optic cable management. After connector termination carefully route the Fiber around the ring to maintain the pertinent bend radius. The box will support 1 meter of stored fiber per connector.

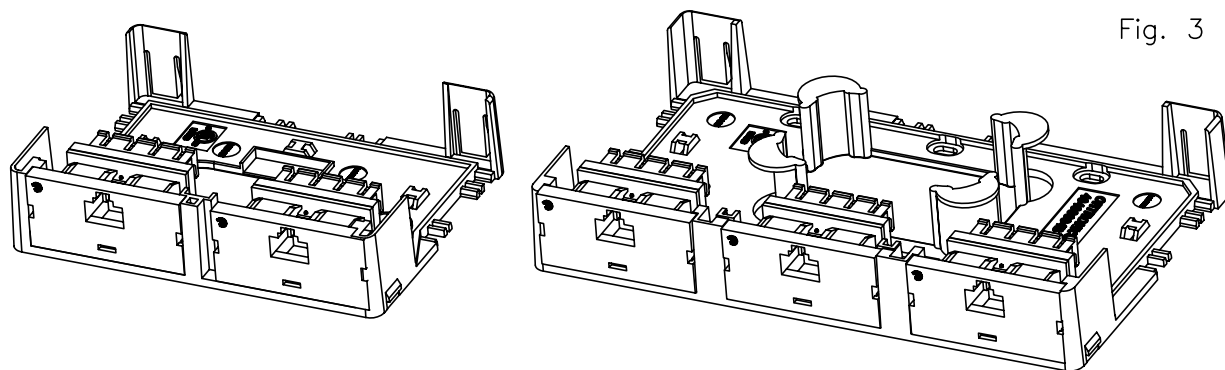

To remove the cover, release latches by applying pressure to the lower corners,

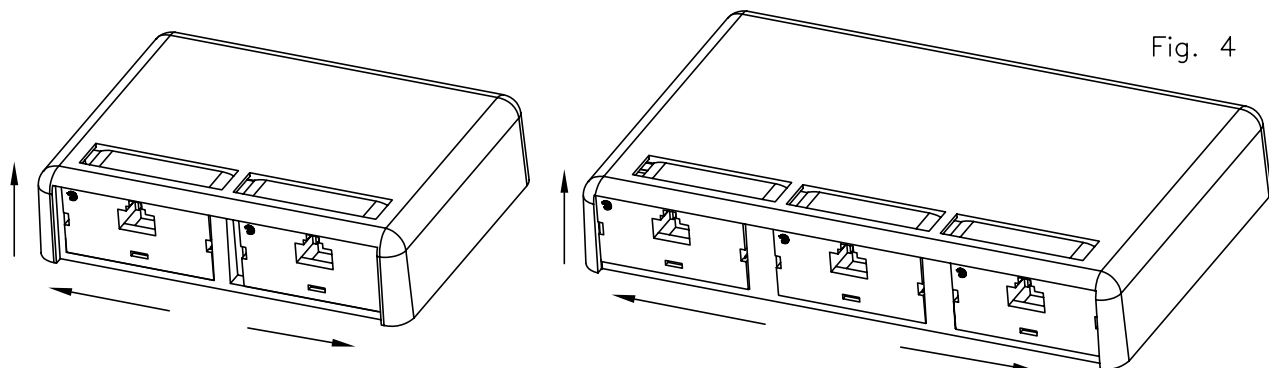

INSTRUCTION SHEET #	REV.	ECN #	SHEET	DWN.BY:	DATE	CHK.BY:	DATE	APP.BY:	DATE
71601497	00		2 of 2	L.FIGUEROA	05/29/07	C.A.C.	09/07/07	M.E.M.	09/07/07