


# DATA SHEET

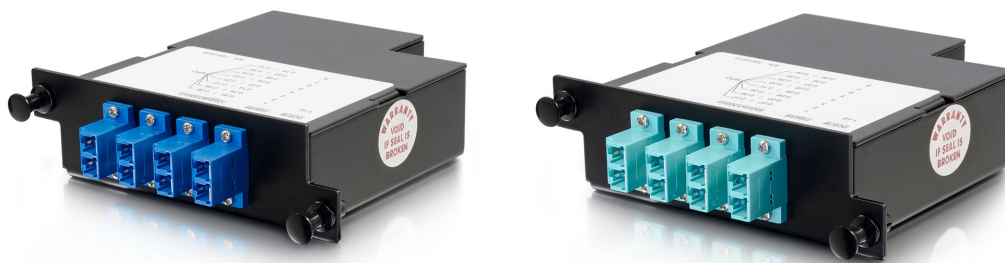

## 8-Fiber M4 Cassettes with 8 LC Duplex Adapters to 1 MPO (F)

Infinium high density pre-terminated M4 fiber optic cassettes designed to breakout rear MPO connections to front 8-fiber LC duplex adapters.

### OVERVIEW

The 8-fiber M4 Cassettes are designed to be used with the Infinium HD Enclosures and support MPO to LC Duplex 8-fiber connectivity, offering versatile installation and swift deployment. The housing of the cassettes offer additional durability and integrated bend limiting considerations to assure optimum optical performance. The Base 8 configuration of these cassettes match the fiber utilization of most transceivers, providing for 100% fiber utilization. This makes these cassettes a perfect match for Ethernet transmission ranging from 40G to 400G.

### FEATURES

- High Density: 8-fiber cassette compatible with Infinium HD Enclosures
- Base 8 Configuration: Provides 100% fiber utilization for most transceivers
- Pre-terminated solution: For fastest installation, highest performance and consistent factory quality
- Fiber port labeling: Provides easier administration
- Compact high density design: Made with a rugged metal housing
- Internal Shutters: Eliminates the need for protective caps and keeps dust out

### ITEM DESCRIPTION

M4LCD08-50EE3G2	8-Fiber OM4 M4 Cassette with 8 LC Duplex Adapters to 1 MPO (F), Tier 3, Universal Polarity - Aqua
M4LCD08-50EE1G1	8-Fiber OM4 M4 Cassette with 8 LC Duplex Adapters to 1 MPO (F), Tier 1, Universal Polarity - Aqua
M4LCD08-09E1G1	8-Fiber OS2 M4 Cassette with 8 LC Duplex Adapters to 1 MPO (F), Tier 1, Universal Polarity - Blue

### AGENCIES/THIRD PARTY CERTIFICATIONS

- RoHS: Yes

designed to be better.™



# DATA SHEET

## SPECIFICATIONS:

8-Fiber M4 Cassettes with 8 LC Duplex Adapters to 1 MPO (F)

### GENERAL INFO:


- Color: M4LCD08-50EE3G2 - Aqua  
M4LCD08-50EE1G1 - Aqua  
M4LCD08-09E1G1 - Blue
- Number Of Ports: 8
- Typical Applications:
  - M4LCD08-50EE3G2 - Multimode
  - M4LCD08-50EE1G1 - Multimode
  - M4LCD08-09E1G1 - Single-mode
- Connection Type: MPO-LC
- Installation Destination: UC0 Fiber Enclosures
- Product Series: Infinium
- Type: Fiber Cassettes

### DIMENSIONS:

- Depth (Metric): 103.12 mm
- Depth (US): 4.06"
- Height (Metric): 31.24 mm
- Height (US): 1.23"
- Width (Metric): 107.70 mm
- Width (US): 4.24"
- Rack Units: 0.7

### TECHNICAL INFORMATION:

- Connection Method:
  - M4LCD08-50EE3G2 - Universal Polarity (Flipped)
  - M4LCD08-50EE1G1 - Universal Polarity (Non-Flipped)
  - M4LCD08-09E1G1 - Universal Polarity (Non-Flipped)
- Fiber Capacity: 8
- Typical Insertion Loss:
  - M4LCD08-50EE3G2 - 0.5 dB
  - M4LCD08-50EE1G1 - 1.25 dB
  - M4LCD08-09E1G1 - 1.05 dB
- Typical Return Loss:
  - M4LCD08-50EE3G2 - 19.0 dB
  - M4LCD08-50EE1G1 - 19.0 dB
  - M4LCD08-09E1G1 - 52 dB
- Capacity: High Density
- Equipment Type: Pre-Terminated Cassettes

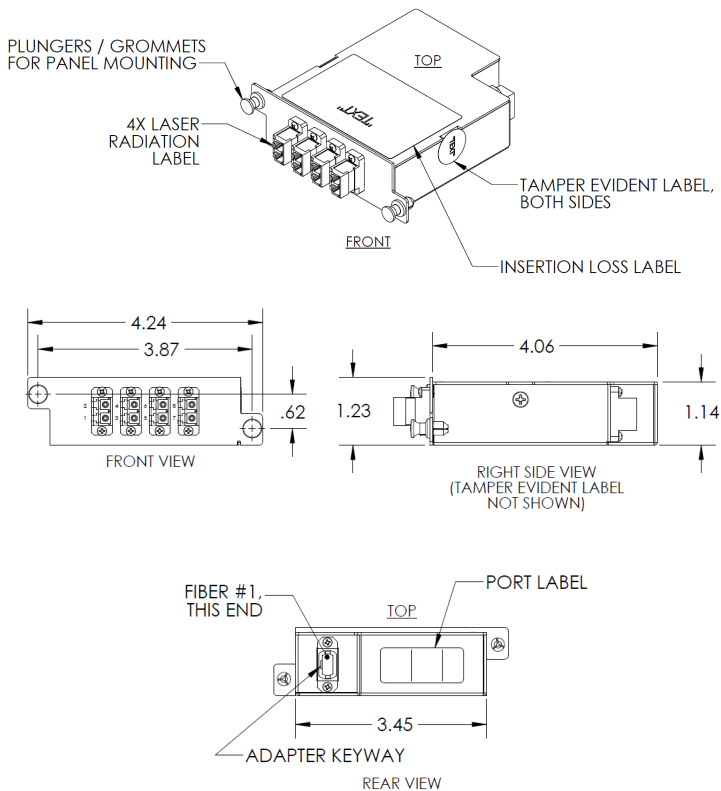

Legrand, North and Central America

60 Woodlawn Street  
West Hartford, CT 06110  
1.877.BY.LEGRAND (295.3472)  
www.legrand.us