



# PASS & SEYMOUR®

## Titan 0-10V Dimmer

### 0-10V LED & Fluorescent

## CD4FBL3P, CD4FBL

### A complete solution for easy, economical multi-gang installations

Multiple commercial controls in a ganged box? It's easy with P&S Titan Series: Superior quality, energy-efficient lighting control with a customizable multi-gang wall plate system and a high-end voltage adjustment feature. Includes an exclusive labeling system.

This complete product line offering features a rugged, more convenient, better-looking multi-gang installation.

The Titan 0-10V dimmers are the latest in the Titan line and provide an all in one solution for your 0-10V dimming needs. The dimmer comes in single pole slide to off as well as single pole/3-way in a preset.



## FEATURES & BENEFITS

**Included screwless wall plate components** make it easy to assemble a custom multi-gang wall plate in any configuration – saving money and time.


**Power-failure memory** retains presets through power outages.

**Preset models** feature large ON/OFF button and single pole/three-way functionality.

**High reliability design** with built-in surge and static protection plus oversize output devices to stand up to abuse.

**Higher wattage ratings and minimal or no derating** for faster job planning.

**Built-in label holder** enables instant circuit identification; looks clean and professional.

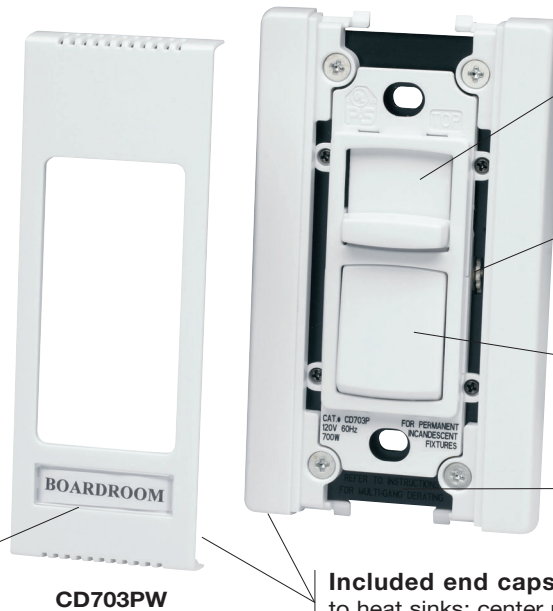

**Enclosed slider** helps prevent dust and dirt contamination.

**Exclusive adjustable limit control in incandescent dimmers** saves energy and extends lamp life – reduces maximum output by up to 10 percent.

**Air gap switch**

**Improved heat management** enables superior load ratings.

**Included end caps and spacers** screw directly to heat sinks; center plate snaps easily on and off.

## FIELD USES / VERTICAL MARKETS

- Residential
- Health Care
- Education
- Light Commercial
- Retail/Office
- Hospitality/Lodging



# PASS & SEYMOUR®

## Titan 0-10V Dimmer 0-10V LED & Flourescent

### ORDERING INFORMATION

Catalog #	Description	Colors	Rating
CD4FBL3P*	4 Wire Single Pole/3-Way 0-10V Preset Dimmer with Integrated Power Pack	W, LA, I, BK, GRY, -	120V 10A/277V 5A 0-10VDC 30mA sink
CD4FBL*	4 Wire Single Pole 0-10V Dimmer with Integrated Power Pack, Non-Preset	W, LA, I, BK, GRY, -	120V 10A/277V 5A 0-10VDC 30mA sink

All devices are cULus Listed




#### \*Color Designation

I	Ivory	-	Brown	BK	Black
W	White	GRY	Gray	LA	Light Almond

#### Notes:

1. Replace \* with color designation (W-White, I-Ivory, LA-Light Almond, BK-Black, GRY-Gray, Blank-Brown).

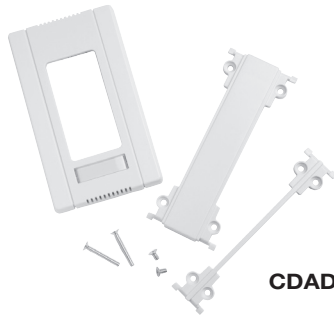

**Adaptor kit enables matching installation of standard P&S Decorator Devices** – outlets, switches, GFCIs and more.

CDADAPTORKIT

For more information on these and other P&S products refer to our Catalog or visit our web site.

# PASS & SEYMOUR®

## Titan 0-10V Dimmer

### 0-10V LED & Flourescent



#### TECHNICAL SPECIFICATIONS

#### 3rd Party Compliance

cULus Listed, UL1472, CSA-C22.2 No. 184.1-95.  
Conforms to NEMA WD-1 and WD-6, California Title 24 Compliant.



#### Performance

##### Electrical

Supply Voltage 120 VAC / 277VAC  
Maximum Rated Load 120V 10A / 277V 5A


Frequency 60 Hz  
Control 0-10VDC 30mA  
Installation Single Pole or 3-Way

##### Environment

Application Indoor Use Only

##### Mechanical

Back Body: Thermoplastic  
Front Body: Thermoplastic  
Wall Plate: Thermoplastic  
End Caps: Thermoplastic  
Spacers: Thermoplastic  
Heat Sink/Strap: Aluminum  
Screws: Plated Steel

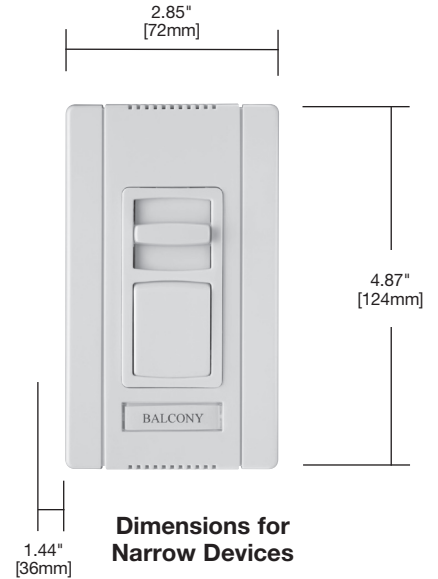

#### Warranty

Lifetime Warranty



**ALSO AVAILABLE...**

- Hospital Grade Devices
- Surge Protective & Isolated Ground Devices
- Bulk Solutions
- Ground Continuity Monitoring (GCM)
- Straight Blade Plugs & Connector
- USB Charging Devices
- Turnlok® Locking Devices
- Weatherproof Boxes & Covers
- IEC 309 Industrial Products
- Flexcor® Wire Mesh Grips



**Electrical Wiring Systems**

P.O. Box 4822  
Syracuse, NY 13221-4822  
Phone: 1.877.BY.LEGRAND (295-3472)  
[www.legrand.us](http://www.legrand.us)

570 Applewood Crescent  
Vaughan, Ontario L4K 4B4  
Phone: 905.738.9195  
[www.legrand.ca](http://www.legrand.ca)

