




Pass & Seymour

Weatherproof Boxes & Covers While-In-Use Covers Single, Shallow, Deep & Two Gang

WIUC10-L, WIUC10-S, WIUC10-DL, WIUC20-L

Innovative design in addition to the latest NEC requirements provides weather protection while-in-use.

Corner hinges allow versatile polycarbonate covers to be installed either vertically or horizontally. They provide generous interior room to accommodate bends in even the heaviest cords. They are lockable to prevent tampering, and deliver excellent weather resistance thanks to neoprene-blend gasketing, a cord flap seal and our exclusive WaterShed™ channel.

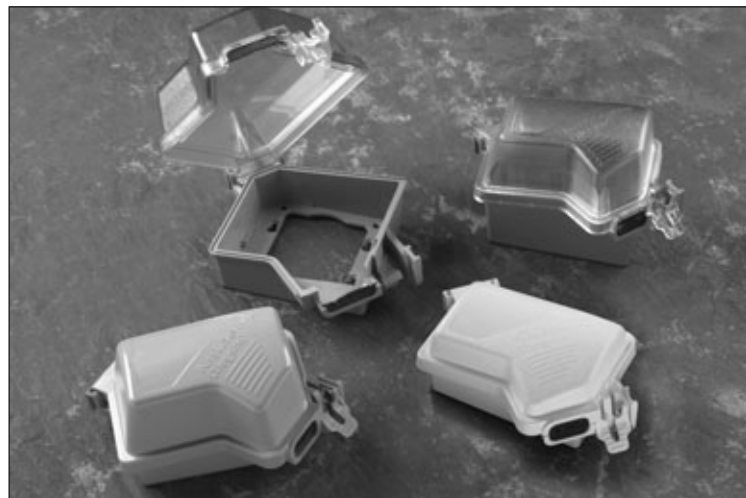

Features & Benefits

Exclusive cord flap gasket inhibits water splash from driving rain or sprinklers.

Sturdy polycarbonate construction resists impacts and harsh weather.

Patented corner hinge and cord opening allow vertical or horizontal installation.

Exclusive WaterShed™ Channel keeps water moving outside while cord flap keeps the inside dry.

Preapplied gasket easier to install, saves time, won't get lost or damaged.

WIUC10-SC

Paintable, textured finish hides scratches.

Patented trigger latch opens easily with one finger, yet is lockable to prevent tampering.

Sturdy, molded-in hinge withstands hard use.

Installs without removing electrical device, thanks to patented, keyed mounting holes.

Roomy interior provides space for plugs and cord bends.

Shallow profile models have 1" shorter top lid than prior models.

The 2002 NEC Section 406.8(B)(1) requires that all 15 and 20 Amp, 125 and 250 Volt outdoor receptacles in wet locations have a cover that is weatherproof — even when a plug is inserted into the receptacle.

Field Uses/Vertical Markets

- | | | | |
|--------------|---------------|-----------------------|---------------------|
| ■ Industrial | ■ Health Care | ■ Education | ■ Institutional |
| ■ Retail | ■ Office | ■ Hospitality/Lodging | ■ Multiple Dwelling |

SF2301R2 — Updated April 2005 — For latest specs visit www.legrand.us/passandseymour





 
 


Pass & Seymour

Weatherproof Boxes & Covers

While-In-Use Covers

Single, Shallow, Deep & Two Gang

Ordering Information

Catalog Number	Bottom Color	Top Color	Device Plates Provided	Plate Width
Single Gang				
WIUC10-GL WIUC10-CL WIUC10-WL	Gray Gray White	Gray Clear White		2 $\frac{3}{8}$ "
Single Gang Shallow				
WIUC10-SG WIUC10-SC WIUC10-SW WIUC10-SB	Gray Gray White White	Gray Clear White Clear		2 $\frac{3}{8}$ "
Single Gang Deep				
WIUC10-DGL WIUC10-DCL WIUC10-DWL	Gray Gray White	Gray Clear White		2 $\frac{3}{8}$ "
Two Gang				
WIUC20-GL WIUC20-CL WIUC20-WL	Gray Gray White	Gray Clear White		2"
Extra Plate Kits				
WIU10-PK WIU10-PKW	Gray White		Single Gang Plate Kit 	2 $\frac{3}{8}$ "
WIU20-PK WIU20-PKW	Gray White		Two Gang Plate Kit 	2"



Snap-in device plates require no tools to install and won't fall out. See chart for plates provided with each catalog number.

For more information on these and other P&S products refer to our Product Guide or visit our web site.

SF2301R2 — Updated April 2005 — For latest specs visit www.legrand.us/passandseymour

Weatherproof Boxes & Covers

While-In-Use Covers

Single, Shallow, Deep & Two Gang



Pass & Seymour

Technical Specifications

3rd Party Compliance

cULus Listed.
Covers conform to NEMA 3R.
Complies with 2002 NEC Section 406.8(B)(1).

Performance

Environmental	Weatherproof
---------------	--------------


Materials

Body	Polycarbonate
Cover	.125" Polycarbonate
Cover Finish	Textured
Screws	302 Stainless Steel
Gasket	Closed Cell Foam, Neoprene Blend
Insert Plate	Polycarbonate


Warranty

1 Year


**SINGLE GANG,
SINGLE GANG SHALLOW,
SINGLE GANG DEEP
COVERS**

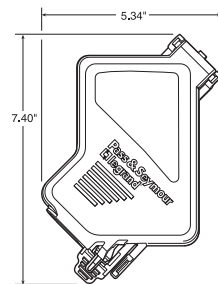


**SINGLE GANG
COVER**

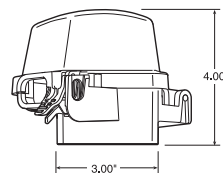



**SINGLE GANG
SHALLOW COVER**

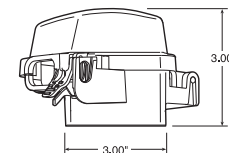

**SINGLE GANG
DEEP COVER**

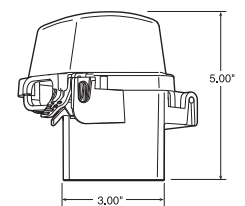

TWO GANG COVER

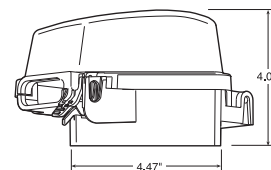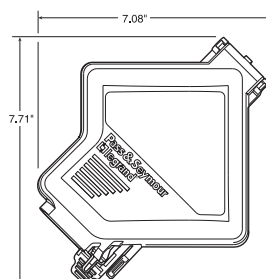

Complimentary Devices & Accessories




WEATHERPROOF BOXES & COVERS

- Heavy Cast Aluminum Covers
- Cast Covers
- Boxes




WALL PLATES

- TradeMaster® Thermoplastic Nylon
- Stainless Steel
- Brass
- Aluminum
- Dustproof Stainless Steel Covers

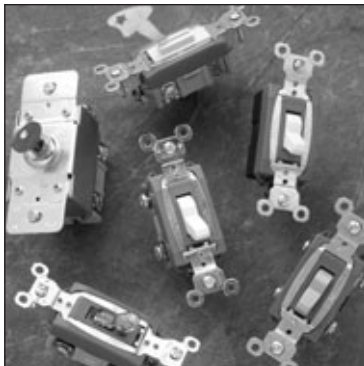


SWITCHES

- Heavy-Duty Toggle
- Heavy-Duty Lighted Toggle
- Heavy-Duty Security
- Heavy-Duty Locking
- Construction Grade Toggle
- Commercial Grade Toggle

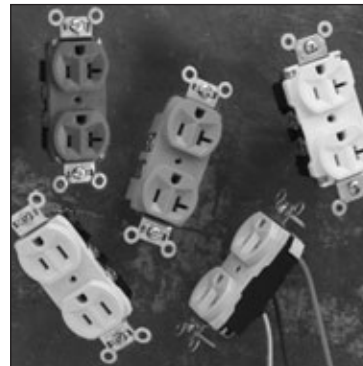

STRAIGHT BLADE RECEPTACLES

- Plug Tail™
- Extra Heavy-Duty
- Heavy-Duty
- Construction Grade
- Construction Grade Leaded
- Commercial Grade

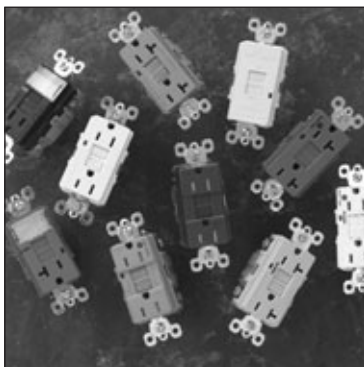

GFCIs

- Specification Grade
- Hospital Grade
- Dead Front

Also available...

- | | | | |
|--------------------------|--------------------------------------|-------------------------------------|-------------------------------|
| ■ Light Almond Devices | ■ PlugTail™ Devices | ■ Straight Blade Plugs & Connectors | ■ IEC 309 Industrial Products |
| ■ Decorator Devices | ■ TVSS & Isolated Ground Devices | ■ Turnlok® Locking Devices | ■ Flexcor® Wire Mesh Grips |
| ■ Hospital Grade Devices | ■ Ground Continuity Monitoring (GCM) | | ■ Configurable Solutions |



Legrand/Pass & Seymour
P.O. Box 4822
Syracuse, NY 13221-4822
800-223-4185

North America Headquarters
60 Woodlawn Street
West Hartford, CT 06110
Phone: 1.877.BY.LEGRAND (295.3472)
Fax: 1.860.232.2062
www.legrand.us

Legrand Canada
570 Applewood Crescent
Vaughan, ON, L4K 4B4
Phone: 905.738.9195
Fax: 905.738.9721
www.legrand.ca