

TSDDH163PTC

Simple, stylish fan speed control.

TSDDH163P*

Replace your standard switch with the new Toggle Slide Fan Speed Control by Legrand. The ergonomic slider was designed with the end user in mind, making it easier to adjust in the dark or on the run. This fan control offers a specially designed capacitive circuitry de-hummer feature that virtually eliminates fan motor "hum" for quiet fan speed control.


*Denotes color suffix

Features & Benefits

New aesthetically pleasing ergonomic design allows for easier operation

Constant memory returns fan speed to previous level after a power failure

Three settings for fan speed control – low, medium and high

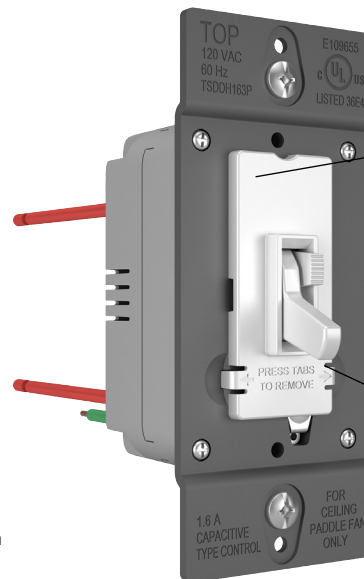

TSDDH163PW

Interchangeable face plates available in seven colors (TSDKIT*; sold separately)

Patented De-Hummer technology eliminates fan-motor "hum"

Convenient operation – combines ON/OFF toggle switch with separate slider for fan speed control

- 3-speed fan control.
- Preset, Single Pole and 3-Way operation.
- Lifetime warranty.

3rd Party Compliance

 cULus Listed, Standard UL1472, Standard CSA

Technical Information

Performance

Electrical

| | |
|----------------|-------------------------------------|
| Supply Voltage | 120VAC |
| Ratings | 1.6A |
| Frequency | 60Hz |
| Installation | Single Pole or 3-Way (Flying Leads) |

Environmental


| | |
|-------------|-----------------|
| Application | Indoor Use Only |
|-------------|-----------------|

Mechanical

| | |
|--------------------|---------------|
| Enclosure Material | Polycarbonate |
|--------------------|---------------|

Warranty

Lifetime

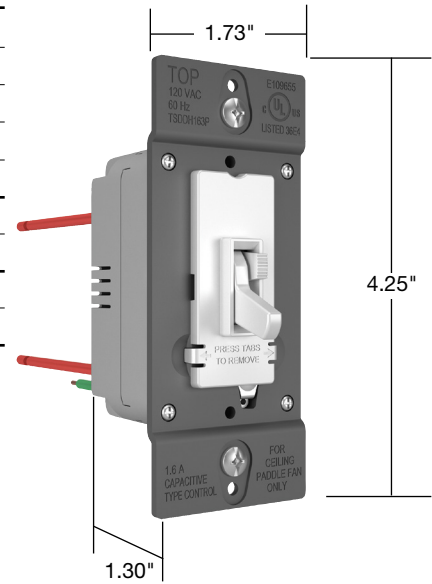

TSDDH163PW

Ordering Information

Toggle Slide Fan Speed Controls


| Catalog Number | Description | Color | Voltage | Rating |
|---------------------|-------------------------------|--|----------------|--------|
| TSDDH163PTC | Preset, Single Pole and 3-Way | Three interchangeable Face Colors: Ivory, White, Light Almond | 120VAC 60Hz | 1.6A |
| TSDDH163PW | Preset, Single Pole and 3-Way | Face Color: White | 120VAC 60Hz | 1.6A |
| TSDDH163PLA | Preset, Single Pole and 3-Way | Face Color: Light Almond | 120VAC 60Hz | 1.6A |
| TSDDH163PI | Preset, Single Pole and 3-Way | Face Color: Ivory | 120VAC 60Hz | 1.6A |
| TSDDH163P | Preset, Single Pole and 3-Way | Face Color: Brown | 120VAC 60Hz | 1.6A |
| TSDDH163PBK | Preset, Single Pole and 3-Way | Face Color: Black | 120VAC 60Hz | 1.6A |
| TSDDH163PRED | Preset, Single Pole and 3-Way | Face Color: Red | 120VAC 60Hz | 1.6A |
| TSDDH163PGRY | Preset, Single Pole and 3-Way | Face Color: Gray | 120VAC 60Hz | 1.6A |
| TSDKIT | | Brown | | |
| TSDKITBK | | Black | | |
| TSDKITGRY | | Gray | | |
| TSDKITI | Interchangeable Faces | Ivory | | |
| TSDKITLA | | Light Almond | | |
| TSDKITW | | White | | |
| TSDKITRED | | Red | | |

Vertical Markets

- Office
- Residential
- Multiple Dwelling
- Hospitality/Lodging

Available in the radiant® collection

- GFCI Receptacles
- Tamper-Resistant and Standard Duplex Receptacles
- Paddle Switches
- Fan Controls
- Sensors
- Timers
- Home Automation Controls
- USB Charging Devices
- Night Lights
- Screwless Wall Plates

 The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act compliant. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.

All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



Legrand, North America
60 Woodlawn Street
West Hartford, CT 06110
1.877.BY.LEGRAND (295.3472)
www.legrand.us
905.738.9195
www.legrand.ca

