



PASS & SEYMOUR® Harmony® 0-10V Dimmer 0-10V LED & Fluorescent

H4FBL3PTC / H4FBL3PW

A simple solution for 0-10V dimming.

Harmony® Dimmers have always been known for style. But now, thanks to customer input, they're known for added simplicity as well. The new Harmony 0-10V dimmer controls all the latest LED and fluorescent fixtures in one wall box control (0-10V style fixtures). That means no requirement for a separate power pack. Interchangeable face covers are available for the dimmers in a variety of popular colors. Each dimmer also has a green LED that glows when the light is turned OFF, making it easier to find in the dark.

Ideal for use in residential and commercial applications, the Harmony 0-10V LED and fluorescent dimmer is the simple solution for all your 0-10V control needs.



FEATURES & BENEFITS

Trim adjustment: allows users to fine tune the dimmer performance to the fixture.

Convenient operation: combines On/Off Decorator switch with separate slider for dimming control.

Preset, Single Pole and 3-Way operation: Support for both 120VAC and 277VAC applications.

Green LED: glows when off to make dimmer easy to find in the dark.

Sleek, ergonomic design: that matches today's styles

Wider slide controller: for easier dimming operation.



H4FBL3PTCW

FIELD USES / VERTICAL MARKETS

- | | | |
|--------------------|-----------------|-----------------------|
| ■ Residential | ■ Health Care | ■ Education |
| ■ Light Commercial | ■ Retail/Office | ■ Hospitality/Lodging |



PASS & SEYMOUR® Harmony® 0-10V Dimmer 0-10V LED & Fluorescent

ORDERING INFORMATION

Catalog Number	Description	Color	Voltage	Rating
Harmony® 0-10V Dimmer				
H4FBL3PTC	Preset, Single Pole and 3-Way	Three interchangeable Face Colors: Ivory, White, Light Almond	120 VAC, 60Hz 277 VAC, 60Hz	120V AC 10A 277V AC 5A 0-10V DC 30mA Sink
H4FBL3PW	Preset, Single Pole and 3-Way	Face Colors: White	120 VAC, 60Hz 277 VAC, 60Hz	120V AC 10A 277V AC 5A 0-10V DC 30mA Sink
HKIT	Interchangeable Face	Brown		
HKITBK	Interchangeable Face	Black		
HKITGRY	Interchangeable Face	Gray		
HKITI	Interchangeable Face	Ivory		
HKITLA	Interchangeable Face	Light Almond		
HKITNI	Interchangeable Face	Nickel		
HKITTI	Interchangeable Face	Titanium		
HKITW	Interchangeable Face	White		
HKITAB	Interchangeable Face	Antique Brass		
HKITDB	Interchangeable Face	Dark Bronze		

All devices are cULus Listed.

For more information on these and other P&S products refer to our Catalog or visit our web site.

Harmony[®] PASS & SEYMOUR[®] 0-10V Dimmer

0-10V LED & Fluorescent



TECHNICAL SPECIFICATIONS

3rd Party Compliance

cULus Listed, UL1472, CSA-C22.2 No. 184.1-95.
Conforms to NEMA WD-1 and WD-6, California Title 24 Compliant.



Performance

Electrical

Supply Voltage	120 VAC / 277VAC
Maximum Rated Load	120V 10A / 277V 5A
Frequency	60 Hz
Control	0-10VDC 30mA
Installation	Single Pole or 3-Way


Environment

Application	Indoor Use Only
-------------	-----------------

Mechanical

Enclosure Material	Polycarbonate Lexan
--------------------	---------------------

H4FBL3PTC

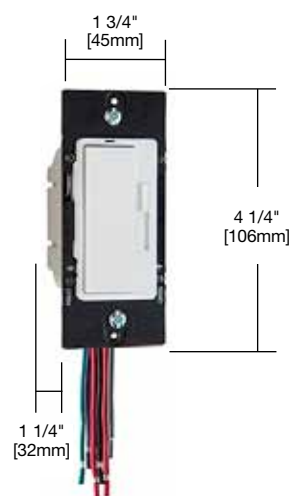

Warranty

Lifetime Warranty

ALSO AVAILABLE...

- | | | | |
|--|--------------------------------------|-------------------------------|-------------------------------|
| ■ Hospital Grade Devices | ■ Ground Continuity Monitoring (GCM) | ■ Turnlok® Locking Devices | ■ IEC 309 Industrial Products |
| ■ Surge Protective & Isolated Ground Devices | ■ Straight Blade Plugs & Connector | ■ Weatherproof Boxes & Covers | ■ Flexcor® Wire Mesh Grips |
| ■ Bulk Solutions | ■ USB Charging Devices | | |



Electrical Wiring Systems

P.O. Box 4822
Syracuse, NY 13221-4822
Phone: 1.877.BY.LEGRAND (295-3472)
www.legrand.us

570 Applewood Crescent
Vaughan, Ontario L4K 4B4
Phone: 905.738.9195
www.legrand.ca

