



# PASS & SEYMOUR® Harmony® Tru-Universal Dimmer

Incandescent, Halogen, ELV, MLV, LED, CFL, EFL

## H703PTUTC

### A simple dimming solution for you and your customers

Harmony® Tru-Universal Dimmers do something today's dimmers don't: **they simply work** – with virtually any dimmable lamp, load, and fixture on typical residential and light commercial wiring (with the exception of 0-10V LED drivers).

Once a user selects the lamp type, the dimmer's self-calibrating technology automatically sets the minimum voltage of that lamp. That means no more flickering lights, no more frustrated customers and no more unnecessary callbacks. And because it's the one product in the category that lives up to its universal name, it dramatically reduces the number of SKUs as well.

Ideal for residential and light commercial applications, the Harmony Tru-Universal Dimmer is the simple solution to all your customers' dimming challenges.



### FEATURES & BENEFITS

**Self Calibration feature** allows users to select lamp type, which then automatically sets the minimum voltage for that lamp, eliminating flickering and poor performance.

**Works with virtually any dimmable lamp and load** on typical residential and light commercial wiring (with the exception of 0-10V LED drivers).

**Convenient operation** combines On/Off Decorator switch with separate slider for dimming control.

**Preset, Single Pole and 3-Way operation.**

**Green LED** glows when off to make dimmer easy to find in the dark.

**Sleek, ergonomic design** that matches today's styles

**Wider slide controller** for easier dimming operation.



H703PTUTC

### FIELD USES/VERTICAL MARKETS

- |                    |                 |                       |
|--------------------|-----------------|-----------------------|
| ■ Residential      | ■ Health Care   | ■ Education           |
| ■ Light Commercial | ■ Retail/Office | ■ Hospitality/Lodging |



**PASS & SEYMOUR®**  
**Harmony® Tru-Universal Dimmer**  
Incandescent, Halogen, ELV, MLV, LED, CFL, EFL

**ORDERING INFORMATION**

Catalog Number	Description	Color	Voltage	Rating
<b>Harmony® Tru-Universal Dimmer</b>				
<b>H703PTUTC*</b>	Preset, Single Pole and 3-Way	Three interchangeable Face Colors: Ivory, White, Light Almond	120 VAC, 60Hz	Incandescent, Halogen & ELV: 700W, MLV: 50VA, LED/CFL: 450W (not compatible with 0-10V LED drivers), EFL: 5.5A
<b>HKIT</b>	Interchangeable Face	Brown		
<b>HKITBK</b>	Interchangeable Face	Black		
<b>HKITGRY</b>	Interchangeable Face	Gray		
<b>HKITI</b>	Interchangeable Face	Ivory		
<b>HKITLA</b>	Interchangeable Face	Light Almond		
<b>HKITNI</b>	Interchangeable Face	Nickel		
<b>HKITTI</b>	Interchangeable Face	Titanium		
<b>HKITW</b>	Interchangeable Face	White		
<b>HKITAB</b>	Interchangeable Face	Antique Brass		
<b>HKITDB</b>	Interchangeable Face	Dark Bronze		

\* Available in VisionPak™ packaging. Add "CCV6" to catalog Number. Example: H703PTUTCCCV6  
All devices are cULus Listed.

For more information on these and other P&S products refer to our Catalog or visit our web site.

# PASS & SEYMOUR® Harmony® Tru-Universal Dimmer

Incandescent, Halogen, ELV, MLV, LED, CFL, EFL



## TECHNICAL SPECIFICATIONS

### 3rd Party Compliance

cULus Listed, UL1472, CSA-C22.2 No. 184.1-95.  
Conforms to NEMA WD-1 and WD-6, California Title 24 Compliant.



### Performance

#### Electrical


Supply Voltage	120 VAC
Maximum Rated Load	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W, EFL: 5.5A
Frequency	60 Hz
Phase Control	Forward or Reverse
Installation	Single Pole or 3-Way

#### Environment

Application	Indoor Use Only
-------------	-----------------

#### Mechanical

Enclosure Material	Polycarbonate Lexan
--------------------	---------------------

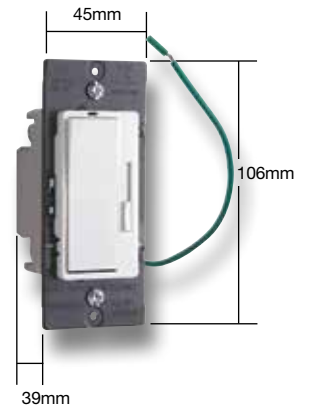

**H703PTUTC**

### Warranty

Lifetime Warranty

ALSO AVAILABLE...

- |  |                                      |                               |                               |
|--|--------------------------------------|-------------------------------|-------------------------------|
| ■ Hospital Grade Devices                     | ■ Ground Continuity Monitoring (GCM) | ■ Turnlok® Locking Devices    | ■ IEC 309 Industrial Products |
| ■ Surge Protective & Isolated Ground Devices | ■ Straight Blade Plugs & Connector   | ■ Weatherproof Boxes & Covers | ■ Flexcor® Wire Mesh Grips    |
| ■ Bulk Solutions                             | ■ USB Charging Devices               |                               |                               |



**Electrical Wiring Systems**

P.O. Box 4822  
Syracuse, NY 13221-4822  
Phone: 1.877.BY.LEGRAND (295-3472)  
[www.legrand.us](http://www.legrand.us)

570 Applewood Crescent  
Vaughan, Ontario L4K 4B4  
Phone: 905.738.9195  
[www.legrand.ca](http://www.legrand.ca)

