



Pass & Seymour

Wall Plates Aluminum One & Two Gang

SA1, SA2, SA8, SA82, SA26, SA262, SA13, SA23, SA7

Great value, great look.

Sturdy and nonmagnetic, these satin-finished aluminum plates look good in any application. Their tough lacquer finish prevents corrosion and they are a full .040" thick of true commercial durability.



Features & Benefits

Constructed of .040 inch thick satin-finish aluminum.



Aesthetically pleasing contour design.

Packaged in protective film, with finish-matching screws.

SA1, SA82





 




Field Uses/Vertical Markets

- Industrial
- Health Care
- Education
- Institutional
- Retail
- Office
- Hospitality/Lodging
- Multiple Dwelling

SF2504R1 — Updated January 2004 — For latest specs visit www.legrand.us/passandseymour

Wall Plates Aluminum One & Two Gang

Ordering Information

Description	Catalog Number	Description	Catalog Number
Aluminum Toggle Switch Openings			
One Gang 	SA1	Two Gang 	SA2
Aluminum Duplex Receptacle Openings			
One Gang 	SA8	Two Gang 	SA82
Aluminum Decorator Openings			
One Gang 	SA26	Two Gang 	SA262
Aluminum Blank Plates – Box Mounted			
One Gang 	SA13	Two Gang 	SA23
Aluminum Single Receptacle Opening			
One Gang 	SA7		

For more information on these and other P&S products refer to our Product Guide or visit our web site.

Wall Plates Aluminum One & Two Gang



Pass & Seymour

Technical Specifications

3rd Party Compliance

UL Listed, Standard UL514, Cover Plates for Flush Mounted Wiring Devices.
CSA Certified.

Performance


Environmental Corrosion-Resistant

Materials


Plate Material	.040" Aluminum, T 5005
Plate Finish	Satin, Lacquered, Anodized
Screws	Aluminum, T 5005

Warranty

1 Year

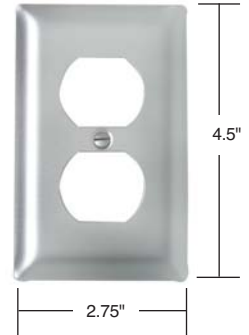

Dimensions for
One Gang

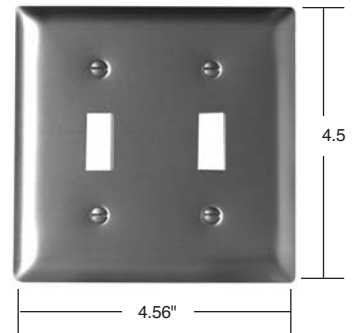


Dimensions for
Two Gang

Complementary Devices & Accessories




WALL PLATES

- TradeMaster® Thermoplastic Nylon
- Stainless Steel
- Brass
- Dustproof Stainless Steel Covers

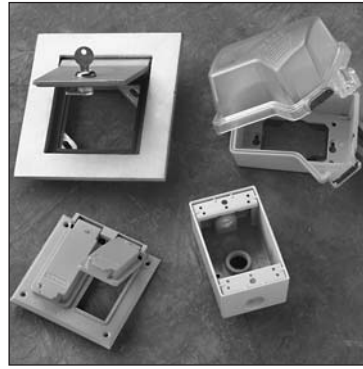


WEATHERPROOF BOXES & COVERS

- While-In-Use Covers
- Heavy Cast Aluminum Covers
- Cast Covers
- Boxes

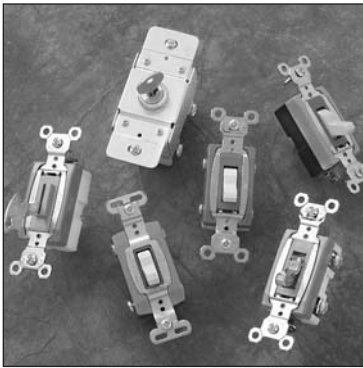


SWITCHES

- Heavy-Duty Toggle
- Heavy-Duty Lighted Toggle
- Heavy-Duty Security
- Heavy-Duty Locking
- Construction Grade Toggle
- Commercial Grade Toggle

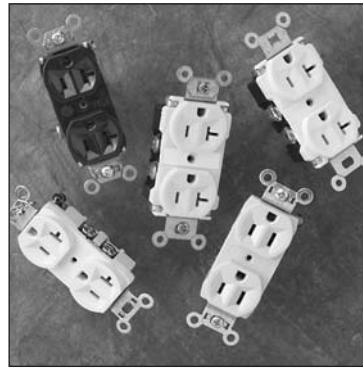

STRAIGHT BLADE RECEPTACLES

- Extra Heavy-Duty
- Heavy-Duty
- Construction Grade
- Commercial Grade

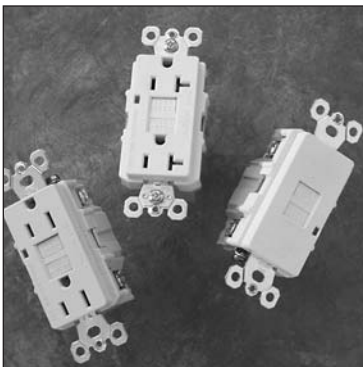

GFCIs

- Construction Grade with Auto-Ground
- Construction Grade
- Construction Grade Dead Front

Also available...

- Light Almond Devices
- Decorator Devices
- Hospital Grade Devices
- PlugTail™ Devices
- TVSS & Isolated Ground Devices
- Ground Continuity Monitoring (GCM)
- Straight Blade Plugs & Connectors
- Turnlok® Locking Devices
- IEC 309 Industrial Products
- Flexcor® Wire Mesh Grips
- Configurable Solutions



Legrand/Pass & Seymour
P.O. Box 4822
Syracuse, NY 13221-4822
800-223-4185

North America Headquarters
60 Woodlawn Street
West Hartford, CT 06110
Phone: 1.877.BY.LEGRAND (295.3472)
Fax: 1.860.232.2062
www.legrand.us

Legrand Canada
570 Applewood Crescent
Vaughan, ON, L4K 4B4
Phone: 905.738.9195
Fax: 905.738.9721
www.legrand.ca