



Pass & Seymour

Wall Plates Brass One & Two Gang

SB1, SB2, SB8, SB82, SB26, SB262, SB13, SB23, SB7


The soft, warm look of brushed brass.

These sturdy wall plates deliver a winning combination of commercial durability and rich style. We build these plates with a 70 percent copper/30 percent zinc brass alloy that provides a handsome, warm appearance. They are finished with durable lacquer to prevent corrosion.



Features & Benefits

Constructed of .040 inch thick brushed brass.

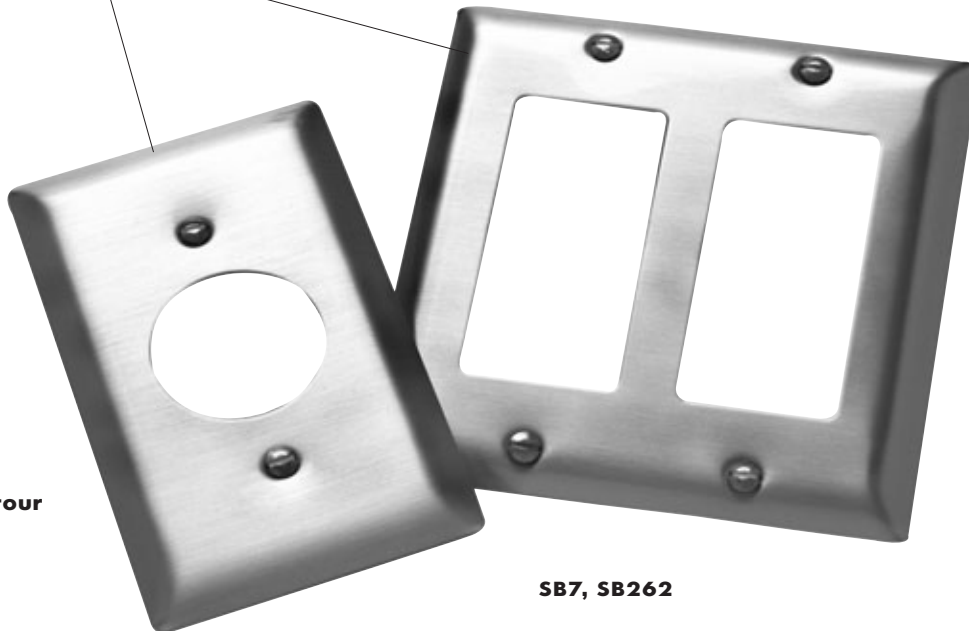

Aesthetically pleasing contour design.

Packaged in protective film, with finish-matching screws.








 

SB7, SB262

Field Uses/Vertical Markets

- Institutional
- Hospitality/Lodging
- Retail
- Multiple Dwelling
- Office

Wall Plates Brass One & Two Gang

Ordering Information

Description	Catalog Number	Description	Catalog Number
Brass Toggle Switch Openings			
One Gang 	SB1	Two Gang 	SB2
Brass Duplex Receptacle Openings			
One Gang 	SB8	Two Gang 	SB82
Brass Decorator Openings			
One Gang 	SB26	Two Gang 	SB262
Brass Blank Plates — Box Mounted			
One Gang 	SB13	Two Gang 	SB23
Brass Single Receptacle Opening			
One Gang 	SB7		

For more information on these and other P&S products refer to our Product Guide or visit our web site.

Wall Plates Brass One & Two Gang



Pass & Seymour

Technical Specifications

3rd Party Compliance

UL Listed, Standard UL514, Cover Plates for Flush Mounted Wiring Devices.
CSA Certified.

Performance


Environmental Corrosion-Resistant

Materials


Plate Material	.040" Brass
Plate Finish	Brushed, Lacquered
Screws	Brass

Warranty

1 Year

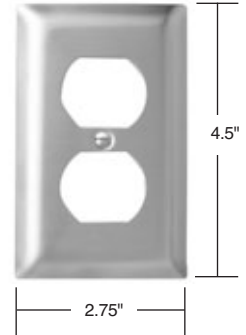

Dimensions for
One Gang

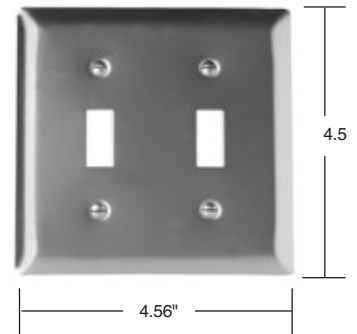


Dimensions for
Two Gang

Complimentary Devices & Accessories




WALL PLATES

- TradeMaster® Thermoplastic Nylon
- Stainless Steel
- Aluminum
- Dustproof Stainless Steel Covers

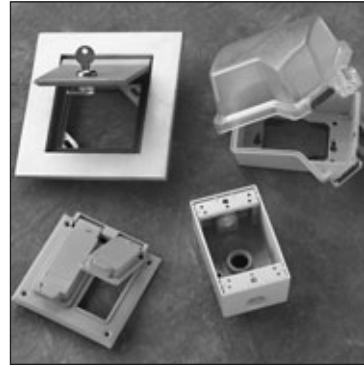


WEATHERPROOF BOXES & COVERS

- While-In-Use Covers
- Heavy Cast Aluminum Covers
- Cast Covers
- Boxes

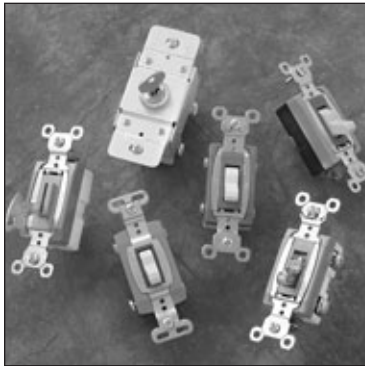


SWITCHES

- Heavy-Duty Toggle
- Heavy-Duty Lighted Toggle
- Heavy-Duty Security
- Heavy-Duty Locking
- Construction Grade Toggle
- Commercial Grade Toggle

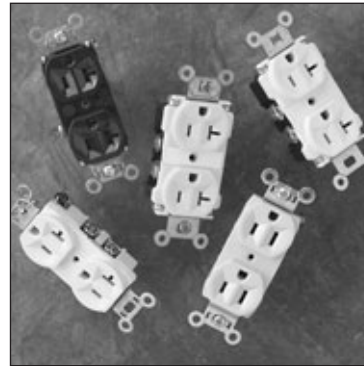

STRAIGHT BLADE RECEPTACLES

- Extra Heavy-Duty
- Heavy-Duty
- Construction Grade
- Commercial Grade

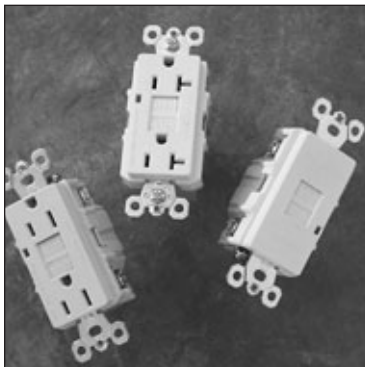

GFCIs

- Construction Grade with Auto-Ground
- Construction Grade
- Construction Grade Dead Front

Also available...

- Light Almond Devices
- Decorator Devices
- Hospital Grade Devices
- PlugTail™ Devices
- TVSS & Isolated Ground Devices
- Ground Continuity Monitoring (GCM)
- Straight Blade Plugs & Connectors
- Turnlok® Locking Devices
- IEC 309 Industrial Products
- Flexcor® Wire Mesh Grips
- Configurable Solutions



Legrand/Pass & Seymour
P.O. Box 4822
Syracuse, NY 13221-4822
800-223-4185

North America Headquarters
60 Woodlawn Street
West Hartford, CT 06110
Phone: 1.877.BY.LEGRAND (295.3472)
Fax: 1.860.232.2062
www.legrand.us

Legrand Canada
570 Applewood Crescent
Vaughan, ON, L4K 4B4
Phone: 905.738.9195
Fax: 905.738.9721
www.legrand.ca