

Conveniently control your lights or appliances from anywhere

WWP20

Conveniently control your lights and power from anywhere using the Legrand Smart Lights mobile app, Amazon Alexa, the Google Assistant, and other popular control platforms. In the app, use Scenes to create the perfect ambiance in your home. With automated schedules, sync your lights with sunrise and sunset, or program to simulate occupancy while you're away. Legrand switches also use less energy than ordinary switches, with automated options available to promote enhanced energy savings.

Ideal for residential and light commercial applications, the Wi-Fi Tru-Universal Smart Plug in Dimmer is the simple solution to all your customers' dimming challenges.




Android is a trademark of Google LLC.



FEATURES & BENEFITS

- **Plug into an open outlet and smart enable any dimmable lamp**
- **Works with virtually any dimmable lamp and load on typical residential and light commercial wiring**
- **Works with iOS and Android smart phones for control while at home or halfway around the world**
- **Schedule lights on/off automatically so you never come home to a dark house**
- **Group with other Wi-Fi smart devices and create scenes**
- **White LED locator light glows when device is off for easy location in the dark**
- **Dimmer controls can be adjusted for ground plug up or ground plug down orientation**

COMPLIANCE

-  cULus Listed, UL916, File E495025
- FCC Class B Part 15, IC. Works with Alexa Works Works with the Google Assistant, OCF Certified, Wi-Fi Certified.
- Works with IFTTT, Samsung Artik Cloud enabled
- **RoHS Compliant.**



ORDERING INFORMATION

CATALOG NUMBER	DESCRIPTION	RATING	NEMA	COMPLIANCE	COLORS	COO
WWP20	Plug-In Smart Dimmer	FWD – 1A LED/CFL FWD – 300W Inc/Halogen/ELV FWD – 300 VA MLV REV – 300W INC/Halogen/ELV	5-15R, 120V		White	China



VERTICAL MARKETS

- Residential

COMPATIBILITY



OPEN CONNECTIVITY
 FOUNDATION™



SAMSUNG
ARTIK™
 POWERED

IC

FC

TECHNICAL SPECIFICATIONS

3rd Party Compliance

- cULus Listed, UL916, File E495025
- FCC Class B Part 15, IC. Works with Alexa Works
- Works with the Google Assistant, OCF Certified, Wi-Fi Certified.
- Works with IFTTT, Samsung Artik Cloud enabled


Performance

ELECTRICAL

Supply Voltage	120 VAC
Maximum Rated Load	FWD – 1A LED/CFL
	FWD – 300W Inc/Halogen/ELV
	FWD – 300 VA MLV
	REV – 300W INC/Halogen/ELV
Frequency	60Hz
Phase Control	Forward or Reverse (Selectable)
Installation	Single-Pole or 3-Way

MECHANICAL

Enclosure Material	Indoor Use Only
--------------------	-----------------

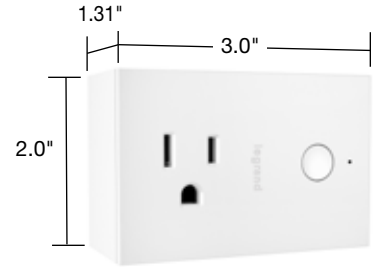

Materials

Paddle	Polycarbonate	Terminal	Brass
Back Body	Polycarbonate		

App

Android Requirements	Android 5.0 or higher with camera
Apple IOS Requirements	iOS 10.0 or higher with camera

Radio

Wi-Fi	Certified IEEE802.11 b/g/n Wi-Fi® 2.4GHz radio. Supports IPv6 addressing to conform to EU standards.
-------	---

Warranty

Limited Lifetime Warranty

NOTE: All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



NOTE: The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act compliant. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.



Legrand, North America
60 Woodlawn Street
West Hartford, CT 06110
1.877.BY.LEGRAND (295.3472)
www.legrand.us

Canada
905.738.9195
www.legrand.ca

FOLLOW US

