

HCL453PMMTC

## Multi-location dimming for Incandescent, CFL, LED and MLV loads.

HCL453PMMTC, HCL453PMMW

The radiant® Multi-Location Master Dimmer can be paired with up to nine remote dimmers (HMRTC/HMRW) for simple multi-way dimming. These dimmers are ideal for residential, multi-dwelling and hospitality environments, and as part of the radiant® collection, now offer a better fit, form and finish.

## Features & Benefits

**Convenient operation:** combines ON/OFF paddle switch with separate slider for dimming control.




**White LED** glows when OFF to make dimmer easy to find in the dark.

Sleek, ergonomic design that matches today's styles.

HCL453PMMW

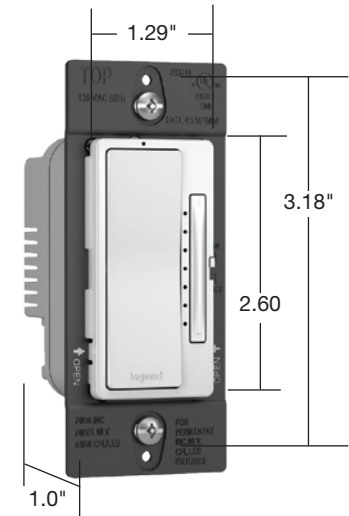
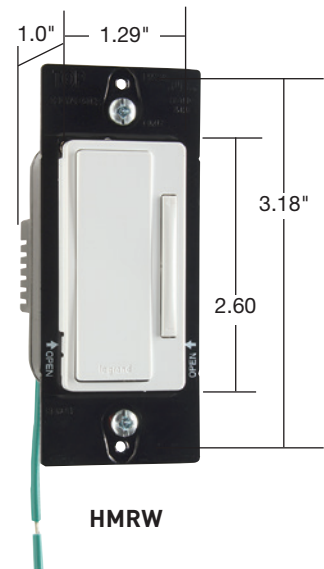
- **Preset, Single Pole and 3-Way multi-location operation.**
- **Interchangeable face plates** available in eight colors (HMKIT\*; sold separately)

## 3rd Party Compliance

 cULus listed, UL1472, CSA

**Technical Information**
**Performance**

Electrical	
Supply Voltage	120VAC
Rating	450W CFL/LED; 700W Incandescent; 700VA MLV
Frequency	60Hz
Installation	Single Pole or 3-Way
Environmental	
Application	Indoor Use Only
Mechanical	
Enclosure Material	Polycarbonate


**HCL453PMMW**

**HMRW**
**Warranty**

Lifetime

## Ordering Information

### radiant® Multi-Location Master Dimmers and Replacement Face Plates

Catalog Number	Description	Color	Voltage	Rating
HCL453PMMTC	Preset, Single Pole and 3-Way	Three interchangeable Face Colors: Ivory, White, Light Almond	120VAC 60Hz	700W Inc/ 500VA MLV/ 450W CFL/LED
HCL453PMMW	Preset, Single Pole and 3-Way	Face Color: White	120VAC 60Hz	700W Inc/ 500VA MLV/ 450W CFL/LED
HMKITBK		Black		
HMKITGRY		Gray		
HMKITI		Ivory		
HMKITLA		Light Almond		
HMKITNI		Nickel		
HMKITW		White		
HMKITDB		Dark Bronze		

### radiant® Multi-Location Remote Dimmers and Replacement Face Plates

Catalog Number	Description	Color	Voltage	Rating
HMRTC	Multi-Location Remote Single Pole/3-Way	Three Interchangeable Face Colors: Ivory, White, Light Almond	120VAC 60Hz	N/A
HMRW	Multi-Location Remote Single Pole/3-Way	Face Color: White	120VAC 60Hz	N/A
HMRKITBK	Multi-Location Remote Dimmer Interchangeable Face Plate	Black		
HMRKITGRY	Multi-Location Remote Dimmer Interchangeable Face Plate	Gray		
HMRKITI	Multi-Location Remote Dimmer Interchangeable Face Plate	Ivory		
HMRKITLA	Multi-Location Remote Dimmer Interchangeable Face Plate	Light Almond		
HMRKITNI	Multi-Location Remote Dimmer Interchangeable Face Plate	Nickel		
HMRKITW	Multi-Location Remote Dimmer Interchangeable Face Plate	White		
HMRKITDB	Multi-Location Remote Dimmer Interchangeable Face Plate	Dark Bronze		

---

## Vertical Markets


- Office
- Residential
- Multiple Dwelling
- Hospitality/Lodging

---

## Also available in the radiant® collection

- GFCI Receptacles
- Tamper-Resistant and Standard Duplex Receptacles
- Paddle Switches
- Fan Controls
- Sensors
- Timers
- Home Automation Controls
- USB Charging Devices
- Night Lights
- Screwless Wall Plates

---

 The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act compliant. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.

All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



**Legrand, North America**  
60 Woodlawn Street  
West Hartford, CT 06110  
1.877.BY.LEGRAND (295.3472)  
[www.legrand.us](http://www.legrand.us)

570 Applewood Crescent  
Vaughan, Ontario L4K 4B4  
905.738.9195  
[www.legrand.ca](http://www.legrand.ca)

FOLLOW US

