

PANEL ENCLOSURES

LENC

16-gauge all steel tubs with
galvineal finish

Screw on, powder coated cover
permits temporary hanging via
key hole screw slots

Surface mounting with back
mounting holes, screw cover



Lockable door access to Class 2
panel section, meets NFPA 70

Studs provided for quick installation
of panel interior section

UL and cUL listed; five year warranty


DESCRIPTION

LENC panel enclosures are designed specifically to work with all configurations of LMCP panel interiors containing 8 to 48 relays. The enclosures are provided with integral mounting studs that are configured to accept the panel interior making the installation quick and easy. Covers are secured to the tubs with screws and have keyhole style mounting. This allows the cover to be temporarily hung on the tub during the construction phase of the project. All covers have hinged doors that expose only the low voltage (Class 2) section of the panel and are equipped with key locks and two keys each. All LENC enclosures are NEMA 1 rated. Consult factory for other NEMA rated applications.

APPLICATIONS

Enclosures rated for 24 or 48 relay capacity have space provided at the bottom for optional mounting plates (DMP) to accept DIN rail mounted accessories such as multi-pole contactors and ELCU-100 Emergency Lighting Control Units. Standard LENC24 and LENC48 enclosures will accommodate up to six four pole contactors (requires DMP mounting plate) or four ELCU-100 units (requires DMP-1EM mounting plate). LENC8-24 and LENC24-48 enclosures have additional space provided and will accommodate up to twelve four pole contactors (requires DMP-2 mounting plate) or 12 ELCU-100 units (requires DMP-3EM mounting plate).


DIN RAIL MOUNTING OPTIONS

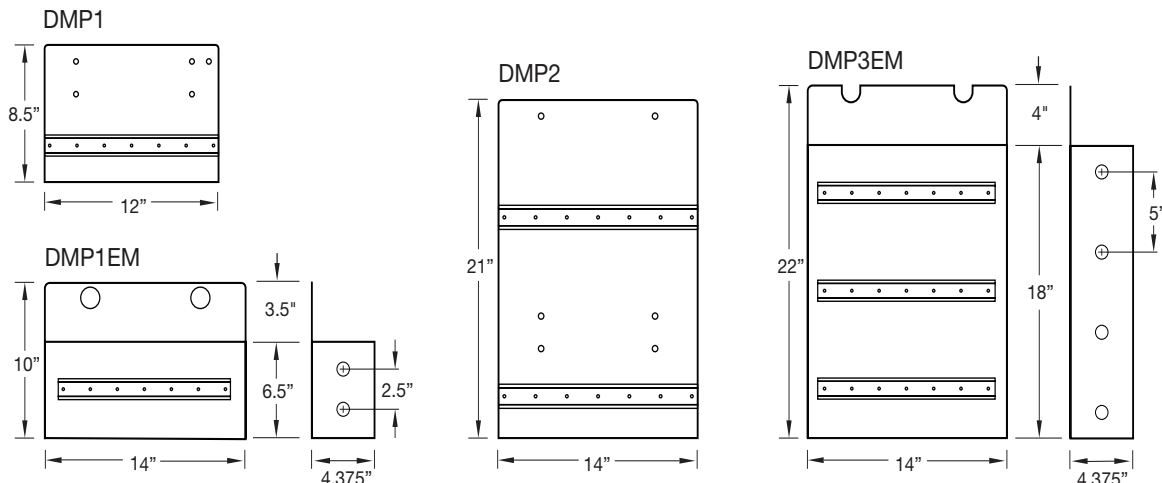

PROJECT

LOCATION/
TYPE

TUB DIMENSIONS

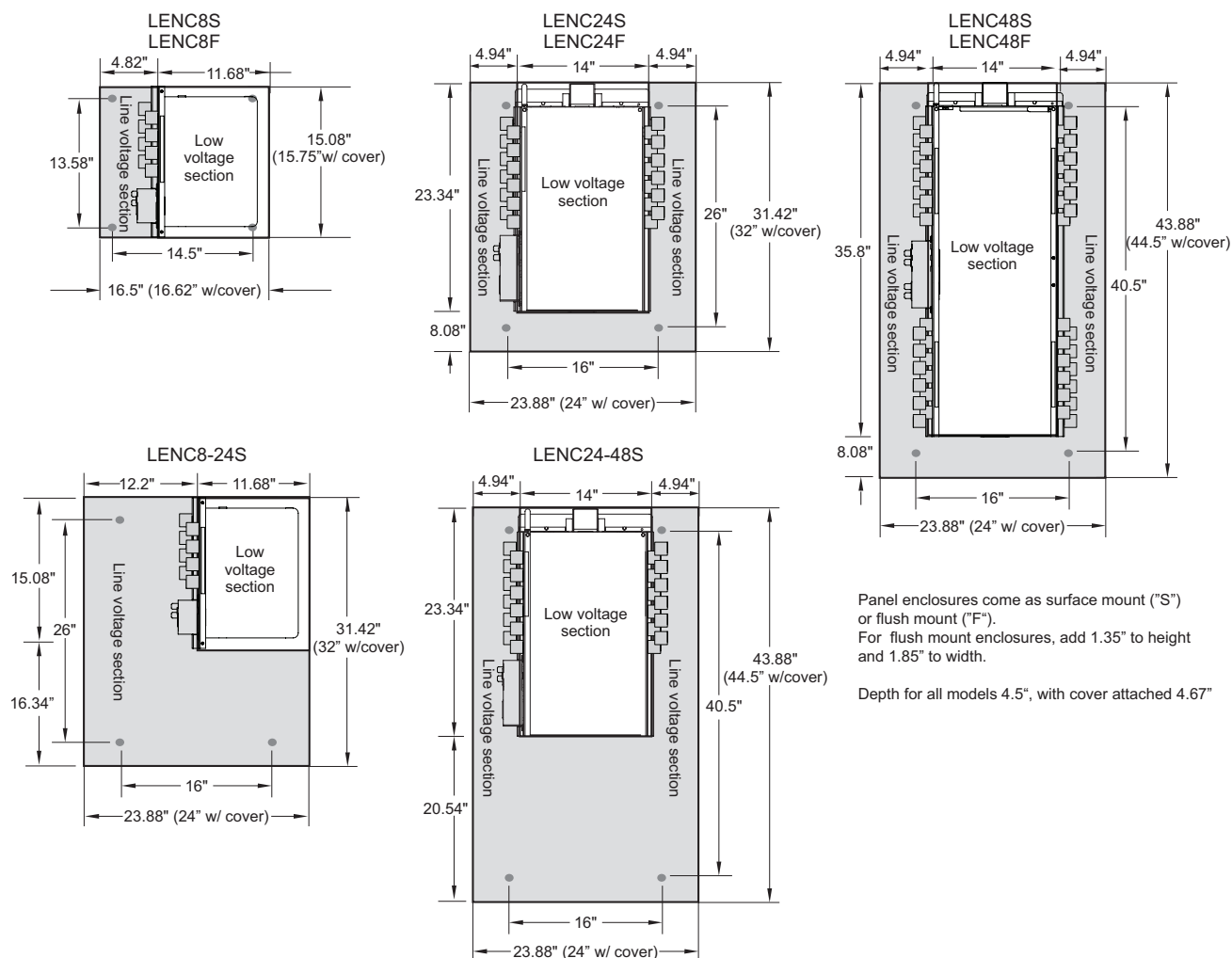

ORDERING INFORMATION

Catalog #	Description	Overall Dimensions Including Cover (HxWxD)	Overall Weight
<input type="checkbox"/> LENC8S	8 relay capacity, surface mount	15.75" x 16.62" x 4.67"	18 lbs.
<input type="checkbox"/> LENC8F	8 relay capacity, flush mount	17.10" x 18.48" x 4.67"	20 lbs.
<input type="checkbox"/> LENC8-24S	8 relay capacity with 24 size tub, surface mount	32.00" x 24.00" x 4.67"	45 lbs.
<input type="checkbox"/> LENC24S	24 relay capacity, surface mount	32.00" x 24.00" x 4.67"	45 lbs.
<input type="checkbox"/> LENC24F	24 relay capacity, flush mount	33.35" x 25.85" x 4.67"	50 lbs.
<input type="checkbox"/> LENC24-48S	24 relay capacity with 48 size tub	44.50" x 24.00" x 4.67"	62 lbs.
<input type="checkbox"/> LENC48S	48 relay capacity, surface mount	44.50" x 24.00" x 4.67"	62 lbs.
<input type="checkbox"/> LENC48F	48 relay capacity, flush mount	45.85" x 25.85" x 4.67"	66 lbs.
<input type="checkbox"/> DMP	Mounting Plate, one DIN rail for up to 6 contactors	8" x 12" x 0.34"	1.86 lbs.
<input type="checkbox"/> DMP-2	Mounting Plate, one DIN rail for up to 12 contactors	21" x 14" x 0.34"	5.30 lbs.
<input type="checkbox"/> DMP-1EM	Mounting Plate, one DIN rail with barrier for up to 4 ELCU-100s	10" x 14" x 4.39"	3.64 lbs.
<input type="checkbox"/> DMP-3EM	Mounting Plate, three DIN rails with barrier for up to 12 ELCU-100s	22" x 14" x 4.39"	7.60 lbs.

27224r1 Rev 03/2021