


PRESET COUNTDOWN TIME SWITCH

RT-20

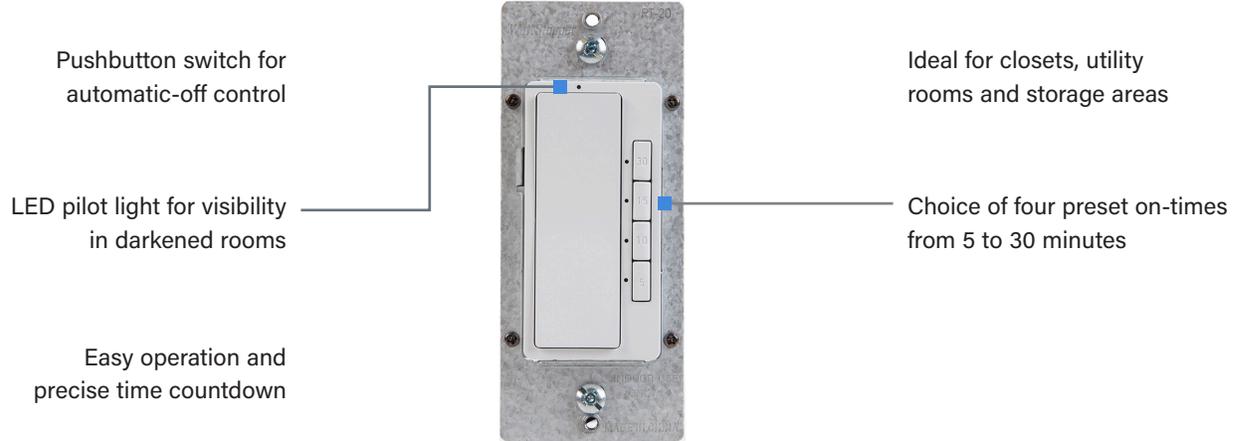

DESCRIPTION

The RT-20 Preset Countdown Time Switch automatically turns lighting or other loads off when the selected on-time expires. It replaces standard single-pole wall switches for energy savings throughout a range of applications.

OPERATION

Users press one of the four preset buttons to turn connected lighting on for the corresponding period of time. After the time has elapsed, lighting is automatically turned off. Lights can be turned off before the countdown is complete by pressing the on/off button. Users may press the on/off button to turn lights on. The time switch will activate the preset that was last used, and the indicator light for that preset will turn on. To change the countdown, users press the desired preset button and the RT-20 will reset to that countdown interval.

CHOICE OF ON TIMES

The RT-20 will keep lighting on for 5, 10, 15 or 30 minutes. The digital on-time options provide precise control and help users avoid leaving lights on unnecessarily.

APPLICATIONS

Countdown time switches are an ideal lighting control choice for areas where wall switch vacancy or occupancy sensors may be inappropriate. The RT-20 preset time switch is recommended for controlling lighting in areas such as utility rooms, closets, laundry rooms, pantries and storage rooms.

FEATURES

- Five-button preset time switch
- Replaces single-pole switch
- Selectable on-time: 5, 10, 15, 30 minutes
- LED pilot light for visibility in darkened rooms
- Low-profile styling
- Choice of four decorator colors
- Operates most common types of lighting
- Relay-based switching
- Zero crossing reduces stress on the relay and increases product longevity
- No current leakage to load in off mode for safety
- Compatible with decorator wall plates


PROJECT

LOCATION/
TYPE


SPECIFICATIONS

- 120-277VAC, 60 Hz (single phase); neutral required
- Load ratings: 0-800 VA incandescent, LED, fluorescent, E-ballast, compact fluorescent (CFL), magnetic low voltage (MLV), electronic low voltage (ELV), and 1/4 Hp motor
- On-time options: 5, 10, 15, 30 minutes
- 2.63" x 1.69" x 1.88" (67.8mm x 42.9mm x 47.8mm) L x W x D
- Operating conditions: 32-131°F (0-55°C), 95% RH, non-condensing; for indoor use only
- UL and cUL listed
- Five year warranty

INSTALLATION & WIRING

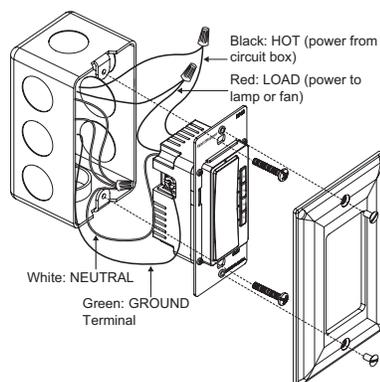

PRODUCT CONTROLS

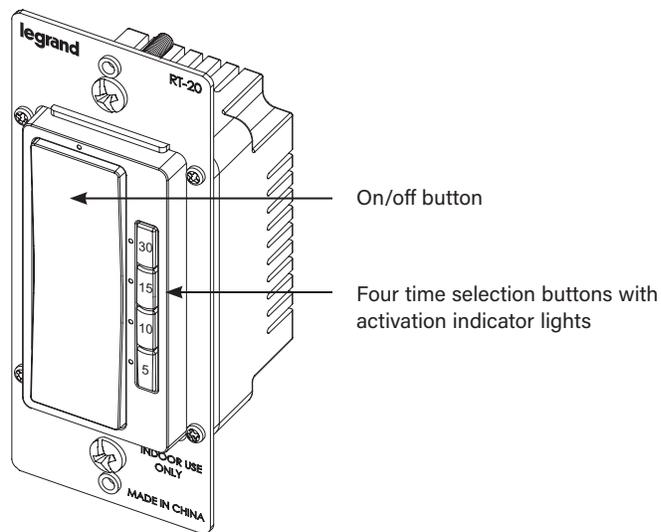

ORDERING INFORMATION

Catalog #	Color	Description	Voltage	Load Rating
<input type="checkbox"/> RT-20-W	White	Preset Countdown Time Switch	120-277VAC; 60 Hz	0-800 VA incandescent, LED, fluorescent, E-ballast, CFL, MLV, ELV, 1/4 Hp motor
<input type="checkbox"/> RT-20-I	Ivory			
<input type="checkbox"/> RT-20-LA	Light Almond			
<input type="checkbox"/> RT-20-B	Black			

Order wallplates separately.

31821r1 Rev 11/2021