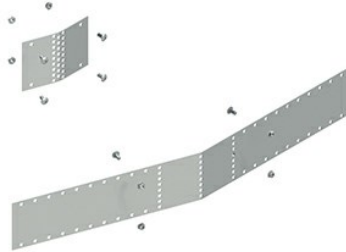

HORIZONTAL ADJUSTABLE SPLICE KIT

HASP | [Cablofil](#)



FEATURES & BENEFITS

The aluminum I-beam design of ITray is perfect for industrial installations with large diameter cables in long span situations, minimizing total tray width and creating a smooth transition between straight sections and fittings. A structural offset in the sidewall creates strong, mid-span splices that need fewer supports. Each splice snaps in place and stays without holding. Additionally, only four bolts are needed for each splice reducing hardware needs by 50%. These features allow Itray to be installed up to 30% faster than standard tray.

- Bend plates to appropriate angle as needed
- Field drill outer plate if needed
- Torque: 19ft./lbs.
- MEETS CABLE TRAY BONDING REQUIREMENTS (NO BONDING JUMPERS REQUIRED) WHEN TRAY IS NOT USED AS AN EGC
- KIT INCLUDES ONE INSIDE AND OUTSIDE PLATE AND ALL NECESSARY HARDWARE TO COMPLETE SPLICE CONNECTION

SPECIFICATIONS

GENERAL INFO

Finish: Plain
Product Series: Itray
Type: Splices

CONSTRUCTION INFORMATION

Material 1: Aluminum