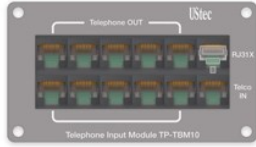

10 PORT BASE TELEPHONE MODULE

TP-TBM10 | [On-Q](#)



FEATURES & BENEFITS

- 1 Telephone-in port
- Telephone base module
- 10 Telephone-out ports, 4 lines each
- 1 RJ31X security interface port

SPECIFICATIONS

GENERAL INFO

Discontinued: Yes
Cable Type: Cat5e
Color: Gray/Black
Type: Telecom Module Pro-LAN

ASSEMBLY/INSTALLATION INFORMATION

Mounting Hardware Included: Yes

LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

UN SPSC: 43222819

CONSTRUCTION INFORMATION

Installation Location: Residential

DIMENSIONS

Height (Metric): 6.1 cm
Height (US): 2.4"
Length (Metric): 2.5 cm
Length (US): 1"
Width (Metric): 10.8 cm
Width (US): 4.25 in

TECHNICAL INFORMATION

Connection Method: RJ45

Humidity: 90% Relative Humidity (Non-Condensing)
Material: 18 Gauge CRS
Mounting: ProLAN Enclosure
Operating Temperature (Celsius): 0°C to 55°C
Output And Line Out Connection: 10-port Telecom