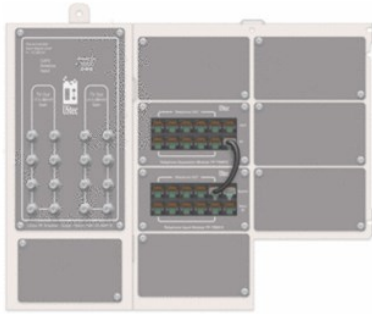

ILAN SERIES TECLAN16X1B

TECLAN16X1B | [On-Q](#)



FEATURES & BENEFITS

- 20 Phone ports (4 line)
- Includes PW7760 power source
- 16 Amplified CATV ports with surge protection
- 1 RJ31X security interface port

SPECIFICATIONS

GENERAL INFO

Discontinued: Yes
Cable Type: Cat5e and RG6
Color: Gray/White
Type: Telecom/Amplified Video Module In Frame

ASSEMBLY/INSTALLATION INFORMATION

Mounting Hardware Included: Yes

LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

UN SPSC: 43222819

CONSTRUCTION INFORMATION

Installation Location: Residential

DIMENSIONS

Height (Metric): 29.2 cm
Height (US): 11.5"
Length (Metric): 9.4 cm
Length (US): 3.7"
Width (Metric): 37.5 cm
Width (US): 14.75 in

TECHNICAL INFORMATION

AC Voltage Input: 100-240 VAC ~ 1A max, 50-60Hz
Cat5 Cable Rating: Category 5e

Connection Method: RJ45 and F
Humidity: 90% Relative Humidity (Non-Condensing)
Material: LCS .048" Thick
Mounting: Enclosure
Operating Temperature (Celsius): 0°C to 55°C
Output And Line Out Connection: 20 Telecom x 16 Video
Volts (DC): 15 VDC 1000 mA Included