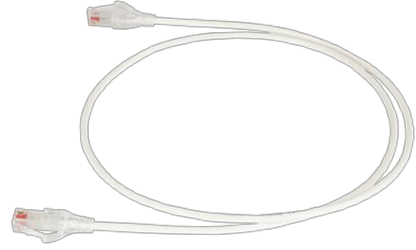

EZ PATCH, 28AWG RDC C6 CORD 9FT, BLUE, 70 PCS

EZRD609Q70-06 | [Ortronics](#)



FEATURES & BENEFITS

EZ Patch 50 pack, Reduced diameter Cat 6 modular patch cord, blue, 9', four-pair UTP stranded 28 AWG PVC/CM,

- **Dispenses patch cords quickly and easily:** Reduces staging and installation time.
- **Eliminates trash from opening bags:** A green, friendly approach to packaging patch cords.
- **Provides a more orderly staging approach:** Eliminates errors and tangles from traditional staging
- **Each cord is factory tested:** Ensures every cord shipped meets Category 6 channel specifications.
- **Reduced diameter mini patch cord :** takes up less cable management space and leaves more space for airflow
- **Premium plug designed for reduced OD 28 awg patch cable:** Protects performance integrity through the plug termination .
- **Snagless plug design:** Protects plugs when pulling through cable managers or pathways .
- **Premium 28 awg conductor cordage:** Reliable performance and durable cord life.
- **Compatible with both T568A and T568B wiring:** Provides universal wiring ability.
- **Backwards compatible to Category 3, 5, and 5e:** Supports lower category installations and components.

SPECIFICATIONS

GENERAL INFO

Cable Type: Four-pair 28 awg stranded UTP CMR rated

Color: Blue

Color Cable Jacket: Blue

Pair Count: 4 pair

Quantity: 70 cords

Termination: 8-Position Modular plug

Typical Applications: IEEE 802.3 1000Base-T (Gigabit Ethernet), 10-100Base-T, TIA/EIA-854 1000Base-TX,

Type: Patch Cord

LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

FCC Standard: Yes

CONSTRUCTION INFORMATION

Component 1: Cable

Component 2: Eight-position plug assembly

Component 3: Modular plug IDC contacts

Component 4: Clear plastic strain relief

Finish Plating 3: 50 Micro inch elective gold plating over nickel

Material 1: 28 AWG tinned copper stranded conductors, HDPE insulation, PVC jacket

Material 2: Polycarbonate plug housing and conductor centering sled

Material 3: Phosphor-bronze contacts designed for smaller 28awg conductors

Material 4: Molded PolyCarbonate

DIMENSIONS

Diameter (Metric): 3.94 mm

Diameter (US): 0.155 in

Length (Metric): 2.74 m

CORD INFORMATION

Connector Type End One: Plug, HSG, eight-contact, RJ45, C6 performance

Connector Type End Two: Plug, HSG, eight-contact, RJ45, C6 performance

Jacket Rating: CMR

Cord Length Metric: 2.74 m

Cord Length US: 9'

Min Bend Radius: .65 "

Pinning: Straight 1-1, 2-2, 3-3, etc.

TECHNICAL INFORMATION

Category Rating: C6

OhmValue: 100 Ohm

Performance Rating: C6

Wire Gauge: 28 AWG

BUY AMERICAN ACT COMPLIANCE

Country Of Origin: MEXICO

Buy American Act Status: Trade Agreement Act Compliant

