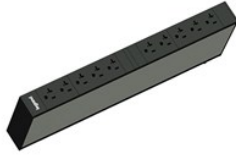


---

## RACK PDU, BASIC, 1U, 24A, 208V, (10) C13, L6-30P CORD

LP-22310 | [Legrand](#)

---

### FEATURES & BENEFITS

Basic PDUs provide reliability and simple installation. Standardized power distribution enables cost effective scaling, speed to deployment, and simplifies procurement due to a common platform.



- **Input Plug:** NEMA L6-30P
- **Output Receptacles:** (10) Locking IEC-C13, 12A
- **Integrated Locking Outlets on IEC Receptacles:** Eliminates the need for special power cords that lock at the PDU
- **Rotatable Cord:** Enables maximum flexibility for routing the input plug—simplifying the installation of Zero U PDUs
- **Mounting Types:** Available in horizontal and vertical configurations to ensure power distribution is optimally located
- **Hydraulic-Magnetic Breakers:** Provide less heat dependent local protection and quick recovery from circuit overload, by utilizing a two-step response curve—these breakers provide a delay on normal overcurrents, while tripping quickly on short circuits

---

### SPECIFICATIONS

#### GENERAL INFO

Color: Black / Silver  
Product Series: LP-Series  
Type: Power Distribution Unit  
Component Type: Basic PDU  
Input Plug Type: NEMA L6-30P

#### LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

RoHS: Yes

#### DIMENSIONS

Rack Units: 1

#### CORD INFORMATION

Cord Length Metric: 3m

## **TECHNICAL INFORMATION**

AC Voltage Input: 208V

Amps: 24A

Mounting: 19" Rack Mount

Capacity: 5kVA

Receptacle Type: C13

Number Of Receptacles: 10

## **BUY AMERICAN ACT COMPLIANCE**

Country Of Origin: CHINA