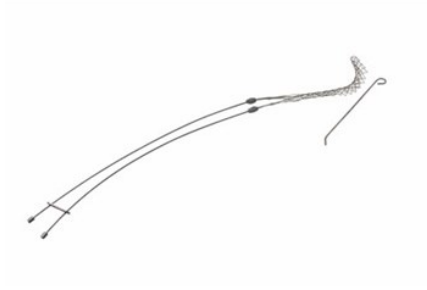

SUPPORT GRIPS STANDARD DUTY, SPLIT ROD

FR075LB | [Pass & Seymour](#)

FEATURES & BENEFITS

Standard-duty, Split rod, Locking bale (Universal eye). Cable diameter - 0.750-0.990", Bale length - 10", Mesh length - 11", Break strength - 1,320 lbs.



- Split rod support grips are designed for loads up to 600 lbs.
- Vertical runs of no more than 100 ft.
- They are available in a variety of eye styles and cable ranges for supporting electrical and fiber optic cable, metal rods, and tubing.
- Split rod support grips are used when the end of the cable cannot be easily accessed and the installation is temporary.
- Support grips are woven of corrosion-resistant tinned-bronze wire.
- Most Flexcor products have UL and/or CSA approvals. Please contact factory for approval information.

SPECIFICATIONS

GENERAL INFO

Typical Applications: Service Drop
Product Series: Flexcor
Type: Split Rod
Duty: Standard Duty
Special Features: Locking Bale

LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

RoHS: Yes
CSA Listing Info: No
CUL Listing No: No
cULus: No
cURus: No

Federal Spec: No
UL Listing No: No
UN SPSC: 39121722
UR: No

DIMENSIONS

Weight: 0.22017

BUY AMERICAN ACT COMPLIANCE

Country Of Origin: MEXICO
Buy American Act Status: Trade Agreement Act Compliant

