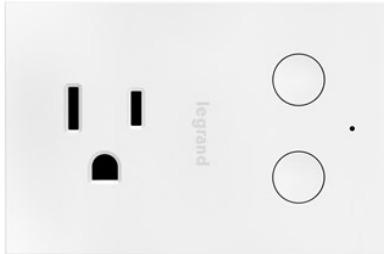


---

## SMART PLUG-IN TRU-UNIVERSAL DIMMER WITH HOMEKIT TECHNOLOGY

HKRP20 | [radiant](#)

---

### FEATURES & BENEFITS

Legrand offers a family of lighting control products for your home fully enabled to interface with Apple HomeKit. Apple HomeKit technology provides an easy, secure way to control your lights, outlets, thermostats, and more from your iPhone or iPad. With the Home app, easily and securely control all your HomeKit accessories from one location.

[Shop on Amazon.](#)



- Works with Apple HomeKit technology
- Operates all dimmable lighting types and loads (except 0-10V loads) from the mobile app.
- Use Siri, Alexa, or the Google Assistant to control your lights with just your voice.
- No hub required. Automated control and remote access requires an Apple TV with tvOS 11 or later, an iPad with iOS 11 or later, or a HomePod set up as a home hub.
- Use Legrand Home app for scenes, room grouping, automation and more.
- Simply plugs into the home's existing electrical 120V outlets.
- Locator light for finding switch in the dark.
- Part of the radiant® Collection.

---

### SPECIFICATIONS

cULus Listed, UL916, CSA C22.2 No. 205, UL498A, CSA-C22.2 No. 42-10.

FCC ID: YV8-SA7529

IC ID: 9922A-SA7529

EMC Regulatory Approval: Yes

SSL 7A Compliant: Yes

### GENERAL INFO

Color: White

Connection Type: Certified IEEE 802.11™ b/g/n Wi-Fi® 2.4GHz radio

#### LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

RoHS: Yes

cULus: Yes

FCC Standard: Yes

UL Listing No: UL916, UL498A

UL Standard: Yes

#### CONSTRUCTION INFORMATION

Material 1: Polycarbonate Lexan

#### DIMENSIONS

Depth (US): 2.0"

Height (US): 2.125"

Width (US): 4.00"

Weight: 0.19 lbs.

#### TECHNICAL INFORMATION

Compatible Power Supplies: Apple

Humidity: 0-90% relative humidity, non-condensing

Interoperability: Works with Apple HomeKit / Works with Alexa / Works with the Google Assistant

IP Rating: IP Native

Load: 300W incandescent/halogen | 300W CFL/EFL | 1A LED/Eballast | 300VA MLV

Mounting: Standard electrical outlet

Operating Temperature (Celsius): 0°C to 43°C

Volts: 120

#### BUY AMERICAN ACT COMPLIANCE

Country Of Origin: CHINA