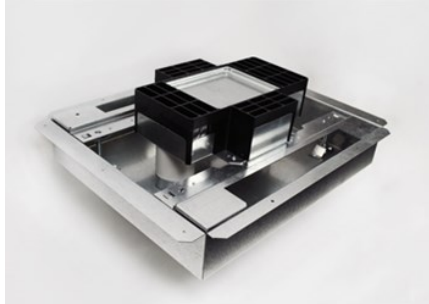

RFB4S-FC RESOURCE RFB SERIES FIRE CLASSIFIED 4-GANG FLOOR BOX

RFB4S-FC | [Wiremold](#)

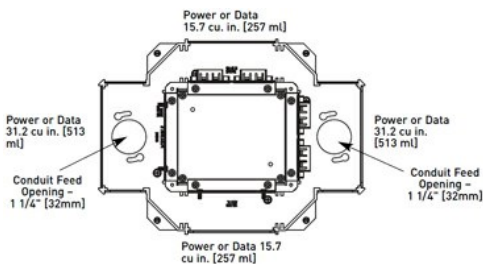


FEATURES & BENEFITS

Fire Classified 4-Compartment Box. Includes four duplex receptacle brackets. 12 3/4" L x 10" W x 3 7/16" D (324mm x 254mm x 87mm). Fully adjustable. Tunneling from adjacent or opposite compartments only, (not cross compartments). Tunneling can be set to feed all four compartments from one conduit in a single-service application. NOTE: For use in normal weight concrete floors with a minimum pour depth of 4 1/2" (114mm) over the crest of the deck. Floor Box spacing 2' on center and one for every 4 square feet in a span. Four (4) #12 AWG Type THHN Power Conductors or 48 #23 AWG (6 Cat. 6) Tele Data Conductors per gang. This box preserves the 2-hour fire rating of floors in which it has been installed.

SPECIFICATIONS

Knockout Sizes & Locations:



GENERAL INFO

Product Series: FCFB
Component Type: Boxes
Knockout Size: 1 1/4"

CONSTRUCTION INFORMATION

Installation Location: Above-Grade

BUY AMERICAN ACT COMPLIANCE

Country Of Origin: MULTIPLE

Buy American Act Status: Exception

Note: While most parts within this series comply with the BAA's Country of Origin requirements, some do not. For a complete list of all parts and their respective Country of Origin, refer to the "Series Part List-COO" under "Supporting Documents" on the "Resources" tab.