
AC10105-2 SERIES RAISED FLOOR BOX

AC10105-2 | [Wiremold](#)



FEATURES & BENEFITS

With a 5" (127mm) depth, this is a square profile box that provides eight gangs of power and/or communication device capacity. Power plate with duplex knockouts included with box. It also provides increased plug-in volume which is ideal for the additional space needed when plugging in transformer type plugs. Lids can be rotated 180° for easy orientation. Gray lids are die-cast zinc construction.



- This product meets the material restrictions of RoHS

SPECIFICATIONS

DIMENSIONS:

Box Dimensions: 10" x 10" x 5" [254mm x 254mm x 127mm]

Overall Trim Ring: 11 1/2" x 11 1/2" [292mm x 292mm]

Module Depth Overall: 5" [127mm]

Panel Opening: 10" x 10" [254mm x 254mm]

Cover Size: 9 5/8" x 9 5/8" [245mm x 245mm]

Activation Chamber Volume: 115 cu in. [1884ml]

User Volume: 243 cu in. [3981ml]


Total Volume: 358 cu in. [5865ml]

Knockout Sizes: Power - Four (4) 1/2" Trade Size Concentric KOs; Communication - Four (4) 1/2" Trade Size Concentric KOs

Service: Triple

Maximum Floor Thickness: 2" [51mm] (Includes floor covering)

Knockout Sizes & Locations:

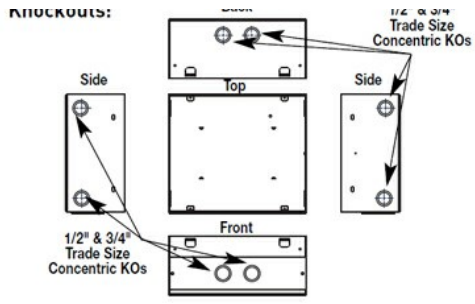

GENERAL INFO

Product Series: AC
Component Type: Boxes
Knockout Size: 1/2"-3/4"

LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

RoHS: Yes

CONSTRUCTION INFORMATION

Installation Location:

BUY AMERICAN ACT COMPLIANCE

Country Of Origin: UNITED STATES OF AMERICA
Buy American Act Status: Buy American Act Compliant

