




Pass and Seymour
Hospital Grade 15A Duplex Self-Test GFCI Receptacles with SafeLock® Protection, Red
Part No. 1597HGRED

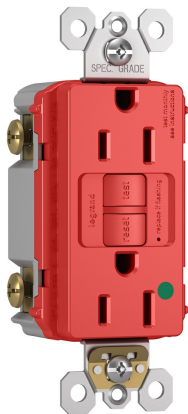

Hospital-Grade 15A Self-Test Duplex GFCI

Features & Benefits

Hospital Grade Self-Test GFCI

Specifications

General Info

| | | | |
|-------------------|-------------------------------------|-----------------------|-------------------------|
| Product Line | Pass & Seymour | Color | Red |
| Country Of Origin | China | Number of Receptacles | 2 |
| Outlet Type | Commercial, GFCI, Indoor, Self-Test | Application Sector | Residential/Commercial |
| Standard | cULus, UL Listed, FSUL | Warranty Type | 1-Year Limited Warranty |
| Type | Outlet | | |

Dimensions

| | | | |
|-------------------|---------|------------------|---------|
| Product Width US | 1.73 in | Product Depth US | 1.03 in |
| Product Height US | 4.2 in | | |

Listing Agencies / 3rd Party Agencies

| | |
|--------------|-----|
| cULus Listed | Yes |
|--------------|-----|

Additional Information

Product Environmental Profile Yes

Technical Information

| | | | |
|--------------------------|------------------------|------------------|--------------------|
| Interrupt Rating | 4 A | Frequency Rating | 60 Hz |
| Trip Range | 5±1 mA | Connection | Back and Side Wire |
| Amperage | 15 A | Number of Poles | Double Pole |
| Indoor/Outdoor | Indoor | Voltage | 125.0 V |
| Environmental Conditions | 95% Humidity, UL 94 V2 | | |