




Pass and Seymour
Isolated Ground Tamper-Resistant 15A Duplex Self-Test GFCI Receptacles with SafeLock® Protection, White
Part No. 1597IGTRW

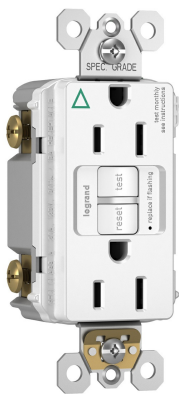

Conducts an automatic test every three seconds, ensuring it is always ready to protect. If the device fails the test, the indicator light flashes to signal that the GFCI should be replaced. It also has our proven SafeLock and tamper-resistant protection feature: if critical components are damaged and protection is lost, power to the receptacle is disconnected. For detailed Tamper-Resistant receptacle information, visit our Tamper-Resistant Receptacles page.

Features & Benefits

Hospital Grade Tamper Resistant GFCI

Specifications

General Info

Product Line	Pass & Seymour	Color	White
UPC Number	785007048193	Country Of Origin	China
Number of Receptacles	2	Features	Isolated Ground, Self-Test
Outlet Type	GFCI, Tamper-Resistant	Application Sector	Commercial, Multi-Dwelling Unit, Residential
Wall Plate Included	Yes	Standard	cULus, UL Listed, FSUL
Warranty Type	1-Year Limited Warranty		

Dimensions

Product Width US	1.7297 in	Product Depth US	1.03 in
Product Height US	4.2 in		

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Additional Information

Product Environmental Profile	Yes
-------------------------------	-----

Technical Information

Is Tamper-Resistant	Yes	Connection Location	Back and Side
Frequency Rating	60 Hz	Connection	Back and side wire
Number of Wires	3	Amperage	15 A
Number of Poles	Double Pole	Indoor/Outdoor	Indoor
NEMA Configuration Code	5-15R	Wire Connection Type	Internal Pressure Plates, Screw Terminals
Voltage	125.0 V	Environmental Conditions	95% Humidity, UL 94 V2