


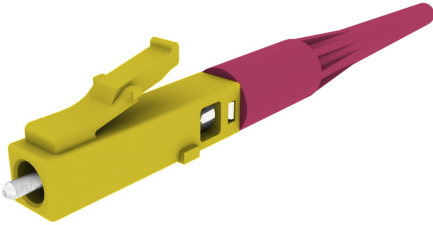

## Infinium Keyed LC Splice-On Connector (SOC) For 900 Micron Fiber, 50/125 Multimode OM4 Yellow Part No. 205KKF9GA-50E-C

Legrand keyed LC fiber solutions provide a simple and convenient way to physically prevent the user from making an unauthorized connection by blocking access to specific optical ports, whether they are at a workstation outlet or in a telecommunications room or data center. This is particularly important for government, finance, military and other facilities where multiple networks having different security level access requirements may be co-located.



### Features & Benefits

A factory-cleaved 900um fiber stub ensures ease of use and optimal performance	1.6 in boot protects the splice for easy cable management
The solution to managing multiple networks with reduced risks	LC Keyed cadapters prevent improper connection of separate networks with common access points
LC SECURE products feature twelve color-coded, keyed designs to limit improper connections networks.	Each LC secure adapter will mate only with same-color LC secure connector
Internal keying feature prevents tampering	High quality 1.25 mm zirconia ferrules used
50/125 $\mu\text{m}$ and 9/125 $\mu\text{m}$ laser-optimized fiber types available	

### Specifications

#### General Info

UPC Number	662875028246	Country Of Origin	United States
Product Line	Legrand	Type	Connector

#### Technical Information

Fiber Size	50/125	Insertion Loss	0.15dB typical dB
Temperature Rating	40 to +75°C	Service Life	< 0.2dB typical change,500 matings
Fiber Type	OM3/4		