




Ortronics
Infinium Fusion Splice-On Connector, LC OM3, aqua 900 micron boot, packaged in boxes of 6
Part No. 205KNF9GA-50T

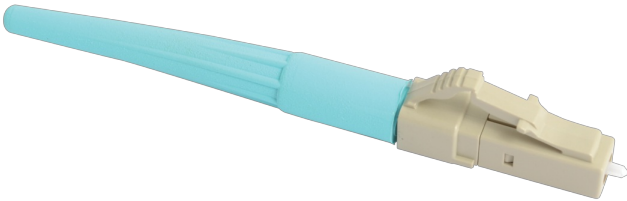

Splice-On Connector LC PC OM3

Features & Benefits

- Better Insertion Loss & Return Loss Performance: Support high-bandwidth/high-speed transmission to 25G, 40G and 100G applications

Available in LC, SC and ST, Single-Mode or Multimode: Multiple connector types available

UV Cure Protection Sleeves: Strain relief boot protects the splice point

3mm Version: Brass crimp to protect splice

Fiber endface types: Endfaces available in PC, APC and UPC
- Factory-cleaved, pre-polished 900-micron fiber stub: Provides a quicker termination

900-micron boot conceals and protects the splice: Enables better cable management

3mm Version: 3mm boot protects splice for easy cable management

3mm Version: Tubing insert to accommodate 1.6/2.0/3.0 cordage

Specifications

General Info

Product Line	Ortronics	UPC Number	662875704027
Country Of Origin	United States		

Dimensions

Product Width US	2.46 in	Product Depth US	2.46 in
Product Height US	0.4 in		