




Pass and Seymour
Hospital Grade Tamper-Resistant Weather-Resistant 20A Duplex Self-Test GFCI Receptacles with SafeLock® Protection, White
Part No. 2097HGTRWRW

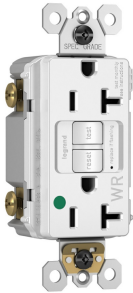

Hospital-Grade Tamper-Resistant Weather-Resistant 15A Self-Test Duplex GFCI

Features & Benefits

Hospital Grade GFCI self-test CH versions feature a factory broken split circuit tab allowing you to control half of the receptacle.

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Finish	Matte	Country Of Origin	China
Number of Receptacles	2	Outlet Type	Commercial, GFCI, Outdoor, Tamper-Resistant, Weather-Resistant
Type	Outlet		

Dimensions

Product Width US	1.73 in	Product Depth US	1.13 in
Product Height US	4.2 in		

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Technical Information

Amperage	20 A	Number of Poles	Double Pole
Indoor/Outdoor	Outdoor	Voltage	125.0 V